

NOTES1:

- UL Standard
1.Rated voltage/current : 300V / 15A
2.Withstanding voltage : AC1600V/1Min.

IEC Standard

1. Pollution degree	2
Overvoltage category	III
Rate impulse voltage(KV)	4KV
Rate voltage(V)	320V
Rate current(A)	10A

NOTES2:

- 1.Dimension shall be interpreted per ASME Y14.5-2009
2.Pitch : 5.08mm, Poles : N=04~48P
3.Operating temperature: -40°C~+105°C
4.Undimensioned tolerances:

Pitch range in mm		Nominal dimension range in mm						— C D			
Over	6	Over	10	Over	30	Over	60	Over	100	Over	150
TO	10	TO	24	TO	30	TO	60	TO	100	TO	150
6	10	24	30	60	100	150					
±0.15±0.20±0.30±0.30±0.50±0.70±1.00±1.30											±2°

5.RoHS Compliance

Ordering Information






JL2EDGVT - 508 XX G 0 1

Pitch
508=5.08PH

No.of pins
4P~48P

Housing Color
B=Black
G=Green
U=Blue
R=Red
W=White
Y=Yellow
E=Grey

Packing
0=Pe bag
T=Tube
A=Tray

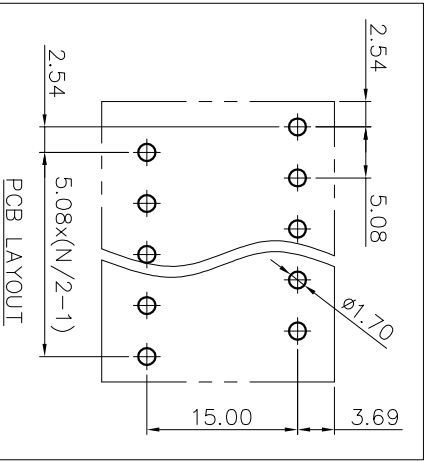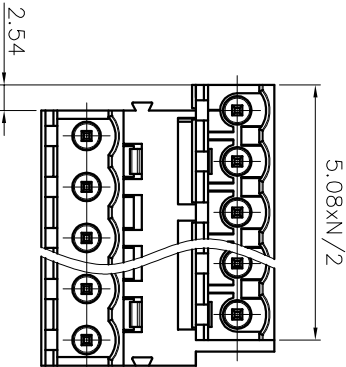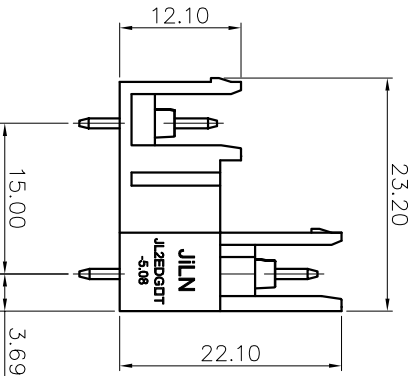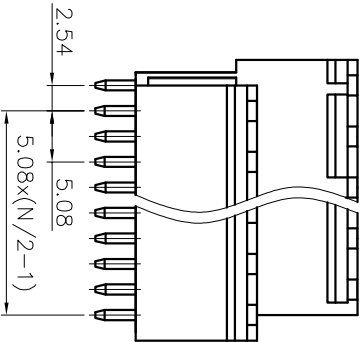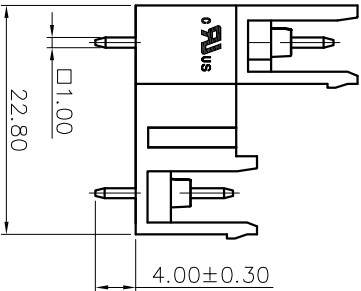

PCB LAYOUT

REVISION RECORD			
REV	ECN	DESCRIPTION	DATE

DRAW	SHUANGPING ZHENG	SCALE	FIT	PART NO.	
		UNIT	mm		
CHECK	LICHAD LIU	SIZE	A4	TITLE:	
APPROVE	YONGLIANG GAO	SHEET	1/1		
		PROJ.		JL2EDGVT-5-08-2xNP插拔式公座/直脚/开口绿色	

jiln®东莞市锦凌电子有限公司
DONGGUAN JINLING ELECTRONIC CO.,LTD