


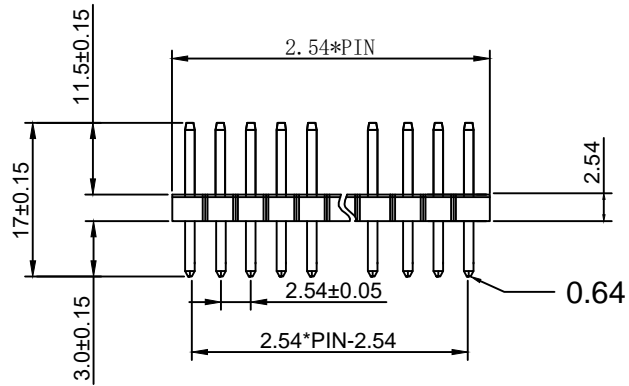

材料Material  
 原料Insulator:PBT,(UL 94V-0)  
 相关材料Related Material: Brass  
 表面涂层Surface Coating:Gold Over Nickel

规格Specification  
 额定电流Current rating:3AMP  
 耐压Dielectric Withstanding Voltage:30v Ac Min  
 绝缘电阻Insulation Resistance:1000MΩ min  
 接触电阻Contact resistance:20MΩ Max  
 工作温度Operating Temperature:-40 °C ~+105 °C



		上海洲日电子有限公司	
		Shanghai Zhouri Electronics CO.,LTD	
		上海康司玛电子设备进出口有限公司	
		Shanghai KangSiMa Eletronic Equipment import and export Co.,LTD	
绘图:	MAXIA	日期:	20170205
审核:	FANHUA	日期:	20170205
版本编号:	ZRLCGY2015-05-01-CJ	产品名称:	排针1*40 2.54 L=17MM 0.4U
第三视角:		单位:	mm
		比例:	图幅:A4
		页次 共 01 第 01	