






Material

Insulator: Glass filled PBT, (UL 94V-0)
 Contact : Brass

Electrical Characteristics

Current rating: 3AMP
 Dielectric Withstanding Voltage: AC 500V for 1 Minute.
 Insulator Resistance: 1000MΩ Min. AT DC 500V.
 Contact Resistance: 20mΩ Max.
 Operating Temperature: -45°C ~ +105°C

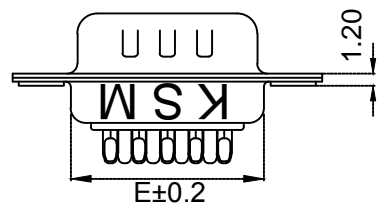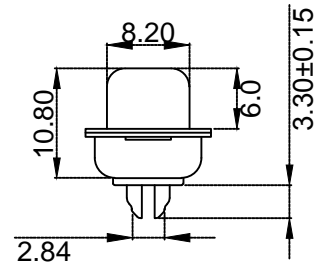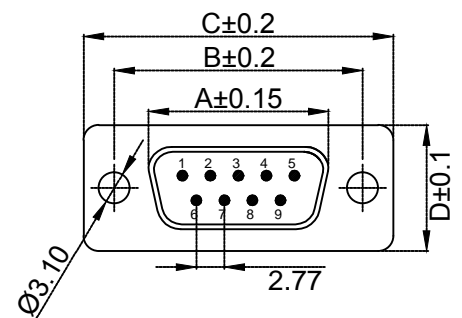

| PIN | 尺寸 | | | | | | | | D-SUB-*M | | 上海洲日电子有限公司 Shanghai Zhouri Electronics CO.,LTD | | | |
|-----------|--------|-------|-------|-------|-------|------|-------|-----|------------------|--|--|--|--|--|
| | A±0.15 | B±0.2 | C±0.2 | D±0.1 | E±0.2 | | | | | | 上海康司玛电子设备进出口有限公司 Shanghai KangSiMa Eletronic Equipment import and export Co.,LTD | | | |
| D-SUB-9M | 17.90 | 25.00 | 30.80 | 12.50 | 19.20 | X. | ±0.3 | ±5° | 20171018 A/0 | | TEL:86-21-34975176/51571121 | | | |
| D-SUB-15M | 26.50 | 33.30 | 39.20 | 12.50 | 27.80 | X.X | ±0.2 | ±3° | ZR20171018-DB-61 | | 物料编号 | | | |
| D-SUB-25M | 40.00 | 47.10 | 53.05 | 12.50 | 41.30 | X.XX | ±0.15 | | 201171018 | | 1:1 mm 图幅 A4 | | | |
| D-SUB-37M | 56.50 | 63.50 | 69.44 | 12.50 | 57.50 | | | | 201171018 | | : 1 1 | | | |
| | | | | | | | | | 201171018 | | | | | |

