

F3 万能转换开关

LW5-16 万能转换开关

选型指南



产品名称	电流规格	特征代号	输出形式	节数
LW5	<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>
	16: 16A	A:0° -45° 自复型 B:45° -0° -45° 自复型 C:0° -45° 定位型 D:45° -0° -45° 定位型 ... P:90° -0° -90° 定位型 ...	0401: 0401 0723: 0723 1050: 1050	1:1节 ... 16:16节



操作方式	特征代号	操作手柄位置									
		0°	45°	0°	45°	0°	45°	90°	135°	180°	120°
自复型	A										
	B					45°	0°	45°			
	C						0°	45°			
	D					45°	0°	45°			
	E					45°	0°	45°			
	F					45°	0°	45°	90°		
	G					90°	45°	0°	45°	90°	
	H					90°	45°	0°	45°	90°	135°
	I					135°	90°	45°	0°	45°	90°
	J					135°	95°	30°	0°	30°	95°
	K					120°	90°	60°	30°	30°	60°
	L					120°	90°	60°	30°	30°	60°
	M					150°	120°	90°	60°	30°	60°
	N						45°	45°			
	P						90°	0°	90°		
	TM	30°	0°	30°	60°	90°	120°	150°	180°	210°	240°
	YH/LH						0°	90°	180°	270°	

注：客户订货时可参照我厂编制的开关接线图进行选用，如有特殊要求，须预先说明或提供接线图。

技术参数

使用类别		AC-15			DC-13			AC-3						
额定工作电压(Ue)	V	500	380	220	440	220	110	380						
额定工作电流(Ie)	A	2.0	2.6	4.6	0.14	0.27	0.55	12						
电气寿命	次	20×10^4			20×10^4			19.5×10^4						
额定绝缘电压(Ui)	V	500												
约定自由空气发热电流(Ith)	A	16												
额定冲击耐受电压(Uimp)	V	6000												
国家标准		GB/T14048.5												
认证证书		CCC												

F3 万能转换开关




LW5-16 万能转换开关

操作图

开关几种常用操作图(“ \times ”表示接通)

LW5-16 TM707/7 操作图


	自动	停止	手动	60°	90°	120°	150°	180°	210°	240°	270°	300°
1—2		\times										
3—4	\times											
5—6	\times											
7—8			\times									
9—10				\times								
11—12					\times							
13—14						\times						
15—16							\times	\times	\times	\times	\times	\times
17—18								\times	\times	\times	\times	\times
19—20									\times	\times	\times	\times
21—22										\times	\times	\times
23—24											\times	\times
25—26												\times
27—28												

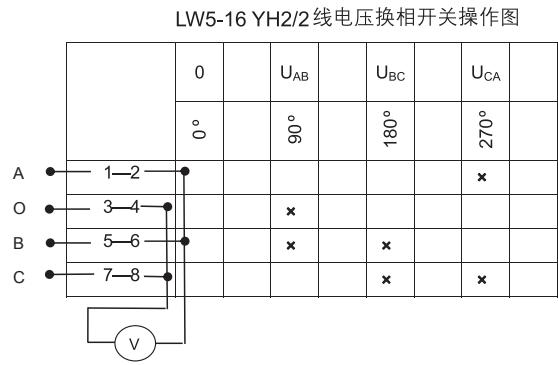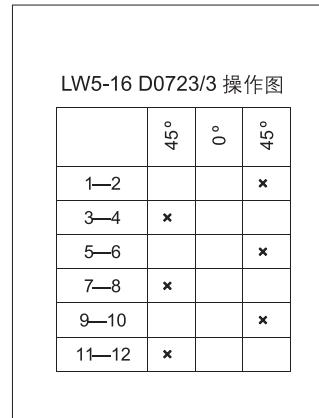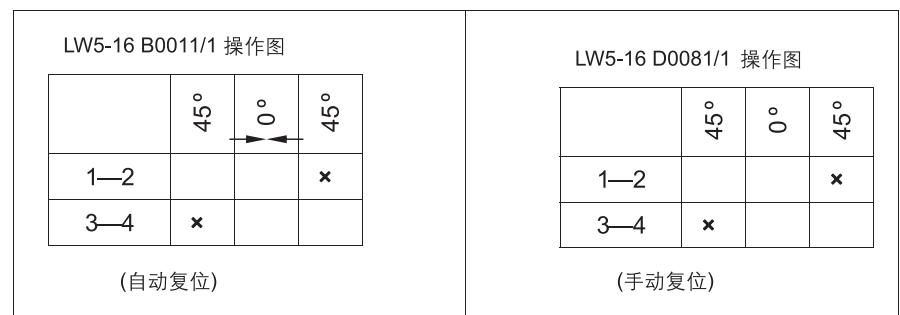


F3 万能转换开关

LW5-16 万能转换开关

LW5-16 YH3/3 线电压换相开关操作图

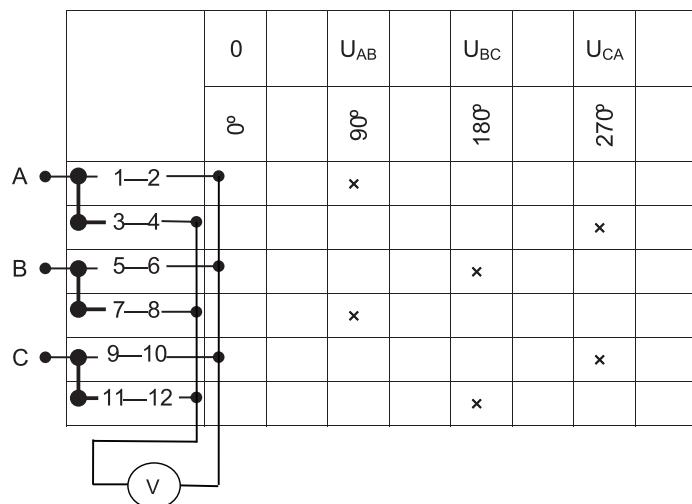

LW5-16 LH3/3 电流压换相开关操作图

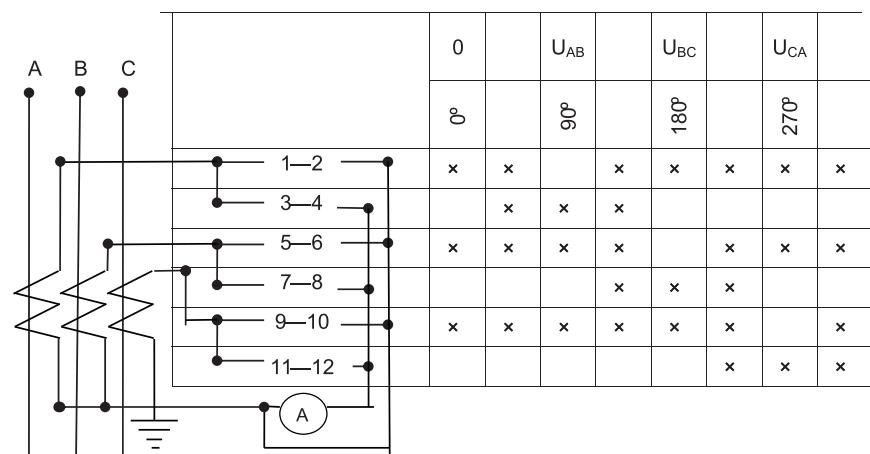


HZ5 组合开关操作图 (“x” 表示接通)

	L01		L02		L03		M04		M05		M06		M07		M08						
	0	1	0	1	0	1	1	0	2	1	0	2	1	0	2	0	Y	Δ	0	1	2
1—2		x		x		x	x				x			x		x	x		x		x
3—4		x		x		x	x			x		x			x		x		x		x
5—6			x		x			x			x			x			x			x	
7—8				x				x	x		x				x		x	x		x	
9—10					x					x			x			x	x	x		x	
11—12						x				x				x			x			x	
13—14							x				x				x		x		x		x
15—16								x				x				x			x		x

F3 万能转换开关

LW5-16 万能转换开关

外形及安装尺寸(mm)

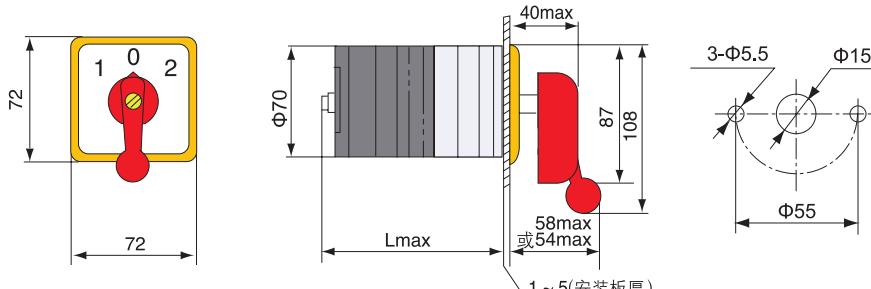

定位型：

Lmax+40max(旋钮)

Lmax+58max(旋钮)

Lmax=44+16n(节数)


自复型：

Lmax+40max(旋钮)


Lmax+54max(旋钮)

Lmax=48+16n(节数)

LW5-16万能转换开关外形尺寸、安装尺寸

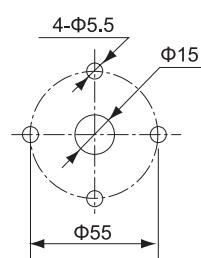

LW5-16定位型用安装尺寸
(自复型不适用)

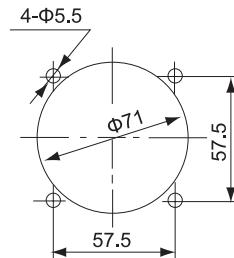

LW5-16备用安装尺寸
(4节以上不推荐使用)