
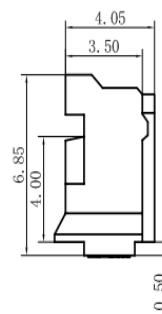
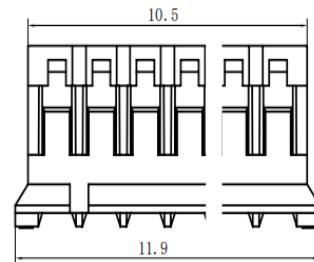
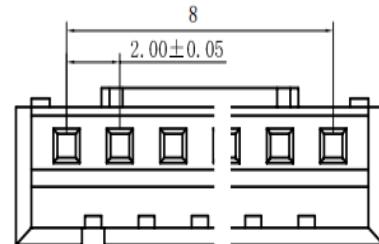
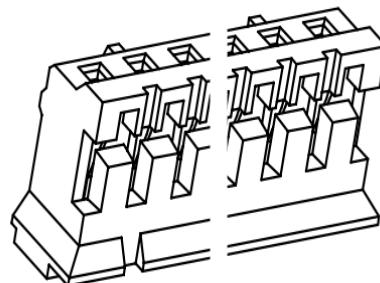


HX 2.0-5P DT 200mm 26AWG

2.0 mm×5P插头, UL1007, 80 ,26AWG, 线长200mm (1端插头, 另一端剥皮镀锡2mm)

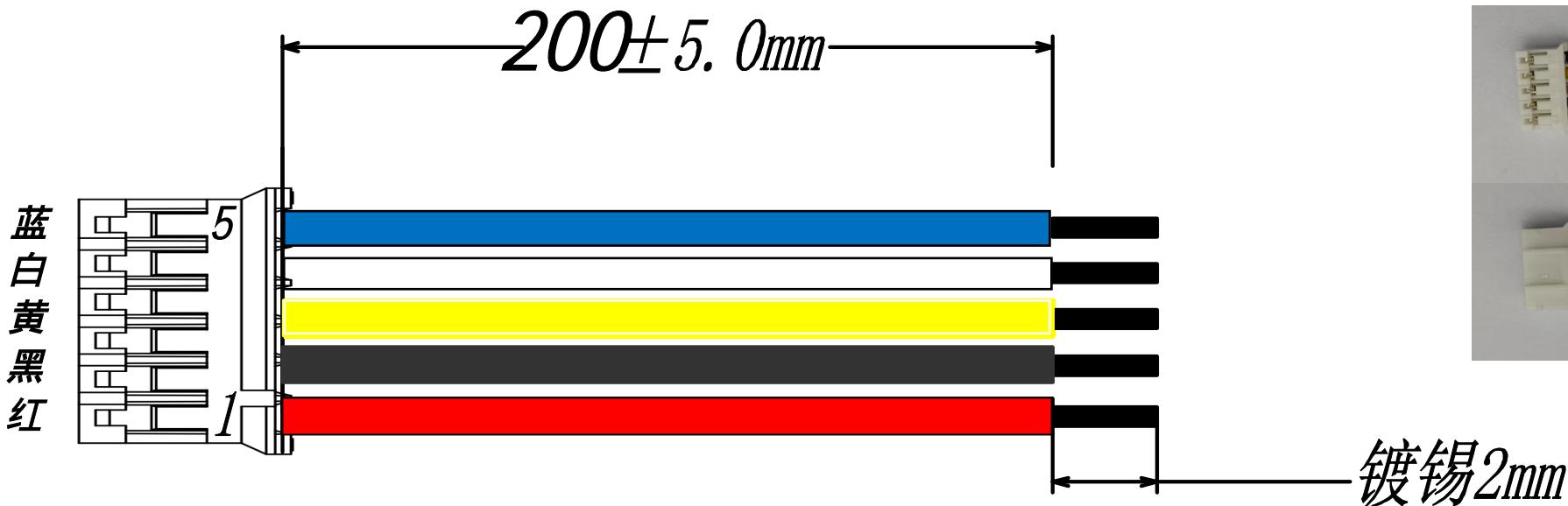

- 1. 极数 poles: 2 to 20P
- 2. 额定电流 Current rating: 2.0A AC, DC
- 3. 额定电压 Voltage rating: 100V AC, DC
- 4. 温度范围 Temperature range: -25° C to +85° C
- 5. 接触电阻 Contact resistance: $\leq 10\text{m}\Omega$
- 6. 绝缘电阻 Insulation resistance: $\geq 1000\text{M}\Omega$
- 7. 耐电压 Withstand voltage: 800V AC/minute
- 8. 适用线规 Applicable Wire: AWG #26
- 9. 适用基板厚度 Applicable PC board thickness: 1.6mm

韩下 HANXIA 深圳市韩下电子有限公司	
日期: 2020-6-15	元件名称: HX 2.0-5P DT 200mm 26AWG
设计: 李丽凤	
审核: 钟华华	
批准: 罗华金	
尺寸单位: mm	
第1页 共1页	