


THR-2520

FEATURES


- Surface mount ceramic enclosures
- Miniature size
- Excellent temperature tracking
- Designed for mobile communication
- RoHS Compliant and Pb Free

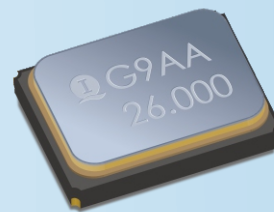

Electrical Specifications		
Parameters	Symbol	Specifications
Nominal Frequency Range 标称频率范围	f_0	16 MHz~96 MHz
Frequency Tolerance, Ta=25°C ± 3°C 常温频率偏差	$\Delta f/f$	±10ppm
Load Capacitance 负载电容	C_L	7pF, 9pF or specify
Frequency Tolerance over Operating Temperature Range 频率温度特性	$\Delta f/f$	±10ppm or specify
Operating Temperature Range 工作温度	T_{OPR}	-30°C ~ +85°C, -40°C ~ +85°C
Storage Temperature Range 储存温度	T_{STG}	-55°C ~ +125°C
Drive Level 激励功率	DL	100µW Max.
Shunt Capacitance 静态电容	C_0	2pF Max.
Equivalent Series Resistance (ESR) 串联谐振阻抗	ESR	80Ω 60Ω
Aging 老化率	Δf_A	±1ppm/Year
Oscillation Mode 振动模式	OT	Fundamental
Thermistor Resistance 热敏电阻阻值		100 KΩ ± 1%
Thermistor B-Constant 热敏电阻B常数		4250K ± 1%

Please consult our sales representatives for other specifications. 如对其他规格查询, 请与我司销售人员联系。

Dimensions

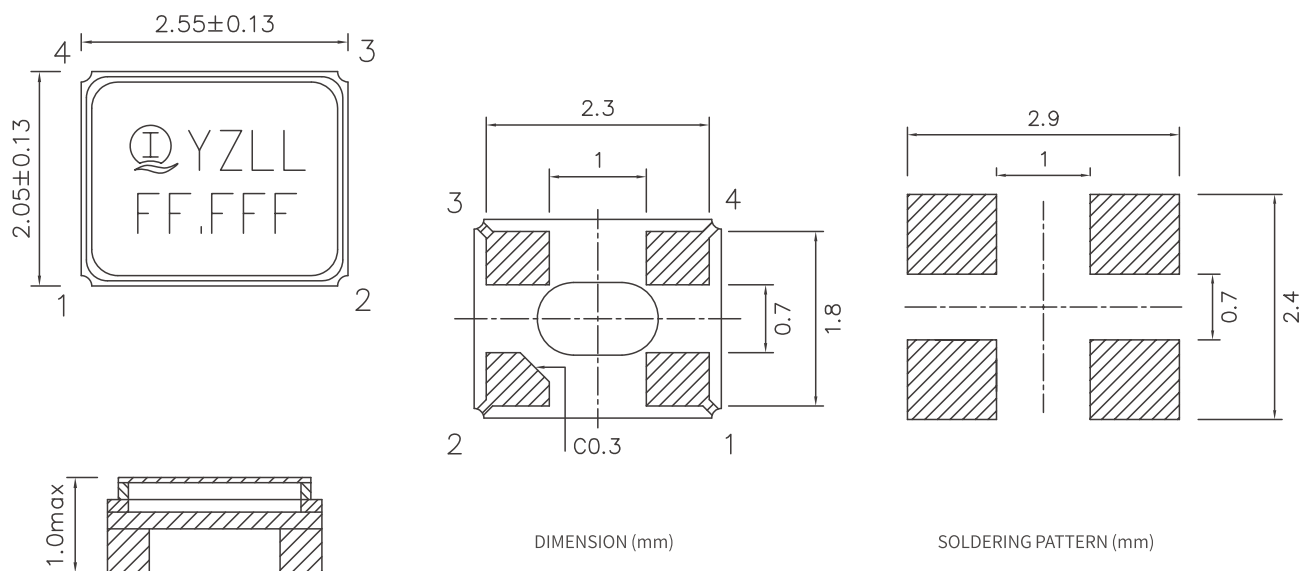

DIMENSION (mm)

SOLDERING PATTERN (mm)

All specifications are subject to change without prior notice. 本公司保留修改规格的权利。