

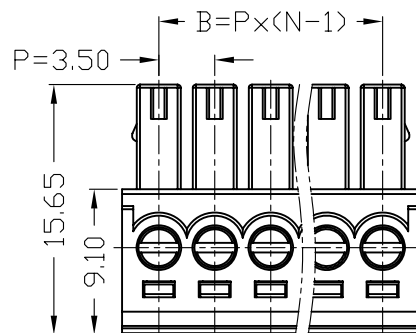
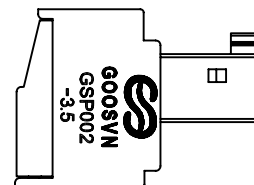


版次 (Version)	変更内容 (Rev. Content)	変更者 (Change Person)

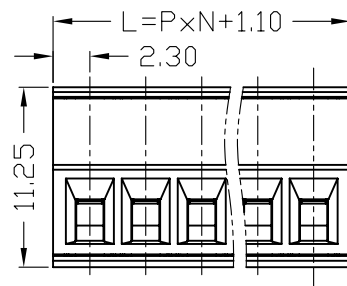

≥7P No locking tab

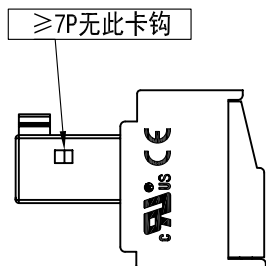

技术参数 (Technical Data)		
项 目 (Item)	UL	IEC
额定电气参数 (Rated Electrical Parameters)	300V/8A	250V/7A
压线范围 (Wire Range)	28~16AWG	0.5~1.5mm ²
工频耐压 (Frequency Voltage)	AC 2000V	
冲击耐压 (Rated Surge Voltage)	4000V	
绝缘阻抗 (Insulation Resistance)	DC500V 500M Ω above	
接触电阻 (Contact Resistance)	≤8m Ω	
剥线长度 (Stripping Length)	7mm	
工作温度 (Temperature)	-40℃~+105℃	
材质和电镀 (Material and plating)		
绝缘材质 (Housing)	PA66 (UL94 V-0)	
触点材料 (Contact)	铜合金, 镀镍 (Copper alloy, Ni plated)	
螺丝 (Screws)	钢, 镀锌 (Steel, Zn plated)	
方盒 (Cage)	铜合金, 镀镍 (Copper alloy, Ni plated)	

产品命名编码:

(Product Number Code):

GSP002-3.5-XXP-1Y-00A (H)

产品型号 (Series No.)-

—客户需求

(Customer Request)

 
极数 (No. of poles)

—塑体颜色(Housing Color)

- 1:单倍间距
(Single Pitch)
2:双倍间距
(Double Pitch)

- | | |
|----------------|--------------------------|
| 1: 绿色 (Green) | 7: 透明色
(Transparent) |
| 2: 蓝色 (Blue) | 8: 白色 (White) |
| 3: 黑色 (Black) | 9: 黄色 (Yellow) |
| 4: 灰色 (Grey) | Y: 多种颜色
(Mixed Color) |
| 5: 橙色 (Orange) | |
| 6: 红色 (Red) | |

P=3.5mm, N为孔位数 (N for hole digits), 有效位数为 (Significant Digits): 02P~24P												
N	02P	03P	04P	05P	06P	07P	08P	09P	10P	11P	12P	13P
L	8.10	11.60	15.10	18.60	22.10	25.60	29.10	32.60	36.10	39.60	43.10	46.60
B	3.50	7.00	10.50	14.00	17.50	21.00	24.50	28.00	31.50	35.00	38.50	42.00
N	14P	15P	16P	17P	18P	19P	20P	21P	22P	23P	24P	
L	50.10	53.60	57.10	60.60	64.10	67.60	71.10	74.60	78.10	81.60	85.10	
B	45.50	49.00	52.50	56.00	59.50	62.50	66.50	70.00	73.50	77.00	80.50	

 宁波高胜电子有限公司 NINGBO GOOSVN ELECTRONIC CO.,LTD			公差范围(Tolerance Range)		
型号(Type): GSP002-3.5-XXP-1Y-00A (H)			150~		±1.50
			60~150		±1.00
			30~60		±0.60
核准(Approval):			6~30		±0.40
			0~6		±0.25
审核(Audit):			角度(Angle)		X ±2°
			X,X		±1°
单位(Units):mm			页码(Page): 1/1		
设计(Design):			比例(Scale):FULL		
					版次 (Version): TO