


技术参数:

- 1、额定电器性能: 3~16A 125/250VAC (UL;CUL);
- 2、动作时间标准: 环境温度25℃电流200% (6~32A) 时3到60秒内断开;
- 3、耐压: 1500VAC/0.5mA/1min无闪络、无击穿;
- 4、机械寿命: ≥10000次;
- 5、耐焊时间: ≤3秒焊接温度350±10℃。


品名	底座	上盖	端子类型	带灯类型
WH-201-**BR01W3-L22-R	黑色	暗红色	长脚	带红灯
WH-201-**BR01W2-L22-R	黑色	暗红色	中长脚	带红灯
WH-201-**WR01B2-L22-R	白色	暗红色	中长脚	带红灯
WH-201-**WC01B3-L22-R	白色	白色透明	长脚	带红灯
WH-201-**BC01W3-L22-R	黑色	白色透明	长脚	带红灯

WH-001-*****-***-A
 额定电流: 03~16A 端子类型

端子类型 (参考)

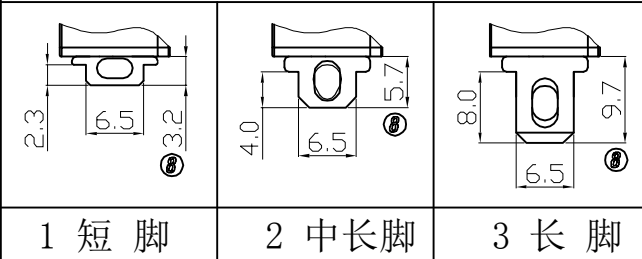

开孔尺寸参考

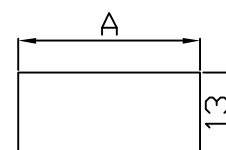

THICKNESS	DIMENSION A
0.8~1.0	29.0 ^{+0.1} ₀
1.1~1.4	29.5 ^{+0.1} ₀
1.5~2.5	30.0 ^{+0.1} ₀

NO	DESCRIPTION	NO	DESCRIPTION	DIMENSIONAL TOLERANCES		APPROVED	CHECKED	DESIGN	DRAWN	ALL SIZE ARE IN		DRAWING NO.	REV.
				RANGE	TOLERANCE					MM	NO		
5	→	10	→	X	±0.30				LMC	MATERIAL NO.	WH-201-10BR01W3-L22-R	WIF119007	A1
4	→	9	→	X.X	±0.20				2019.03.16				
3	→	8	→	X.XX	±0.10								
2	34.4 → 33.9 2020.12.07	7	→	ANGLES	±1°								
1	28.2 → 28.4 2020.12.07	6	→	LEGION ELECTRONIC & HARDWARE CO., LTD.									

