

Operation: SMT/立贴式 中型平头 自锁按键开关 [操作力可定制]



LTEM NO.: PS-2158S-P (Series)

(L5.8×W5.8×H7.5mm PUSH-SWITCH)

表面贴装 SMT

正向操作

精密部品 NICETY

可靠 STABILIZE






適合環保 RoHS

Technical parameter

LEVEL		A[better product]	B[average product]
PROJECT			
Electrical Properties	Contact Rating	0.5A, 24V DC	
	Initial Contact Resistance	50mΩ max.	
	Insulation Resistance	100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
Durable Performance	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minut
	There No Load	15,000 Cycles	10,000 Cycles
	Rated Load	12,000 Cycles	85,000 Cycles
	Storage temp.	-40℃~+85℃(Operating Temp:)	
	Operating Force	3. 6N. (1N. =100gram-force)	
	Heat Rrsistance	IR Reflow:255℃, 5sec. Manual :350℃, 3sec.	

Unit:mm

CIRCUIT DIAGRAM

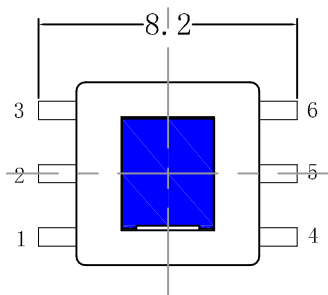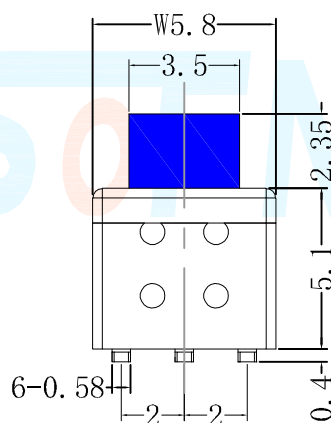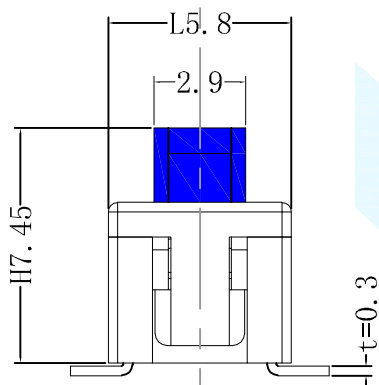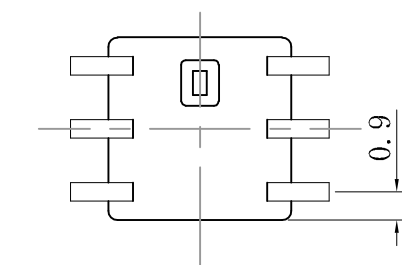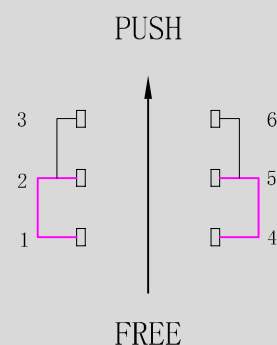

P.C.B LAYOUT

