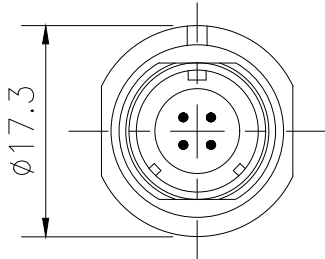
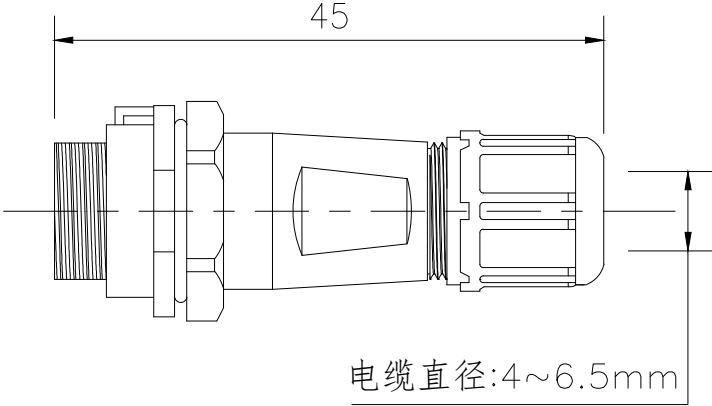


1		2		3		4		5		6				
A	芯位									芯数	2P	3P	4P	5P
		2P		3P		4P		5P		工作电压 (V)	180	180	125	125
										额定电流 (A)	5	5	3	3
										耐压 (V)	1000	1000	1000	1000
										接触电阻 (mΩ)	5	5	10	10

B			B
C	C		

材料和技术参数		GENERAL TOLERANCE (UNLESS SPECIFIED) ≤10 ±0.1 ＜10~≤20 ±0.2 ＜20~≤50 ±0.5 Angle ±1°  THIRD ANGLE	DWN DATE		2022.10.10	TITLE JH1111P 塑料组装式针型插头
接插方式:	螺纹锁紧		L.L			
外壳材料:	热塑性塑料PC, PA66 防火等级: V-0		CHK DATE			
绝缘体:	热塑性塑料PPS, 耐高温260° C		APVD DATE			
接触件材料:	铜, 镀金					
电缆直径:	4-6.5 mm					
防护等级:	IP68					
接插次数:	500		UNIT REV			
温度范围:	-40°C ~ +85°C		MM A			
绝缘电阻:	2000 MΩ		SIZE SHEET			
		A4 1 OF 1		PART NO		
				DRAWING NO		