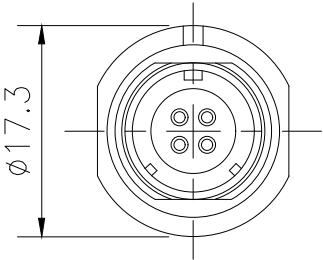
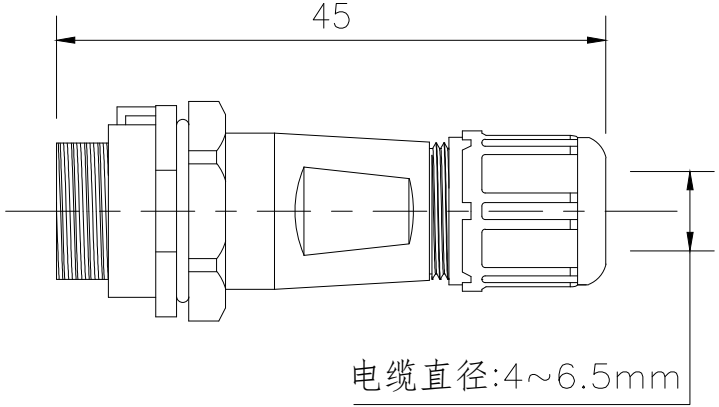
 


1		2		3		4		5		6				
A	芯位									芯数	2P	3P	4P	5P
										工作电压 (V)	180	180	125	125
										额定电流 (A)	5	5	3	3
										耐压 (V)	1000	1000	1000	1000
										接触电阻 (mΩ)	5	5	10	10

B				B
C				C

材料和技术参数		GENERAL TOLERANCE (UNLESS SPECIFIED) ≤10 ±0.1 ＜10~≤20 ±0.2 ＜20~≤50 ±0.5 Angle ±1°  THIRD ANGLE	DWN DATE L.L 2022.10.10		
接插方式:	螺纹锁紧		CHK DATE		
外壳材料:	热塑性塑料PC, PA66 防火等级: V-0		APVD DATE		
绝缘体:	热塑性塑料PPS, 耐高温260° C		TITLE		JH1111S 塑料组装式孔型插头
接触件材料:	铜, 镀金		UNIT REV		
电缆直径:	4-6.5 mm		MM A		
防护等级:	IP68		SIZE SHEET		
接插次数:	500		A4 1 OF 1		PART NO
温度范围:	-40°C ~ +85°C				DRAWING NO
绝缘电阻:	2000 MΩ				