


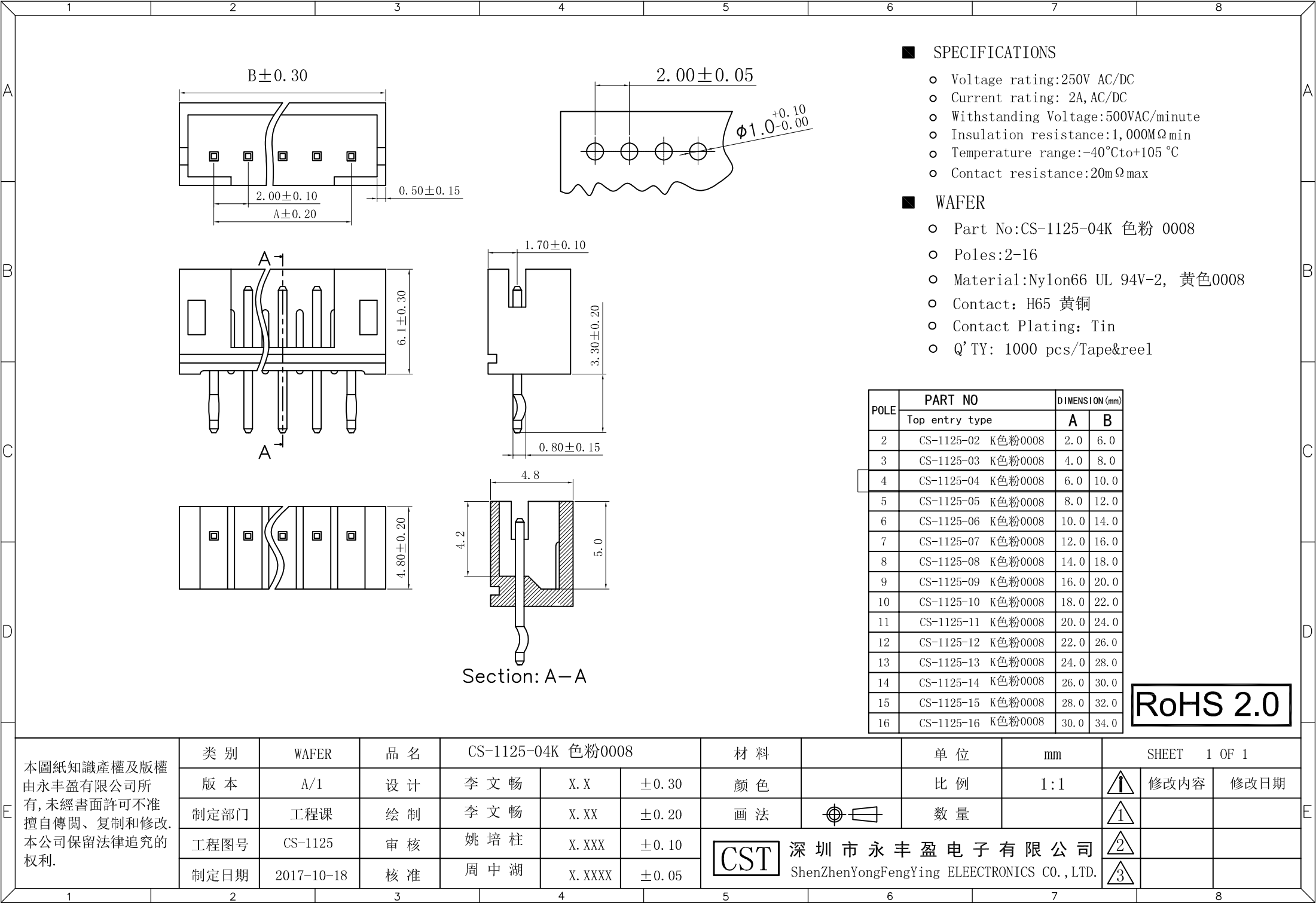

SPECIFICATIONS

- Voltage rating:250V AC/DC
- Current rating: 2A, AC/DC
- Withstanding Voltage:500VAC/minute
- Insulation resistance:1,000M Ω min
- Temperature range:-40°Cto+105 °C
- Contact resistance:20m Ω max

WAFER

- Part No:CS-1125-04K 色粉 0008
- Poles:2-16
- Material:Nylon66 UL 94V-2, 黄色0008
- Contact: H65 黄铜
- Contact Plating: Tin
- Q' TY: 1000 pcs/Tape&reel

RoHS 2.0

本圖紙知識產權及版權由永丰盈有限公司所有, 未經書面許可不准擅自傳閱、复制和修改. 本公司保留法律追究的权利.