


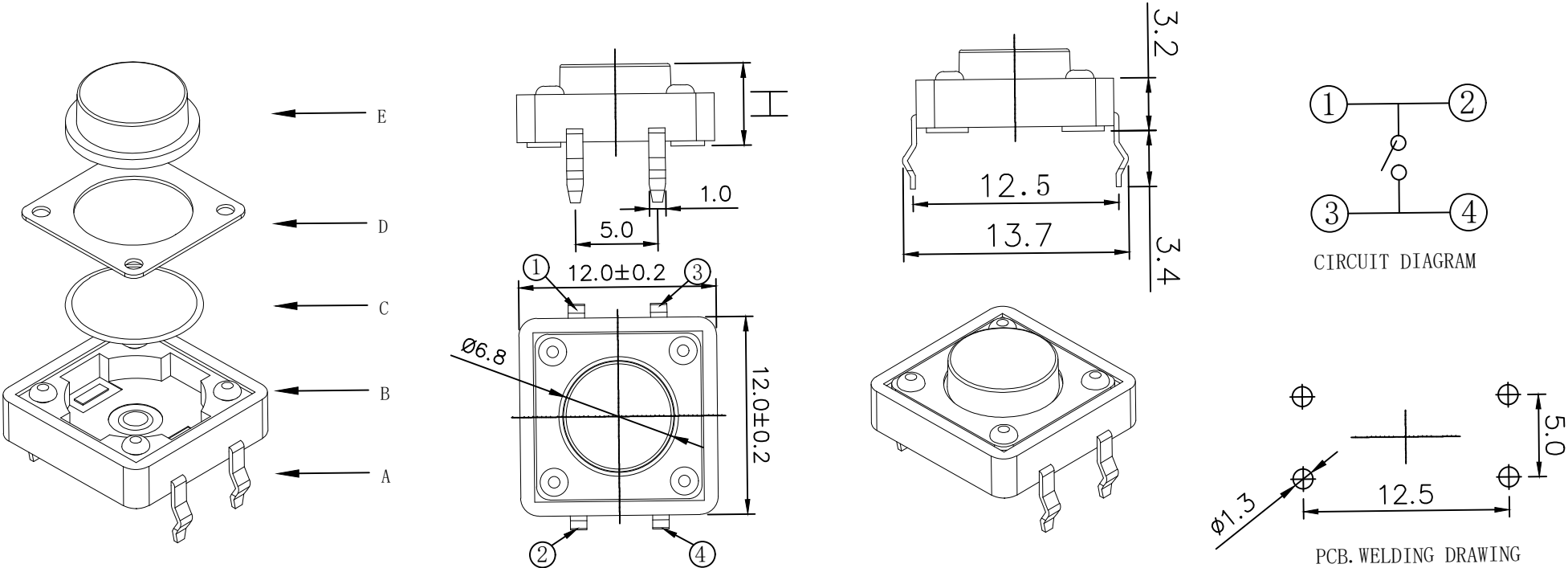

Specification

Operating Life	100,000
Contact rating	50mA@12V DC.
Insulation resistance	100mΩ min.
Contact resistance	100mΩ max. initial.
Dielectric Strength	250 V AC(1mn)
Travel	0.3±0.1mm
Storage Temperature	- 30° C to 85° C

Mechanical

E	Button	PPA	1	Black
D	COVER	Brass	1	Cleaning
C	DOME	Stainless Steel	1	Plated Ag
B	HOUSING	PPA	1	Black
A	PIN	PHOSPHOR BRONZE	1	Plated Ag
ITEM	DESCRIPTION	MATERIAL	QTY	FINISH/COLOR

Type	Operating Force (gf)	Height (mm)	Button	Leads Shape (J, G, T)	Ground pin (0, 1)	Page (option (0, 1))
YTS1B001	250±50	Q 15.0	B (BLACK)	T	0	0
		P 13.0				
		O 12.0				
		N 11.0				
		M 10.0				
		L 9.0				
		K 8.5				
		J 8.0				
		H 7.5				
		G 7.0				
YTS1B001	160±50	F 6.5	B (BLACK)	T	0	0
		E 6.0				
		D 5.5				
		C 5.0				
		B 4.5				
		A 4.3				
		A 4.3				

X. ±0.50	X. ° ±2°	UNITS mm
.X ±0.30	.X° ±1°	
.XX ±0.10	.XX° ±0.5°	MAT'L
.XXX ±0.05		
THESE DRAWINGS AND SPECIFICATIONS ARE THE PROPERTY OF YIYUAN TECHNOLOGY CO.,LTD AND SHALL NOT BE REPRODUCED, COPIED OR USED IN ANY MANNER WITHOUT THE PRIOR WRITTEN CONSENT OF YIYUAN TECHNOLOGY CO.,LTD Email at info@yiyuanswitches.com		FINISH
		Q'TY



深圳市怡远科技有限公司
SHENZHEN YIYUAN TECHNOLOGY CO., LTD

PART NO.
YTS1B001

 
APPD: ROGER

CHKD: ROC

DR: BILLY WANG 2020/08/21

TITLE:
TACTILE SWITCH 12x12

DWG NO.:
YTS1B001



SCALE	SHEET	REV.
1/1	1/1	A1

Packaging:
1,000 pieces for bulks