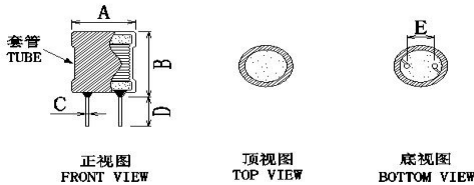


客户编码				发行日期		2023/3/31		
客户物料编码				客户规格型号		10*16-560UH-0.4线		
样如物料编码		XR10*16-561K-L		样如规格型号		XR10*16-561K-L		
送样数量		0PCS		送样日期		2023-03-23		
外观尺寸 mm 				A		12.0 MAX	E	5.0±0.5
				B		20.0 MAX		
				C		0.75±0.1		
				D		15.0±2.0		
				标识				
				原理图				
绕线结构表								
绕组	起始	结束	漆包线	圈数		绕制方式		
N1	S	F	2UEW-0.4mm	119.5TS	圈数参考	平整密绕		
注意事项								
1、起线，收线入磁芯槽口 2、绕线要均匀平整，不能大小边 3、用黑色少字套管								
测试项目		电性范围		测试条件		测试仪器	参考值	
电感量L		560uH±10%		at 25℃ 1KHz/0.25V		TH-2829A	543.30	
直流电阻DCR		0.55Ω MAX		at 25℃ 1KHz/0.25V		TH-2829A	0.42	
饱和电流Isat		L≥L0*90%		at 25℃ DC 1A 1KHz/0.25V		TH2829A		
物料	规格型号			备注		生产厂家	用量	
导针	0.75mm CP线					BAICHUAN	Kg	
磁芯	H3M DR2W10*16 5-11-5			镁锌材质		HUAZHONG	K	
漆包线	QA-1(2UEW)/155					CHANGDA	Kg	
套管	Φ10*15mm UL黑色扁管					XINGQI	m	
	Φ11mm UL黑色扁管					XINGQI	m	
接脚胶	FK661 黑胶 无卤					QI FU	Kg	
无铅锡	无铅锡条					SONGBEN	Kg	
作业流程								
产品包装								
包装代码								
包装标识								
包装物料								
包装尺寸								
包装说明								
标识示意图				包装示意图				
</								