

电气特性:Electrical:

1. 额定电流: Current Rating

1.5A/contact terminal

2.额定电压: Voltage Rating

30V DC

3.接触电阻: Contact Resistance

30 milliohms MAX

4.耐电圧: Dielectric Withstanding Voltage:

500 V AC AT Sea Level

5. 绝缘阻抗: Insulation Resistance:

1000MEGA ohms MIN

物理性能: Mechanical:

1. 插拔力：Connector Mate and Unmate Force

Mate force:3.57kgf(MAX)

Ummate force:0.7kgf(MIN)

2.端子保持力：Terminal Retention

1.2kgf(MIN)

3. 寿命: 1500 次

原材料:Material:

1. 塑胶:Housing: PBT NC

2.端子:Contact:Copper Alloy C2680

3. 外賣: Shell: SPCC


申鍍: Finish:

1 端子Contact: Au 0.7u" Plated on contact area

Tin50u" Plated on solder area

Nickel 50u" Plated underplating over all.

2 外壳Shell: Nickel 50u"Min plating over all.

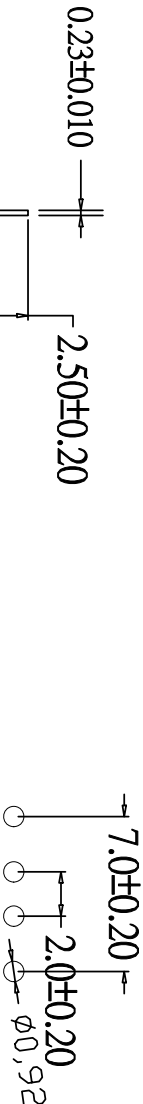

深圳市精拓金电子有限公司