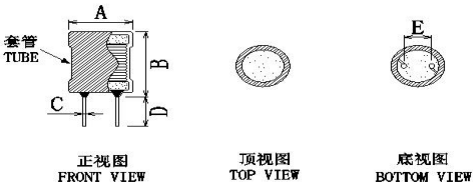


客户编码		发行日期		2023/3/23				
客户物料编码		客户规格型号		9*12-180UH-0.4线				
样如物料编码		样如规格型号		XR9*12-181K-L				
送样数量		送样日期		2023-03-22				
外观尺寸 mm 				A	10.5 MAX	E	5.0±0.5	
				B	15.0 MAX			
				C	0.65±0.1			
				D	15.0±2.0			
				标识				
				原理图				
								
绕线结构表								
绕组	起始	结束	漆包线	圈数		绕制方式		
N1	S	F	2UEW-0.4mm	71.5TS	圈数参考	平整密绕		
注意事项								
1、起线，收线入磁芯槽口 2、绕线要均匀平整，不能大小边 3、用黑色少字套管								
测试项目		电性范围		测试条件		测试仪器		参考值
电感量L		180uH±10%		at 25℃ 1KHz/0.25V		TH2829A		185.00
直流电阻DCR		0.29Ω MAX		at 25℃ 1KHz/0.25V		TH2829A		0.22
饱和电流Isat		L≥L0*90%		at 25℃ DC 600mA 1KHz/0.25V		TH2829A		
物料	规格型号			备注		生产厂家		用量
磁芯	R250 DR2W9*12 4-7.8-5			镁锌材质		LIANXING		K
漆包线	2UEW(155度)					GANYUE		Kg
导针	0.65mm CP线					BAICHUAN		Kg
套管	Φ10.0mm UL黑色扁管					YIMING		m
接脚胶	FK661 黑胶 无卤					QI FU		Kg
无铅锡	无铅锡条					SONGBEN		Kg
作业流程								
产品包装								
包装代码								
包装标识								
包装物料								
包装尺寸								
包装说明								
标识示意图				包装示意图				
				</				