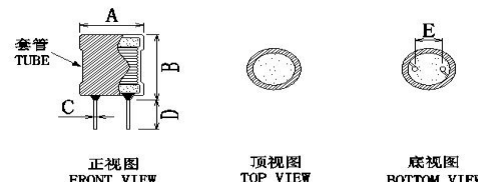
 


|                                        |                                                                                   |                                                                                                                                        |            |                                                                                     |        |         |     |    |    |    |     |
|----------------------------------------|-----------------------------------------------------------------------------------|----------------------------------------------------------------------------------------------------------------------------------------|------------|-------------------------------------------------------------------------------------|--------|---------|-----|----|----|----|-----|
| 客户编码                                   |                                                                                   |                                                                                                                                        | 发行日期       | 2023/3/31                                                                           |        |         |     |    |    |    |     |
| 客户物料编码                                 |                                                                                   |                                                                                                                                        | 客户规格型号     | 10*16-390UH-0.4线                                                                    |        |         |     |    |    |    |     |
| 祥如物料编码                                 | XR10*16-391K-L                                                                    |                                                                                                                                        | 祥如规格型号     | XR10*16-391K-L                                                                      |        |         |     |    |    |    |     |
| 送样数量                                   | 0PCS                                                                              |                                                                                                                                        | 送样日期       | 2023-03-23                                                                          |        |         |     |    |    |    |     |
| 外观尺寸 mm                                |  |                                                                                                                                        | A          | 12.0 MAX                                                                            | E      | 5.0±0.5 |     |    |    |    |     |
|                                        |                                                                                   |                                                                                                                                        | B          | 20.0 MAX                                                                            |        |         |     |    |    |    |     |
|                                        |                                                                                   |                                                                                                                                        | C          | 0.75±0.1                                                                            |        |         |     |    |    |    |     |
|                                        |                                                                                   |                                                                                                                                        | D          | 15.0±2.0                                                                            |        |         |     |    |    |    |     |
|                                        |                                                                                   |                                                                                                                                        | 标识         |                                                                                     |        |         |     |    |    |    |     |
|                                        |                                                                                   |                                                                                                                                        | 原理图        |  |        |         |     |    |    |    |     |
| 绕线结构表                                  |                                                                                   |                                                                                                                                        |            |                                                                                     |        |         |     |    |    |    |     |
| 绕组                                     | 起始                                                                                | 结束                                                                                                                                     | 漆包线        | 圈数                                                                                  | 绕制方式   |         |     |    |    |    |     |
| N1                                     | S                                                                                 | F                                                                                                                                      | 2UEW-0.4mm | 99.5TS                                                                              | 圈数参考   |         |     |    |    |    |     |
|                                        |                                                                                   |                                                                                                                                        |            |                                                                                     | 平整密绕   |         |     |    |    |    |     |
|                                        |                                                                                   |                                                                                                                                        |            |                                                                                     |        |         |     |    |    |    |     |
| 注意事项                                   |                                                                                   |                                                                                                                                        |            |                                                                                     |        |         |     |    |    |    |     |
| 1、起线，收线入磁芯槽口 2、绕线要均匀平整，不能大小边 3、用黑色少字套管 |                                                                                   |                                                                                                                                        |            |                                                                                     |        |         |     |    |    |    |     |
| 测试项目                                   | 电性范围                                                                              | 测试条件                                                                                                                                   |            | 测试仪器                                                                                | 参考值    |         |     |    |    |    |     |
| 电感量L                                   | 390uH±10%                                                                         | at 25℃ 1KHz/0.25V                                                                                                                      |            | TH-2829A                                                                            | 385.70 |         |     |    |    |    |     |
| 直流电阻DCR                                | 0.43Ω MAX                                                                         | at 25℃ 1KHz/0.25V                                                                                                                      |            | TH-2829A                                                                            | 0.33   |         |     |    |    |    |     |
| 饱和电流Isat                               | L ≥ L0*90%                                                                        | at 25℃ DC 1.3A 1KHz/0.25V                                                                                                              |            | TH2829A                                                                             |        |         |     |    |    |    |     |
|                                        |                                                                                   |                                                                                                                                        |            |                                                                                     |        |         |     |    |    |    |     |
| 物料                                     | 规格型号                                                                              | 备注                                                                                                                                     |            | 生产厂家                                                                                | 用量     |         |     |    |    |    |     |
| 导针                                     | 0.75mm CP线                                                                        |                                                                                                                                        |            | BAICHUAN                                                                            | Kg     |         |     |    |    |    |     |
| 磁芯                                     | H3M DR2W10*16 5-11-5                                                              | 镁锌材质                                                                                                                                   |            | HUAZHONG                                                                            | K      |         |     |    |    |    |     |
| 漆包线                                    | QA-1(2UEW)/155                                                                    |                                                                                                                                        |            | CHANGDA                                                                             | Kg     |         |     |    |    |    |     |
| 套管                                     | Φ10*15mm UL黑色扁管                                                                   |                                                                                                                                        |            | XINGQI                                                                              | m      |         |     |    |    |    |     |
|                                        | Φ11mm UL黑色扁管                                                                      |                                                                                                                                        |            | XINGQI                                                                              | m      |         |     |    |    |    |     |
| 接脚胶                                    | FK661 黑胶 无卤                                                                       |                                                                                                                                        |            | QI FU                                                                               | Kg     |         |     |    |    |    |     |
| 无铅锡                                    | 无铅锡条                                                                              |                                                                                                                                        |            | SONGBEN                                                                             | Kg     |         |     |    |    |    |     |
| 作业流程                                   |                                                                                   |                                                                                                                                        |            |                                                                                     |        |         |     |    |    |    |     |
| 产品包装                                   |                                                                                   |                                                                                                                                        |            |                                                                                     |        |         |     |    |    |    |     |
| 包装代码                                   |                                                                                   |                                                                                                                                        |            |                                                                                     |        |         |     |    |    |    |     |
| 包装标识                                   |                                                                                   |                                                                                                                                        |            |                                                                                     |        |         |     |    |    |    |     |
| 包装物料                                   |                                                                                   |                                                                                                                                        |            |                                                                                     |        |         |     |    |    |    |     |
| 包装尺寸                                   |                                                                                   |                                                                                                                                        |            |                                                                                     |        |         |     |    |    |    |     |
| 包装说明                                   |                                                                                   |                                                                                                                                        |            |                                                                                     |        |         |     |    |    |    |     |
| 标识示意图                                  |                                                                                   | 包装示意图                                                                                                                                  |            |                                                                                     |        |         |     |    |    |    |     |
|                                        |                                                                                   | <table border="1"> <tr> <td>制表</td> <td>黄禾香</td> </tr> <tr> <td>审核</td> <td>饶平</td> </tr> <tr> <td>确认</td> <td>钟翠兰</td> </tr> </table> |            |                                                                                     |        | 制表      | 黄禾香 | 审核 | 饶平 | 确认 | 钟翠兰 |
| 制表                                     | 黄禾香                                                                               |                                                                                                                                        |            |                                                                                     |        |         |     |    |    |    |     |
| 审核                                     | 饶平                                                                                |                                                                                                                                        |            |                                                                                     |        |         |     |    |    |    |     |
| 确认                                     | 钟翠兰                                                                               |                                                                                                                                        |            |                                                                                     |        |         |     |    |    |    |     |