



产品名称
Product name

▶ 1. 27PH H1.0 2*nPIN 双
▶ 排SMT W3.4 PC5.5 PA4.5
PB1.5 L7.2

产品应用场景
Product application scenario

▶ 电子通讯/数码产品/家用电器
▶ 外围设备/汽车/医疗设备等.
▶ Electronic communication/
▶ digital products/household
▶ appliance peripherals/
▶ AuTomobile/medical equipment,
▶ etc

产品参数/Product parameters
额定电流(Rated current): 1A AC/DC
盐雾实验 (Life Test) : 48 hours
接触电阻 (Contact Resistance) :20mΩ
绝缘电阻 (Insulation Resistance) :1000MΩ min.
耐电压 (Withstand voltage) : AC 500V
工作温度 (Operating Temperature) :-40° C to 105°
防火等级 (Fire rating) : Polyester (UL94V-0)
触点电镀 (Dielectric Strength) :Gold Flash
耐高温范围/时长 (High temperature resistance range/duration) :260° C for5seconds
包装方式 (Packaging method) :袋装)

材质/MATERIALS:			
No.	名称/NAME	材料/MATERIAL	表面处理/颜色 Surfacetreatment/color
①	端子/Terminal	Brass/C2680	镀金 gold-plating
②	塑胶/plastic cement	PBT/PA6T	黑色 Black

产品PIN位示意图/Schematic diagram of product PIN														
No.of	DIM. A	DIM. B	No. of	DIM. A	DIM. B	No. of	DIM. A	DIM. B	No. of	DIM. A	DIM. B	No. of	DIM. A	DIM. B
1	—	—	2*11P	12.70	13.97	2*21P	25.40	26.67	2*31P	38.10	39.37	2*41P	50.80	52.07
2*2P	1.27	2.54	2*12P	13.97	15.24	2*22P	26.67	27.94	2*32P	39.37	40.64	2*42P	52.07	53.34
2*3P	2.54	3.81	2*13P	15.24	16.51	2*23P	27.94	29.21	2*33P	40.64	41.91	2*43P	53.34	54.61
2*4P	3.81	5.08	2*14P	16.51	17.78	2*24P	29.21	30.48	2*34P	41.91	43.18	2*44P	54.61	55.88
2*5P	5.08	6.35	2*15P	17.78	19.05	2*25P	30.48	31.75	2*35P	43.18	44.45	2*45P	55.88	57.15
2*6P	6.35	7.62	2*16P	19.05	20.32	2*26P	31.75	33.02	2*36P	44.45	45.72	2*46P	57.15	58.42
2*7P	7.62	8.89	2*17P	20.32	21.59	2*27P	33.02	34.29	2*37P	45.72	46.99	2*47P	58.42	59.69
2*8P	8.89	10.16	2*18P	21.59	22.86	2*28P	34.29	35.56	2*38P	46.99	48.26	2*48P	59.69	60.96
2*9P	10.16	11.43	2*19P	22.86	24.13	2*29P	35.56	36.83	2*39P	48.26	49.53	2*49P	60.96	62.23
2*10P	11.43	12.70	2*20P	24.13	25.40	2*30P	36.83	38.10	2*40P	49.53	50.80	2*50P	62.23	63.50

产品编号/Product No

HB

P H *

1 2

* * *

3

* * *

4

* *

5 6

* *

7

* *

8 9

1: Series No:
PH-Pin Header

2:焊接板类型/Welding Board Type:
9-双排贴片/ SMT Type with
Locating Peg

3:产品间距/Product spacing
127-1.27mm
200-2.00mm
254-2.54mm

4: PIN位/PIN bit
2*2P-22P


5: 颜色/Color:
B-Black

6:材料/Material
1-PBT 2-PA6T

7:触点电镀/Contact Plating
GO-Gold Flash


8:包装方式/Packgin Method
P-袋装/PE B-盒装/BOX
T-管装/Tubing W-卷带/winding


9: Serial Code

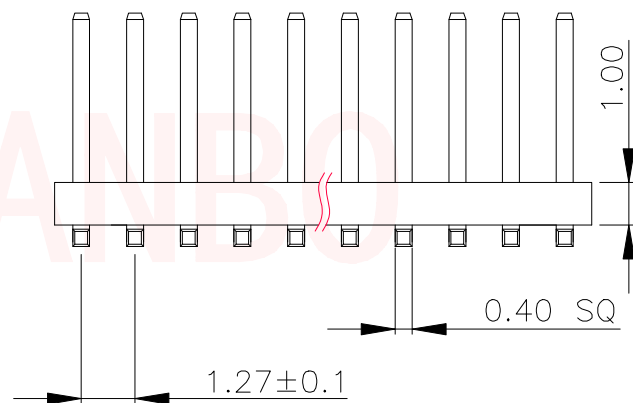



让世界连接更清晰

 ▶ ▶ ▶





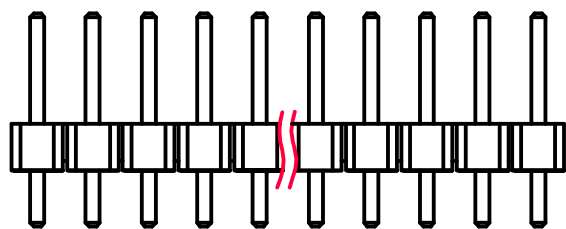

产品

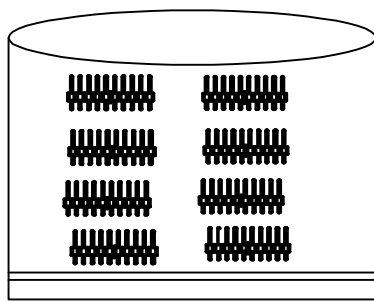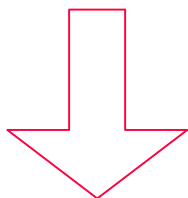

3#胶袋: 16*18cm

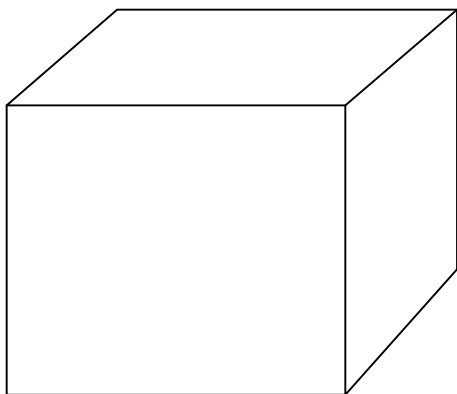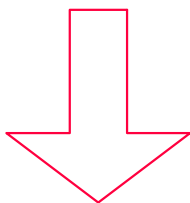

纸箱