
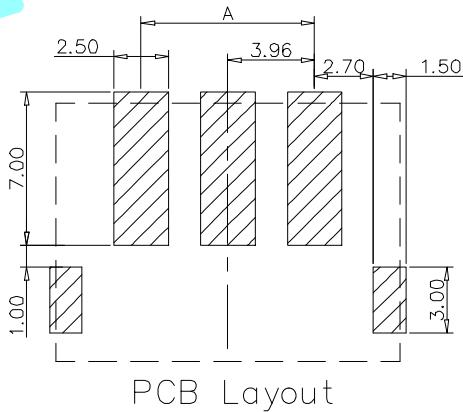
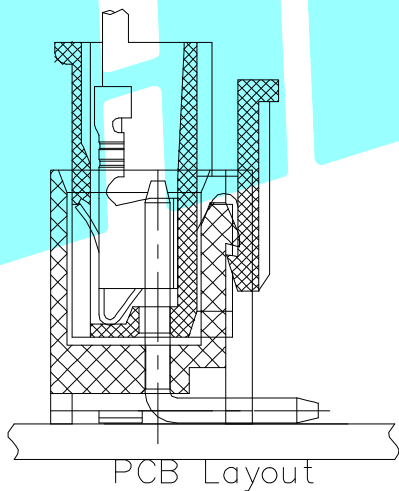
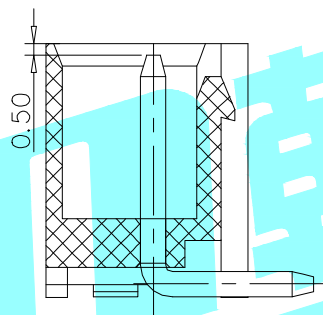


Electrical properties

- 1. Current rating: 7A AC\DC (AWG #26)
- 2. Voltage rating: 250V AC\DC
- 3. Temperature range: -25°C~+85°C
- 4. Contact resistance: Initial value/300mΩ max
- 5. Insulation resistance: 1000MΩmin
- 6. Withstanding voltage: 1000V AC/ minute
- 7. Applicable wire: AWG #18 to #22

Environmental controls

- 1. Banned contains SS – 00259 are restricted substances.
- 2. The corresponding issued by SGS or ITS icp-aes data, Not the material in a list, and validity.

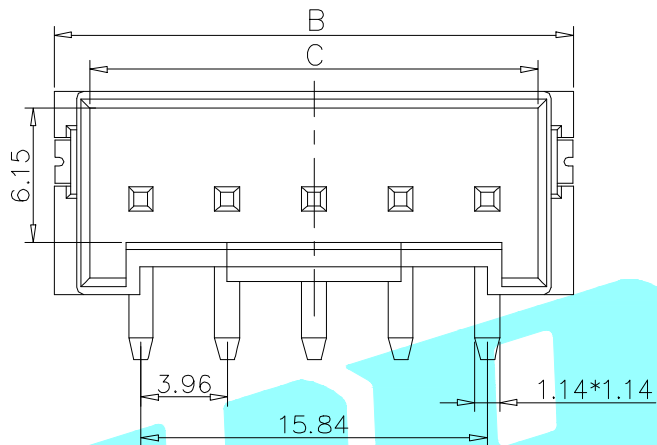

Pin	A	B	C
2	3.96	11.88	8.6
3	7.92	15.84	12.56
4	11.88	19.8	16.52
5	15.84	23.76	20.48
6	19.8	27.72	24.44
7	23.76	31.68	28.4
8	27.72	35.64	32.36
9	31.68	39.6	36.32
10	35.64	43.56	40.28

APPROVALS		DATE	HRD 韩睿® ELECTRONICS CO.,LTD		
DRAWN	LIUCAN	2022.4.16			
CHECKED			TITLE:	Bar Connector Series	
APPROVALS			PART NO.	3.96T-nP-WV	
TOLERANCES ARE	30~以上	±0.30	ANGLE	UNIT: mm	SCALE: 1:1
	10~30	±0.20			
	5~10	±0.15			
	~ 5	±0.10			
			±2°	DRAWING NO.	
					PROJ: 
					SHEET 1 OF 1

	A		NEW			
ECN NO.	REV.	DATE.	DESCRIPTION.	CHANGE.	CHECK.	APPRO.