

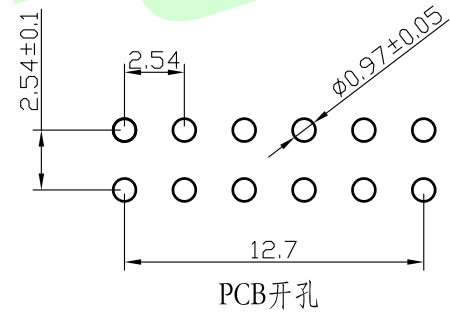
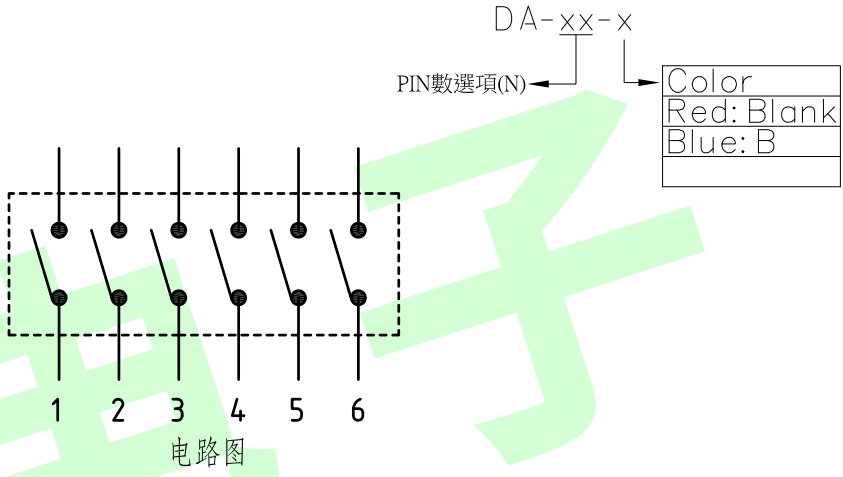
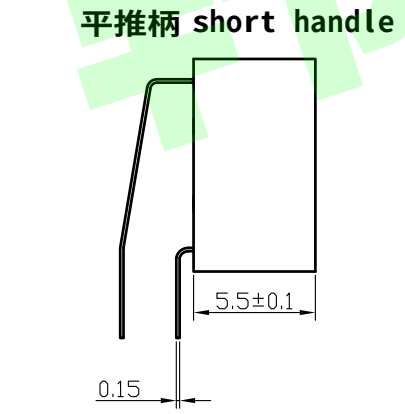
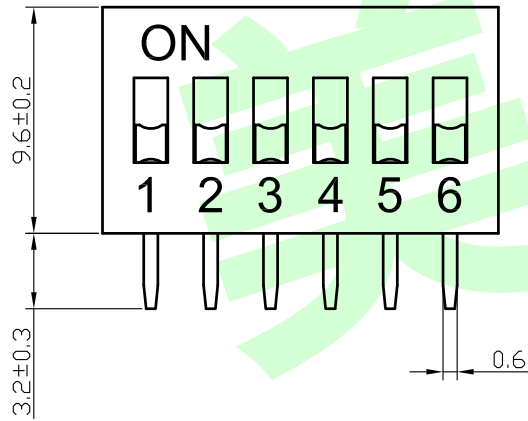
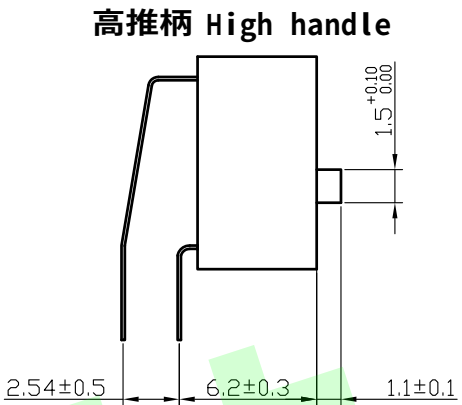


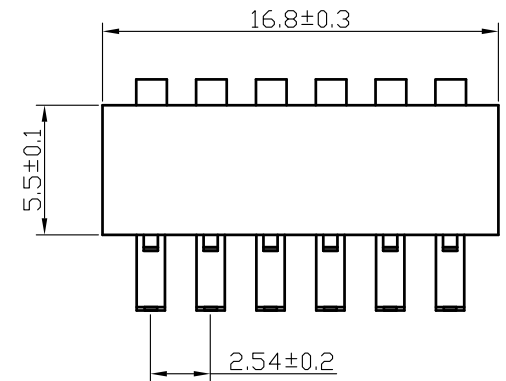

PART NO.	A	B
DA-01-x	3.54	
DA-02-x	6.64	2.54
DA-03-x	9.18	5.08
DA-04-x	11.72	7.62
DA-05-x	14.26	10.16
DA-06-x	16.80	12.70
DA-07-x	19.34	15.24
DA-08-x	21.88	17.78
DA-09-x	24.42	20.32
DA-10-x	26.96	22.86
DA-11-x	29.50	25.40
DA-12-x	32.04	27.94

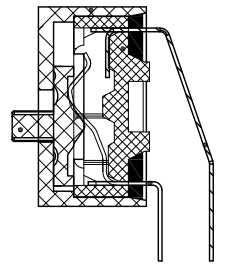

开关特性：
1、电流规格：切换时：25mA@24VDC
2、接触电阻：50MΩ Max
3、绝缘电阻：100MΩ@250VDC
4、绝缘强度：500VAC/1min
5、操作力度：1000gf Max
6、电气寿命：2000次
7、适用温度：-20℃ to 80℃ (无结冰)
8、焊接要求：
手工焊接：320℃不超过2秒 (30瓦烙铁max.)
波峰焊：260℃ 不超过5秒
在焊接和清洁过程中开关处于断开状态
9、开关出厂处于断开状态

材料：
盖子：PBT塑料 (红色或蓝色)
底座：PBT塑料 (黑色)
操作杆：PBT塑料 (白色)
灌密封胶：环氧树脂
端子：镀锡磷青铜，触点
镀金3μ" (或整体镀金1μ")
电镀：(全金/半锡金)

										Dongguan Usakro Electronic Technology Co., Ltd.													
				angle		±2°				design		date				name		DA-06-B					
				10~30		±0.30				Review		date											
				5~10		±0.20				Approved		date						name					
				~ 5		±0.10		Drawing number:															
modify		Review		Approved		Tolerance not specified		Proportion		1:1		unit		mm		gape		number		A4			