
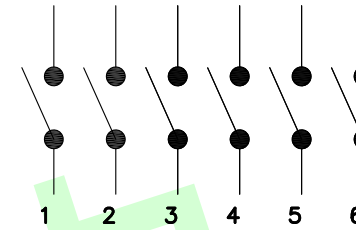


高推柄 High handle




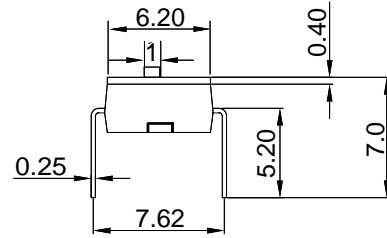


DSIC-C-XX - X

PIN數選項(N)

Packing :  
R: Reel  
T: Tube

平推柄 Hhort handle

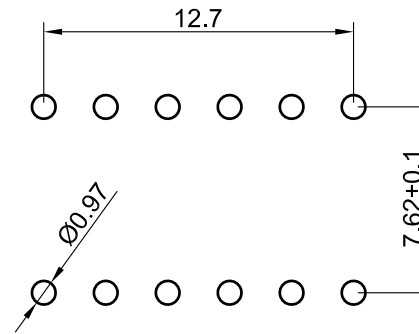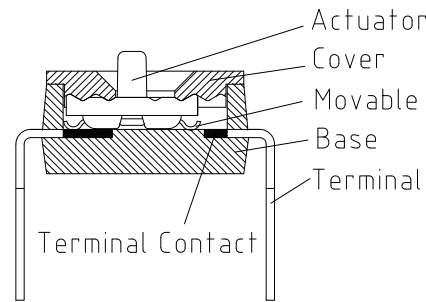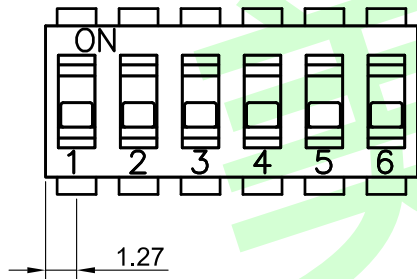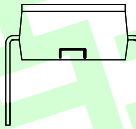

| Poles(N) | A (mm) |
|----------|--------|
| 01       | 2.54   |
| 02       | 5.08   |
| 03       | 7.62   |
| 04       | 10.16  |
| 05       | 12.70  |
| 06       | 15.24  |
| 07       | 17.78  |
| 08       | 20.32  |
| 09       | 22.86  |
| 10       | 25.40  |
| 12       | 30.48  |

规格：

电气寿命：  
无切换：100mA@50VDC  
切换：25mA@24VDC  
绝缘电阻：100M @250VDC  
接触电阻：50M max  
操作力度：500gf max  
使用温度：-30 to 85 (no ice)

材料：

开关盖：PPS UL 94-V0  
开关体：PPS UL 94-V0  
操作杆：PA46 UL 94-V0  
弹片：镀金铍铜  
端子：镀金黄铜

Dongguan Usakro Electronic Technology Co., Ltd.

|                 |        |          |                         |
|-----------------|--------|----------|-------------------------|
| design          | date   | name     | DSIC-C-06               |
| Review          | date   |          |                         |
| Approved        | date   | name     |                         |
| Drawing number: |        |          |                         |
| modify          | Review | Approved | Tolerance not specified |
| Proportion      | 1:1    | unit     | mm                      |
| gape number     |        |          | A4                      |