
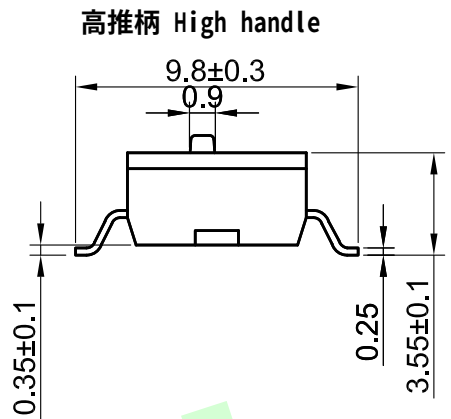
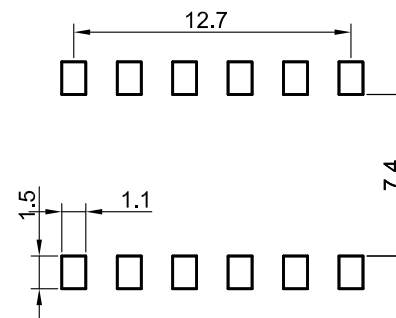
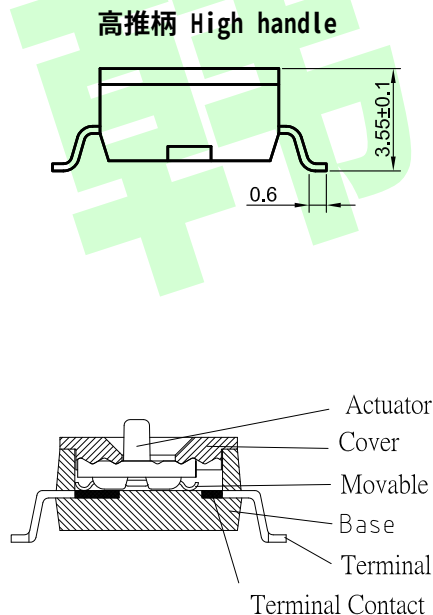


DSIC-T-XX - X

PIN數選項(N)

Packing :

R: Reel
T: Tube

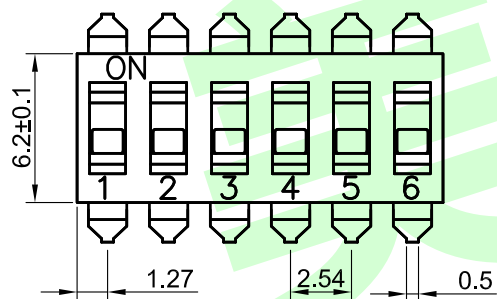

Poles(N)	A (mm)
01	2.54
02	5.08
03	7.62
04	10.16
05	12.70
06	15.24
07	17.78
08	20.32
09	22.86
10	25.40
12	30.48

规格：

电气寿命：

无切换：100mA@50VDC

切换：25mA@24VDC

绝缘电阻：100MΩ@250VDC

接触电阻：50MΩ max

绝缘强度：500VAC/1min

操作力度：500gf max

使用温度：-30℃ to 85℃ (no ice)

材料：

开关盖：PPS UL 94-V0

开关体：PPS UL 94-V0

操作杆：PA46 UL 94-V0

弹片：镀金铍铜

端子：镀金黄铜

Dongguan Usakro Electronic Technology Co., Ltd.

			angle	±2°		design	date		name	DSIC-T-06
			10~30	±0.30		Review	date			
			5~10	±0.20		Approved	date			
			~ 5	±0.10		Drawing number:				
modify	Review	Approved	Tolerance not specified	Proportion	1:1	unit	mm	gape number		A4