
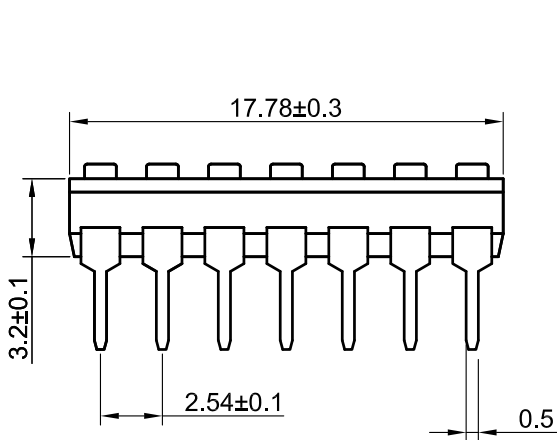
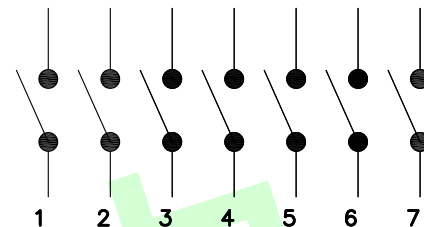
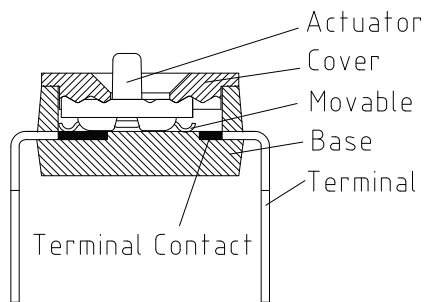
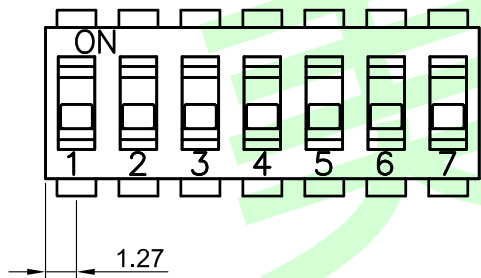


平推柄 Hhort handle

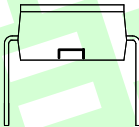


DSIC-C-XX - X

PIN數選項(N)

Packing :

R: Reel
T: Tube

Poles(N)	A (mm)
01	2.54
02	5.08
03	7.62
04	10.16
05	12.70
06	15.24
07	17.78
08	20.32
09	22.86
10	25.40
12	30.48

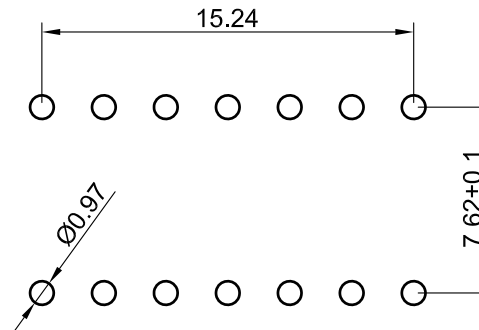

规格：

电气寿命：
无切换：100mA@50VDC
切换：25mA@24VDC
绝缘电阻：100MΩ@250VDC
接触电阻：50MΩ max
操作力度：500gf max
使用温度：-30 to 85 (no ice)

材料：

开关盖：PPS UL 94-V0
开关体：PPS UL 94-V0
操作杆：PA46 UL 94-V0
弹片：镀金铍铜
端子：镀金黄铜

Dongguan Usakro Electronic Technology Co., Ltd.

			angle	±2°		design		date		name	DSIC-C-07
			10~30	±0.30		Review		date			
			5~10	±0.20		Approved		date			
			~ 5	±0.10		Drawing number:					
modify	Review	Approved	Tolerance not specified	Proportion	1:1	unit	mm	gape number		A4	