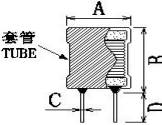


客户编码		发行日期	2023/3/31																													
客户物料编码		客户规格型号	10*16-33UH-0.5线																													
样如物料编码	XR10*16-330K-L	样如规格型号	XR10*16-330K-L																													
送样数量	0PCS	送样日期	2023-03-23																													
外观尺寸 mm  正视图 FRONT VIEW 顶视图 TOP VIEW 底视图 BOTTOM VIEW <tr><td>A</td><td>12.0 MAX</td><td>E</td><td colspan="2">5.0±0.5</td></tr> <tr><td>B</td><td>20.0 MAX</td><td></td><td colspan="2"></td></tr> <tr><td>C</td><td>0.75±0.1</td><td></td><td colspan="2"></td></tr> <tr><td>D</td><td>15.0±2.0</td><td></td><td colspan="2"></td></tr> <tr><td>标识</td><td colspan="4"></td></tr> <tr><td>原理图</td><td colspan="4"></td></tr>			A	12.0 MAX	E	5.0±0.5		B	20.0 MAX				C	0.75±0.1				D	15.0±2.0				标识					原理图				
			A	12.0 MAX	E	5.0±0.5																										
			B	20.0 MAX																												
			C	0.75±0.1																												
			D	15.0±2.0																												
			标识																													
			原理图																													

绕线结构表							
绕组	起始	结束	漆包线	圈数	绕制方式		
N1	S	F	2UEW-0.5mm	28.5TS	圈数参考	平整密绕	

注意事项
 1、起线，收线入磁芯槽口 2、绕线要均匀平整，不能大小边 3、用黑色少字套管

测试项目	电性范围	测试条件	测试仪器	参考值
电感量L	33uH±10%	at 25℃ 1KHz/0.25V	TH-2829A	32.90
直流电阻DCR	70.3mΩ MAX	at 25℃ 1KHz/0.25V	TH-2829A	54.10
饱和电流Isat	L ≥ L0*90%	at 25℃ DC 3A 1KHz/0.25V	TH2829A	
物料	规格型号	备注	生产厂家	用量
导针	0.75mm CP线		BAICHUAN	Kg
磁芯	H3M DR2W10*16 5-11-5	镁锌材质	HUAZHONG	K
漆包线	QA-1(2UEW)/155		CHANGDA	Kg
套管	Φ10*15mm UL黑色扁管 Φ11mm UL黑色扁管		XINGQI XINGQI	m m
接脚胶	FK661 黑胶 无卤		QI FU	Kg
无铅锡	无铅锡条		SONGBEN	Kg
作业流程				

产品包装					
包装代码					
包装标识					
包装物料					
包装尺寸					
包装说明					

标识示意图

包装示意图

制表	黄禾香
审核	饶平
确认	钟翠兰