

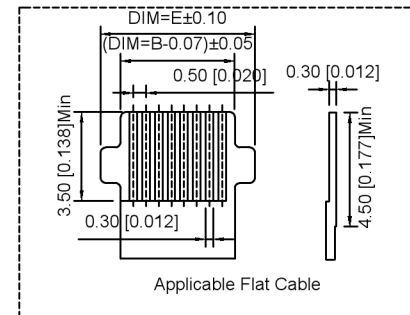
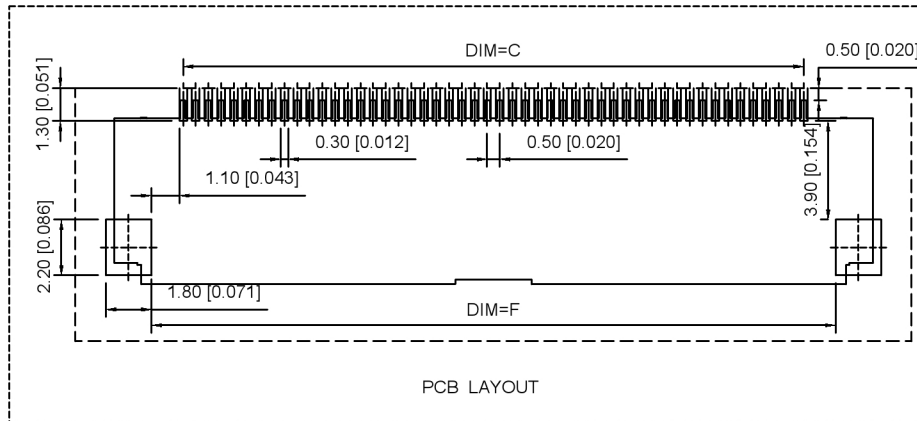
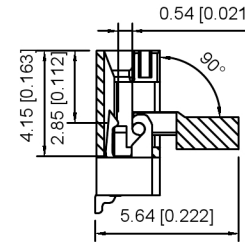
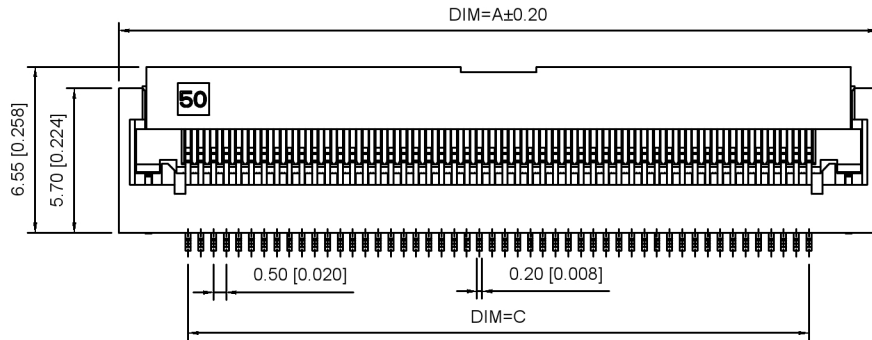
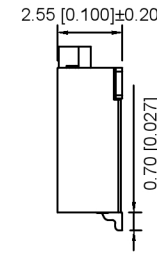


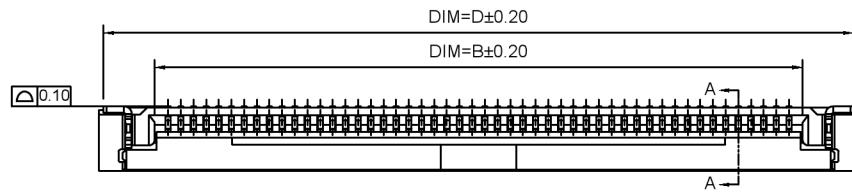

PERFORMANCE
 1:CURRENT RATING:0.5A/PIN.
 2:VOLTAGE RATING: 50V (AC/DC)
 3:CONTACT RESISTANCE: 50mΩ Max
 4:INSULATION RESISTANCE: 500MΩ Min.
 5:OPERATING TEMPERATURE:-40℃~+125℃
MATERIAL:
 1:Metal material:Terminal Copper alloy Gold plating
 Soldering lug Copper alloy Tin plating
 2:Plastic material:Rubber core LCP UL94V-0 nature
 Rear cover LCP UL94V-0 black

X05 A 255 L K XX G
 ① ② ③ ④ ⑤ ⑥ ⑦

- ① Series Name : X05=0.5 mm Pitch
- ② Operating mode:A=Flip-open cover
- ③ Height:255-H=2.55mm
- ④ Assembly style:L:Low Contact SMT Type
- ⑤ Plug the Pin&Special No:K-Belt fastener
- ⑥ Number of terminals :XX=05-80PIN
- ⑦ Plating : G:Gold Flash Over Nickel

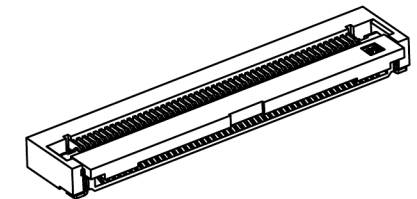

					ANGLAR	±5°
ΔX					L ≤ 4	±0.2
ΔX					4 < L ≤ 16	±0.3
ΔX					16 < L ≤ 63	±0.4
MARK					L > 63	±0.5
REVISIONS					UNSPECIFIED TOLERANCES	
www.helloxkb.com www.helloxkb.cn www.xk-dg.cn						

XKLB

XKB INDUSTRIAL PRECISION CO.,LIMITED

DSND		SCALE: N/A	MODEL TYPE: FPC CONNECTOR		
DWN		VIEW: 	PART NO.: X05A255LKXXG		
CHKD		UNIT: mm/in	DWG NO.: X-X05A255LKXXG		
APPD		SIZE: A4			
L PRECISION CO.,LIMITED			WEIGHT	SHEET	REVISION
				1/1	A0

Poles	DIM A	DIM B	DIM C	DIM D	DIM E	DIM F	Poles	DIM A	DIM B	DIM C	DIM D	DIM E	DIM F
5	7.45	3.07	2.00	7.10	4.60	4.50	42	26.45	22.07	21.00	26.10	23.60	23.50
6	7.95	3.57	2.50	7.60	5.10	5.00	44	26.95	22.57	21.50	26.60	24.10	24.00
7	8.45	4.07	3.00	8.10	5.60	5.50	45	27.45	23.07	22.00	27.10	24.60	24.50
8	8.95	4.57	3.50	8.60	6.10	6.00	46	27.95	23.57	22.50	27.60	25.10	25.00
9	9.45	5.07	4.00	9.10	6.60	6.50	47	28.45	24.07	23.00	28.10	25.60	25.50
10	9.95	5.57	4.50	9.60	7.10	7.00	48	28.95	24.57	23.50	28.60	26.10	26.00
11	10.45	6.07	5.00	10.10	7.60	7.50	49	29.45	25.07	24.00	29.10	26.60	26.50
12	10.95	6.57	5.50	10.60	8.10	8.00	50	29.95	25.57	24.50	29.60	27.10	27.00
13	11.45	7.07	6.00	11.10	8.60	8.50	51	30.45	26.07	25.00	30.10	27.60	27.50
14	11.95	7.57	6.50	11.60	9.10	9.00	52	30.95	26.57	25.50	30.60	28.10	28.00
15	12.45	8.07	7.00	12.10	9.60	9.50	53	31.45	27.07	26.00	31.10	28.60	28.50
16	12.95	8.57	7.50	12.60	10.10	10.00	54	31.95	27.57	26.50	31.60	29.10	29.00
17	13.45	9.07	8.00	13.10	10.60	10.50	55	32.45	28.07	27.00	32.10	29.60	29.50
18	13.95	9.57	8.50	13.60	11.10	11.00	56	32.95	28.57	27.50	32.60	30.10	30.00
19	14.45	10.07	9.00	14.10	11.60	11.50	57	33.45	29.07	28.00	33.10	30.60	30.50
20	14.95	10.57	9.50	14.60	12.10	12.00	58	33.95	29.57	28.50	33.60	31.10	31.00
21	15.45	11.07	10.00	15.10	12.60	12.50	59	34.45	30.07	29.00	34.10	31.60	31.50
22	15.95	11.57	10.50	15.60	13.10	13.00	60	34.95	30.57	29.50	34.60	32.10	32.00
23	16.45	12.07	11.00	16.10	13.60	13.50	61	35.45	31.07	30.00	35.10	32.60	32.50
24	16.95	12.57	11.50	16.60	14.10	14.00	62	35.95	31.57	30.50	35.60	33.10	33.00
25	17.45	13.07	12.00	17.10	14.60	14.50	63	36.45	32.07	31.00	36.10	33.60	33.50
26	17.95	13.57	12.50	17.60	15.10	15.00	64	36.95	32.57	31.50	36.60	34.10	34.00
27	18.45	14.07	13.00	18.10	15.60	15.50	65	37.45	33.07	32.00	37.10	34.60	34.50
28	18.95	14.57	13.50	18.60	16.10	16.00	66	37.95	33.57	32.50	37.60	35.10	35.00
29	19.45	15.07	14.00	19.10	16.60	16.50	67	38.45	34.07	33.00	38.10	35.60	35.50
30	19.95	15.57	14.50	19.60	17.10	17.00	68	38.95	34.57	33.50	38.60	36.10	36.00
31	20.45	16.07	15.00	20.10	17.60	17.50	69	39.45	35.07	34.00	39.10	36.60	36.50
32	20.95	16.57	15.50	20.60	18.10	18.00	70	39.95	35.57	34.50	39.60	37.10	37.00
33	21.45	17.07	16.00	21.10	18.60	18.50	71	40.45	36.07	35.00	40.10	37.60	37.50
34	21.95	17.57	16.50	21.60	19.10	19.00	72	40.95	36.57	35.50	40.60	38.10	38.00
35	22.45	18.07	17.00	22.10	19.60	19.50	73	41.45	37.07	36.00	41.10	38.60	38.50
36	22.95	18.57	17.50	22.60	20.10	20.00	74	41.95	37.57	36.50	41.60	39.10	39.00
37	23.45	19.07	18.00	23.10	20.60	20.50	75	42.45	38.07	37.00	42.10	39.60	39.50
38	23.95	19.57	18.50	23.60	21.10	21.00	76	42.95	38.57	37.50	42.60	40.10	40.00
39	24.45	20.07	19.00	24.10	21.60	21.50	77	43.45	39.07	38.00	43.10	40.60	40.50
40	24.95	20.57	19.50	24.60	22.10	22.00	78	43.95	39.57	38.50	43.60	41.10	41.00
41	25.45	21.07	20.00	25.10	22.60	22.50	79	44.45	40.07	39.00	44.10	41.60	41.50
42	25.95	21.57	20.50	25.60	23.10	23.00	80	44.95	40.57	39.50	44.60	42.10	42.00

							DSND		SCALE: N/A	MODEL TYPE: FPC CONNECTOR		
					ANGLAR	±5°		DWN		VIEW: 	PART NO.: X05A255LKXXG	
ΔX					L≤ 4	±0.2		CHKD		UNIT: mm/in	DWG NO.: X-X05A255LKXXG	
ΔX					4<L≤ 16	±0.3		APPD		SIZE: A4		
ΔX					16<L≤ 63	±0.4						
MARK	DESCRIPTION			DATE	REVISED	APPROVED						
REVISIONS							UNSPECIFIED TOLERANCES		XKB INDUSTRIAL PRECISION CO.,LIMITED			
www.helloxkb.com www.helloxkb.cn www.xk-dg.cn									WEIGHT SHEET REVISION			
									1/1 A0			