
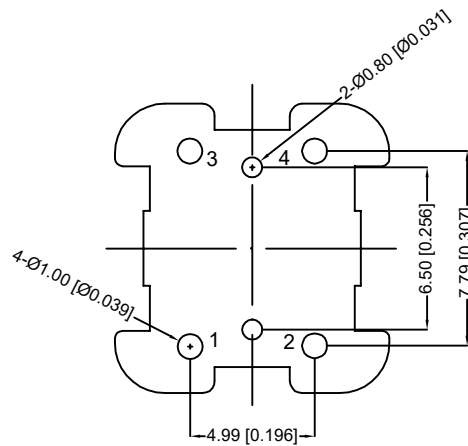
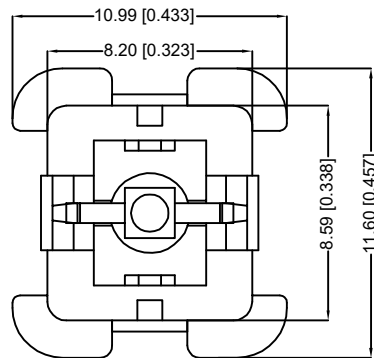


使用温度范围	TemPerature	40~70°C
额定负荷	Rated Load	DC 12V 0.1A
接触电阻	Contact Resistance	≤0.05Ω
绝缘电阻	Insulation Resistance	>100MΩ
耐压	Withstand Voltage	AC250V
动作力	Actuating Force	250~350gf
寿命	Life	100000次

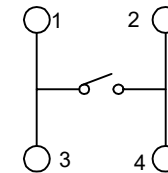

P.C.B

Led Color	Part No
White	TM-006-D1-01
Red	TM-006-D1-02
Blue	TM-006-D1-03
Green	TM-006-D1-04
Yellow	TM-006-D1-05
Orange	TM-006-D1-06

ITEM	PAPT NAMF	TER,NO	QTY	MATERIAL	FINISHING	REMARK
⑦	LED		1			
⑥	Hat		1	ABS		
⑤	Terminal	—	4	Brass (0.30t)	ag Plated	—
④	Contact	—	1	F.ag/SUS		—
③	Base	—	1	PA66		—
①	Cover	—	1	PA66		—
①	Keystake	—	1	POM		—

DSND	SCALE: N/A	MODEL TYPE: LED SWITCH
DWN	VIEW:	PART NO.: TM-006-D1-X
CHKD	UNIT: mm/in	DWG NO.:
APPD	SIZE: A4	
	WEIGHT	SHEET
		1/1
	REVISIC	A0



XKB INDUSTRIAL PRECISION CO.,LIMITED

MARK	DESCRIPTION	DATE	REVISED	APPROVED	ANGLAR	±5°
Δx					L ≤ 4	±0.2
Δx					4 < L ≤ 16	±0.3
Δx					16 < L ≤ 63	±0.4
					L > 63	±0.5
REVISIONS						UNSPECIFIED TOLERANCES
www.helloxkb.com www.helloxkb.cn www.xk-dg.cn						