
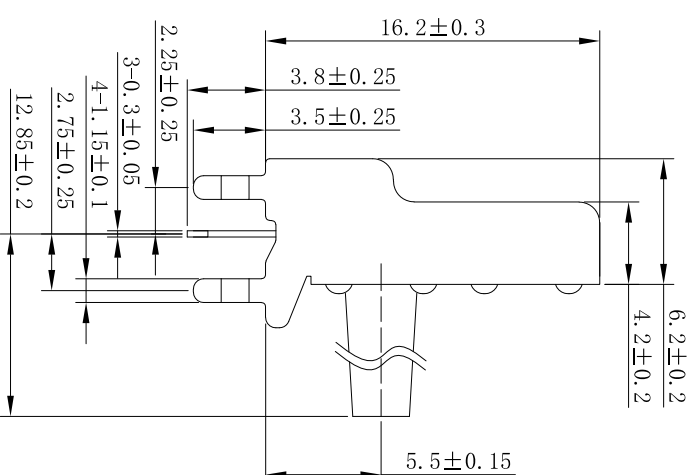
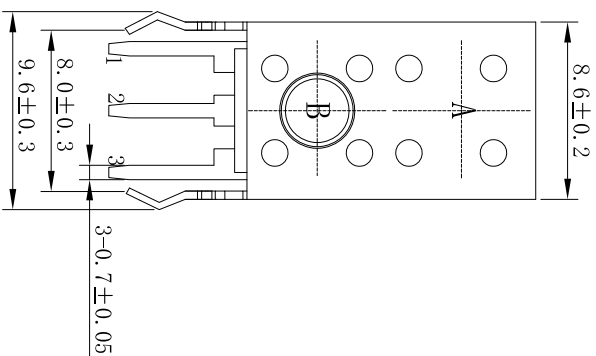
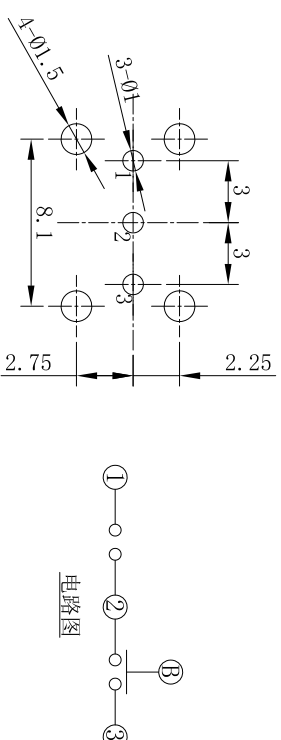


RoHS

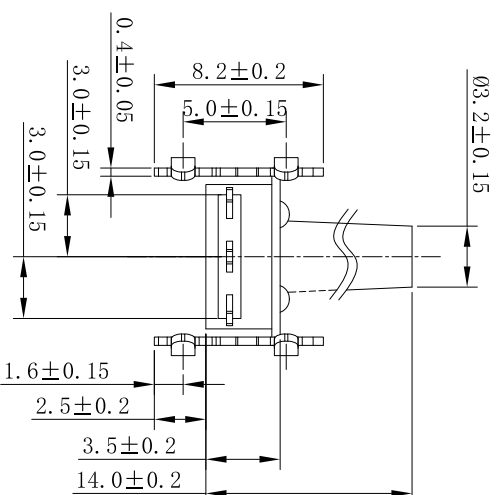

技术参数:

1. 做用温度: $-20\sim+70^{\circ}\text{C}$;
2. 额定负荷: DC 12V 50mA;
3. 接触电阻: $\leq 50\text{m}\Omega$;
4. 绝缘电阻: $\geq 100\text{M}\Omega$;
5. 耐 压: AC250V(50Hz)/min;
6. 动 作 力: $260\pm 50\text{gf}$;
7. 开关行程: $0.25\pm 0.1\text{mm}$
8. 使用寿命: 5~7万次;
9. 高度尺寸可按用户要求选择;
10. 未注尺寸公差 $\pm 0.15\text{mm}$ 。

[illegible]