

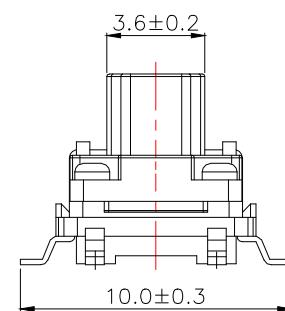



ROHS

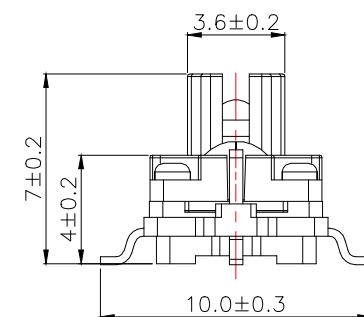

LED colour(LED颜色)	Part No. 料号
Whiler(白色)	K6-6157S-01
Red(红色)	K6-6157S-02
Blue(蓝色)	K6-6157S-03
Green(绿色)	K6-6157S-04
Yellow/Green(黄/绿色)	K6-6157S-45
Red/Blue(红/蓝色)	K6-6157S-23
Red/Green(红/绿色)	K6-6157S-24

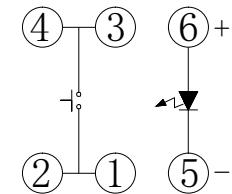


Circuit Diagram

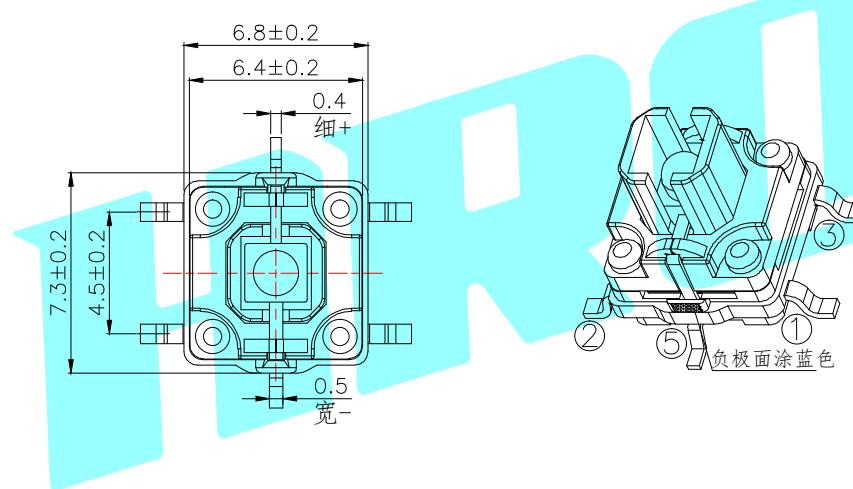

Typical Specifications

- 1.Rating : DC 12V 10mA
 - 2.Insulation Resistance : 100mΩ Min
 - 3.Dielectric Strength :AC 250V for 1 minute
 - 4.Operating Force : 260±50 gf
 - 5.Contact Resistance : 50mΩ MAX
 - 6.Life : 80,000 Cycles Min
 - 7.Waterproof : IP67

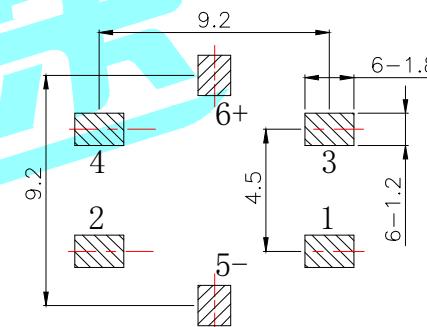

PCBLayout(Top view)

⑧	Waterproof membrane	_____	1	_____	Black	_____
⑦	Waterproof pad	_____	1	_____	Black	_____
⑥	Contact	_____	1	SUS	_____	_____
⑤	Cover	_____	1	PPA	Black	_____
④	LED	_____	1	GaASP/GaP	_____	_____
③	Terminal	_____	6	Brass	Ag Plating	_____
②	Base	_____	1	PPA	Black	_____
①	Button	_____	1	PPA	Black	_____

HRO 韩宗®
ELECTRONICS CO., LTD

							CHECKED			TITLE:	LED Tact Switch		
							APPROVALS			PART NO.	K6-6157S-□ □		
_____	A	_____	NEW	_____	_____	_____	TOLERANCES ARE	30~以上	±0.30	ANGLE	UNIT: mm	SCALE: 1:1	PROJ: 
ECN NO.	REV.	DATE.	DESCRIPTION.	CHANGE.	CHECK.	APPRO.		10~30	±0.20				
								5~10	±0.15	±2°	DRAWING NO.	_____	
								~ 5	±0.10		SHEET 1 OF 1		