


308-PA/..-402 , 308-PAG/..-402

Distributor strip

Tab connections 5 x 6.3; slanted

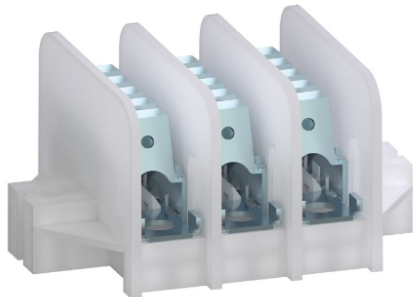

GENERAL INFORMATION

Pitch: 11.00 mm

No. of poles: 1 - 16

TECHNICAL DATA

Rated current: 10 A with receptable 6.3; wire 1.5 mm² 16 A with receptable 6.3; wire 2.5 mm² 20 A with receptable 6.3; wire 4 mm² 25 A with receptable 6.3; wire 6 mm²

Rated insulation voltage: 450 V acc. to EN 60998-1

RATINGS

	Current [A]	Voltage [V]	Group	AWG	Torque [Nm]
	300	20	B		
		10	D		


	Current [A]	Voltage [V]	Cross Section [mm²]	AWG	TORQUE
	17.5	450	1.5		

Distributor Stock Check

Download PDF

How to Order

TECHNICAL DRAWINGS

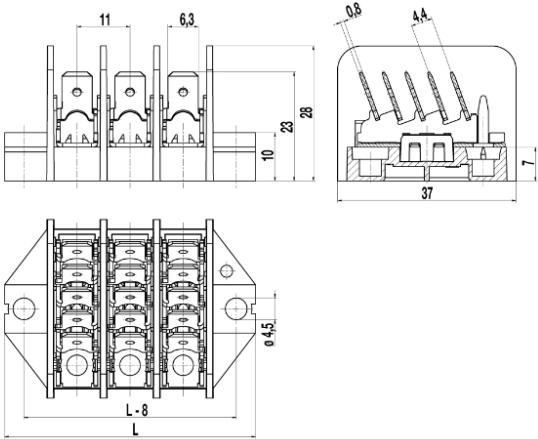

MATERIALS

Moulding: PA, natural, V-2 (PAG-Version: PA glass fiber reinforced, natural, V-0) Details in brackets apply for "no flame" products

Comparative tracking index: CTI 250 (CTI 400)

Temperature range: RTI Str 90°C (130°C PAG-Version)

Tab: Zinc plated steel

OPTIONS / ACCESSORIES

Consecutive Numbering

Special marking according to drawing

Fixed marking in the tool on request