

SPECIFICATIONS

Mechanical

Contact Retention Force: 0.91kg min.

Electrical

Current Rating: 3.0A

Dielectric Withstanding Voltage: 500V AC

Insulation Resistance: 1000MW

Physical

Housing: Thermoplastic, UL 94V-0 rated in Black Color

Contact: Copper alloy

Plating: See "ORDERING INFORMATION"


Operating Temperature: -40 to +105

Breakaway Header


HB11 Series

Vertical, T/H Type

2.54mm [.100"] Pitch

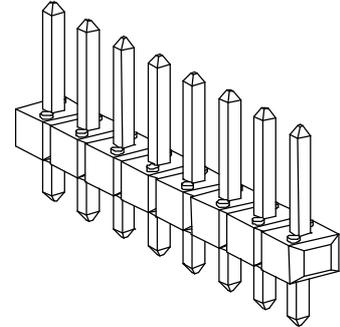


DRAWING

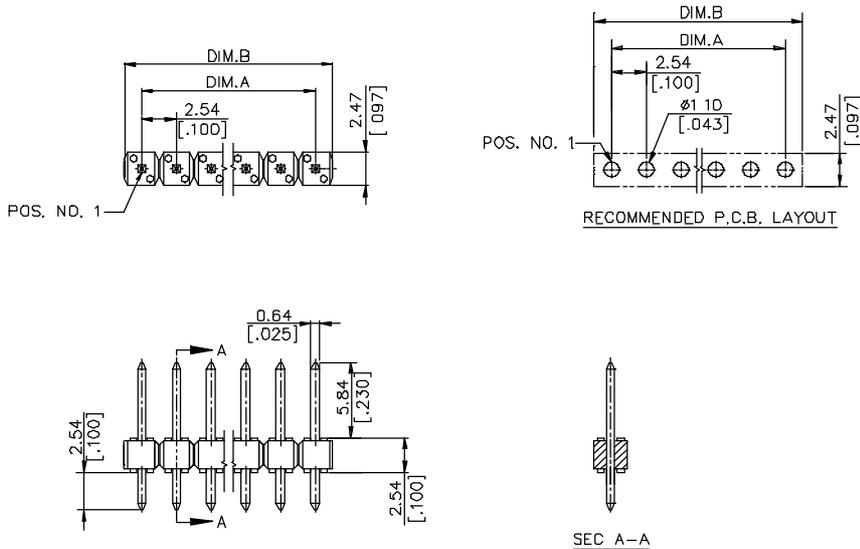

ORDERING INFORMATION

PRODUCT NO.: H B 1 1 ** 1

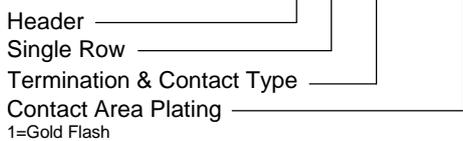

For Position Sizes 4 Through 40 Add 2.54 [.100] For Each Additional Pin

3	5.08 [.200]	7.37 [.290]
2	2.54 [.100]	4.83 [.190]
POS.	DIM. A	DIM. B