

THE INFORMATION CONTAINED IN THIS DRAWING IS THE SOLE PROPERTY OF L-COM, INC. ANY REPRODUCTION IN PART OR WHOLE WITHOUT THE WRITTEN PERMISSION OF L-COM, INC. IS PROHIBITED.

REVISIONS			
REV	DESCRIPTION	DATE	APPROVED
A	INITIAL RELEASE	05/12/2022	PHOSPODAR


FIBER TYPE	MULTIMODE, OM4, RISER
CORE DIAMETER	50 μ m
CLADDING DIAMETER	125 μ m
BUFFER	0.87 \pm 0.05

WAVELENGTH:	850/1300nm FIBER TYPE	850/1300nm MAXIMUM
ATTENUATION	3.0/1.0 dB/km	3.5/1.5 dB/km
OFL BANDWIDTH (MHz.km)	\geq 3500/500	
EFFECTIVE MODER (MHz.km) (850nm)	\geq 4700	
10G ETHERNET SX (M) (850nm)	\leq 550	

MAX. TENSILE STRENGTH (N)	
SHORT TERM	100
LONG TERM	50

MIN. BEND RADIUS (mm)	
DYNAMIC	20X DIA.
STATIC	10X DIA.

MAX. CRUSH RESISTANCE (N/100mm)	
SHORT TERM	500
LONG TERM	100

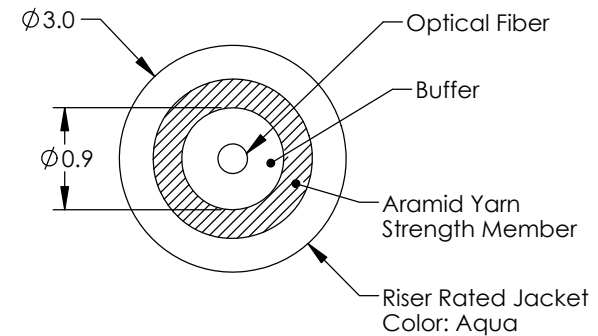


 
ALL DIMENSIONS IN mm, DRAWING NOT TO SCALE

NOTES:

1. BULK CABLE SHALL BE INDIVIDUALLY PACKAGED IN ACCORDANCE WITH L-COM SPECIFICATION PS-0031.

REGULATORY COMPLIANCE:

EU RoHS DIRECTIVE (MOST RECENT RELEASED VERSION)

UNLESS OTHERWISE SPECIFIED, DIMENSIONS ARE IN INCHES [mm] OVERALL CABLE LENGTH TOLERANCE: ≤12 [305] = +1 [25] / -0 >12 [305] ≤60 [1524] = +2 [51] / -0 >60 [1524] ≤120 [3048] = +4 [102] / -0 >120 [3048] ≤300 [7620] = +6 [152] / -0 >300 [7620] = +5% / -0 ALL OTHER DIMENSIONAL TOLERANCES: .X = ± .2 [5] FRACTIONS ± 1/32 .XX = ± .02 [.5] ANGLES ± 1° .XXX = ± .005 [.13]	APPROVALS	DATE	 an INFINITI® brand	50 High Street, West Mill, North Andover, MA 01845 USA. Phone: 1.800.341.5266 1.978.682.6936		
	DRAWN BY DFRISIELLO	05/12/2022				
	THIRD-ANGLE PROJECTION 	CHECKED BY DZINN	05/12/2022		CATEGORY FIBER OPTIC	
		APPROVED BY PHOSPODAR	05/12/2022			
CONFIGURATION DETAILS OF UNDIMENSIONED FEATURES MAY VARY			PRODUCT DESCRIPTION Round Simplex Optical Cable, 50/125 40/100GB OM4, Riser Rated, 3.0mm			
COLOR VARIATIONS MAY OCCUR			SIZE A	CAGE CODE 43321	ITEM NO. FOB-1F3DM4R-M	REV. A
			SCALE: NONE		CAD FILE: FOB-1F3DM4R-M.SLDDRW	
			SHEET 1 OF 1			