
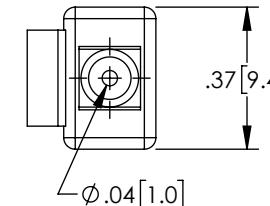
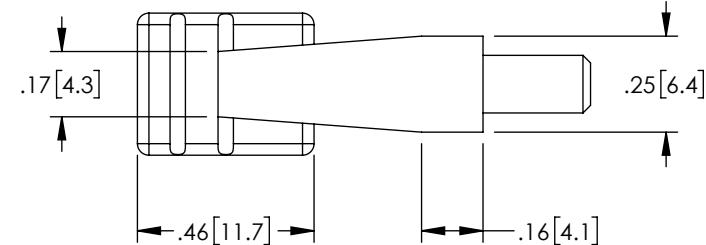


THE INFORMATION CONTAINED IN THIS DRAWING IS THE SOLE PROPERTY OF L-COM, INC. ANY REPRODUCTION IN PART OR WHOLE WITHOUT THE WRITTEN PERMISSION OF L-COM, INC. IS PROHIBITED.

REVISI

REV	DESCRIPTION	DATE	APPROVED
A	INITIAL RELEASE	05/20/2021	PHOSPODAR

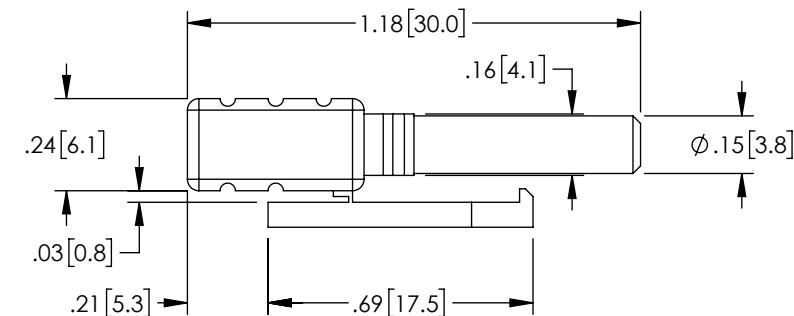

NOTES:

 
1. ALL DIMENSIONS ARE FOR REFERENCE ONLY.
2. INDIVIDUALLY PACKAGE EACH ASSEMBLY
IN ACCORDANCE WITH L-COM SPECIFICATION PS-0031.

REGULATORY COMPLIANCE:

EU RoHS DIRECTIVE (MOST RECENT RELEASED VERSION)

UNLESS OTHERWISE SPECIFIED,
DIMENSIONS ARE IN INCHES [mm].
OVERALL CABLE LENGTH TOLERANCE:
 ≤ 12 [305] = $+1$ [25] / -0
 > 12 [305] ≤ 60 [1524] = $+2$ [51] / -0
 > 60 [1524] ≤ 120 [3048] = $+4$ [102] / -0
 > 120 [3048] ≤ 300 [7620] = $+6$ [152] / -0
 > 300 [7620] = $+5\% / -0$

ALL OTHER DIMENSIONAL TOLERANCES:
 $.X = \pm .2$ [5] FRACTIONS
 $.XX = \pm .02$ [5] $\pm 1/32$
 $.XXX = \pm .005$ [1.3] ANGLES $\pm 1^\circ$



APPROVALS
DRAWN BY
DZINN
CHECKED BY
DFRISIELLO
APPROVED BY
PHOSPODAR

DATE
05/20/2021
05/20/2021
05/20/2021

CATEGORY

L-COMTM
an INFINIT[®] brand

50 High Street, West Mill,
North Andover, MA 01845 USA.
Phone: 1.800.341.5266
1.978.682.6936

FIBER OPTIC

PRODUCT DESCRIPTION

Versatile Link, Simplex, Latching,
Clamshell, 1.0 x 2.2mm, Black

SIZE

A

CAGE CODE

43321

ITEM NO.

FOCOVSLCB-1.0x2.2

REV.

A

SCALE: NONE

CAD FILE: FOCOVSLCB-1.0x2.2.SLDDRW

SHEET 1 OF 1