





8
7
6
5
4
3
2
1
THE INFORMATION CONTAINED IN THIS DRAWING IS THE SOLE PROPERTY OF L-COM, INC. ANY REPRODUCTION IN PART OR WHOLE WITHOUT THE WRITTEN PERMISSION OF L-COM, INC. IS PROHIBITED.

REV DESCRIPTION DATE APPROVED

A INITIAL RELEASE 05/20/2021 PHOSPODAR

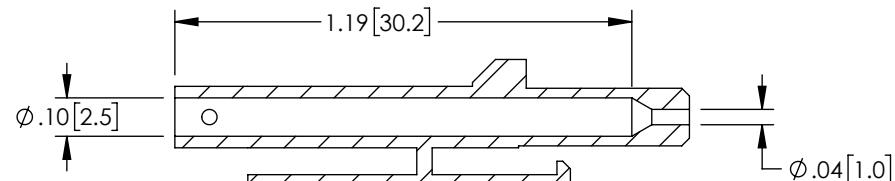

SECTION A-A

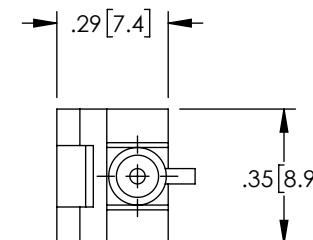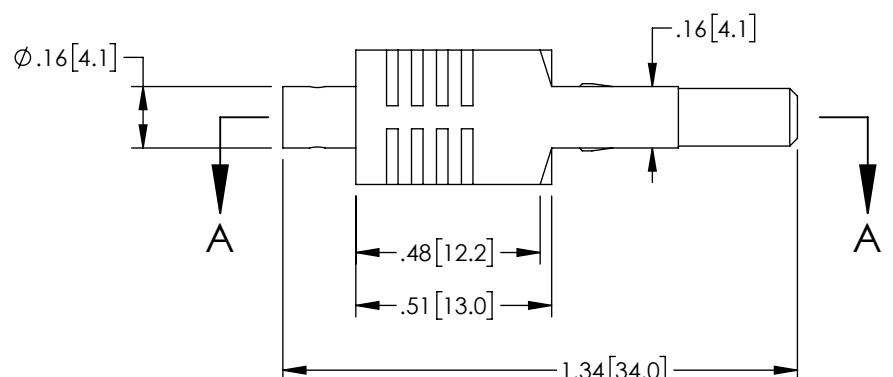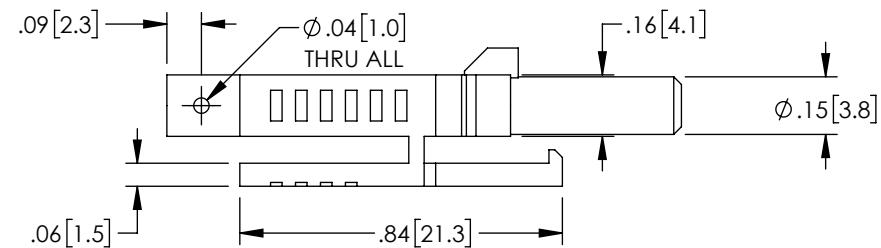

NOTES:

 
1. ALL DIMENSIONS ARE FOR REFERENCE ONLY.
2. INDIVIDUALLY PACKAGE EACH ASSEMBLY
IN ACCORDANCE WITH L-COM SPECIFICATION PS-0031.

REGULATORY COMPLIANCE:

EU RoHS DIRECTIVE (MOST RECENT RELEASED VERSION)

UNLESS OTHERWISE SPECIFIED,
DIMENSIONS ARE IN INCHES [mm]
OVERALL CABLE LENGTH TOLERANCE:
 $\leq 12 [305] = +1 [25] / -0$
 $> 12 [305] \leq 60 [1524] = +2 [51] / -0$
 $> 60 [1524] \leq 120 [3048] = +4 [102] / -0$
 $> 120 [3048] \leq 300 [7620] = +6 [152] / -0$
 $> 300 [7620] = +5\% / -0$

ALL OTHER DIMENSIONAL TOLERANCES:
 $.X = \pm .2 [5]$ FRACTIONS
 $.XX = \pm .02 [5]$ $\pm 1/32$
 $.XXX = \pm .005 [13]$ ANGLES $\pm 1^\circ$



APPROVALS DATE
DRAWN BY DZINN 05/20/2021
CHECKED BY DFRISIELLO 05/20/2021
APPROVED BY PHOSPODAR 05/20/2021

CONFIGURATION DETAILS OF
UNDIMENSIONED FEATURES
MAY VARY

COLOR VARIATIONS
MAY OCCUR

L-COM™
an INFINIT® brand

50 High Street, West Mill,
North Andover, MA 01845 USA.
Phone: 1.800.341.5266
1.978.682.6936

CATEGORY FIBER OPTIC

PRODUCT DESCRIPTION
Versatile Link Blue Simplex Latching-
Style Connector

SIZE A CAGE CODE 43321 ITEM NO. FOCOVLSLBL-1.0x2.2 REV. A
SCALE: NONE CAD FILE: FOCOVLSLBL-1.0x2.2.SLDDRW SHEET 1 OF 1