
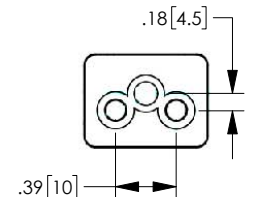
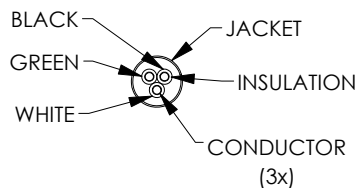
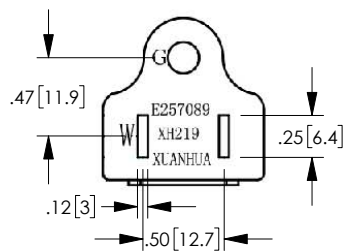


THE INFORMATION CONTAINED IN THIS DRAWING IS THE SOLE PROPERTY OF L-COM, INC. ANY REPRODUCTION IN PART OR WHOLE WITHOUT THE WRITTEN PERMISSION OF L-COM, INC. IS PROHIBITED.


REVISIONS			
REV	DESCRIPTION	DATE	APPROVED
A	REV A DRAWING RELEASED	11/12/2018	BPUCHASKI
B	ECN 10495: REVISED TEMP RATING TO 60 C	05/18/2020	BGATES

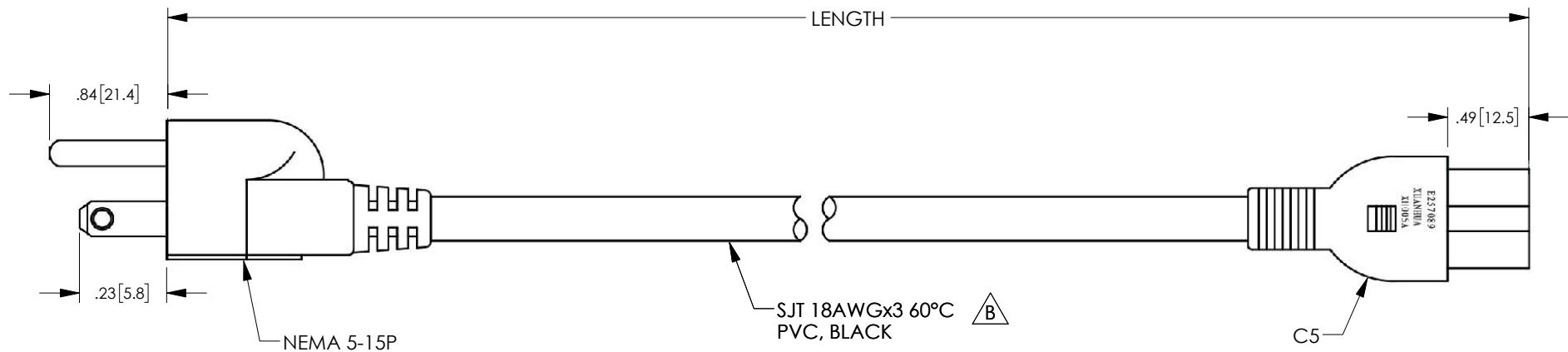

PART NUMBER	LENGTH FEET	LENGTH METERS
PPA00009-04F	4.0	1.22
PPA00009-06F	6.0	1.83
PPA00009-10F	10.0	3.05
PPA00009-15F	15.0	4.57

NOTES:

- VOLTAGE RATING: AC \geq 1500V/S
- CONNECTOR C5 POWER RATING: 10A UL-E257089
- CONNECTOR MALE POWER RATING: NEMA 5-15P UL-E257089
- CABLE: SJT 18AWGx3, 300V, 60°C VW-1 E313867 FT1
- CABLE ASSEMBLY SHALL BE INDIVIDUALLY PACKAGED IN ACCORDANCE WITH SPEC. PS-0031.

UNLESS OTHERWISE SPECIFIED, DIMENSIONS ARE IN INCHES [mm]		APPROVALS		DATE		 an INFINITI brand	50 High Street, West Mill, North Andover, MA 01845 USA. Phone: 1.800.341.5266 1.978.682.6936	
OVERALL CABLE LENGTH TOLERANCE:		DRAWN BY BPUCHASKI		10/29/2018			CATEGORY	POWER PRODUCT
ALL OTHER DIMENSIONAL TOLERANCES:		CHECKED BY DFRISIELLO		10/29/2018				
THIRD-ANGLE PROJECTION		APPROVED BY B.GATES		10/29/2018				
CONFIGURATION DETAILS OF UNDIMENSIONED FEATURES MAY VARY		PRODUCT DESCRIPTION		Laptop Power Cord - NEMA 5-15P to C5 - 10Amp				
SIZE		CAGE CODE		ITEM NO.		PPA00009		REV. B
SCALE: NONE		CAD FILE: PPA00009.SLDDRW		SHEET 1 OF 1				