

## CD32 TYPE


### FEATURES 特性

Various high power inductors are superior be high saturation for surface mounting.  
具有高功率、高饱和电流、低阻抗、小型化之特点。

### APPLICATIONS 用途

Power supply for VTR,OA equipment Digital camera,LCD television set notebook PC,  
portable communication equipments,DC/DC converters,etc.  
录影机, OA仪器, 数码相机, 液晶电视, 笔记型电脑, 小型通信机器, DC/DC变压器  
之电源供应器等。

### DIMENSIONS 尺寸

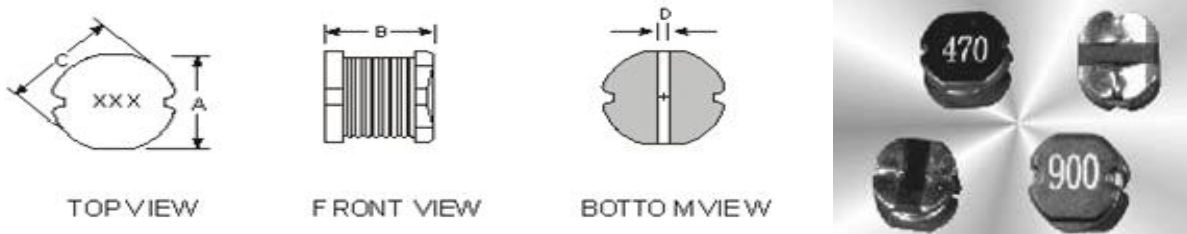

PART NO.	A	B	C	D(Ref)
XRCD32	3.0±0.3	2.1±0.3	3.5±0.3	1.0

### IDENTIFICATION 产品标记说明


XRCD 32 — 470 K I  
1 2 3 4 5

1. product ID 产品代号
2. Dimensions 尺寸
3. Inductance 电感量 (470:47uH,471:470uH)
4. Tolerance 精度 (J:±5%,K:±10%,L:±15% M:±20%,P:±25%,N:±30%)
5. Packaging Style 包装 (T:Tape and reel;B:Bulk)

**SPECIFICATION TABLE:**
**XRCD32 TYPE**

PART NUMBER 品名	INDUCTANCE E (μH) 电感值	DCR (max) (Ω) 直流电阻	IDC (A)(max) ΔL/L=-10%;Δt=40℃ 定格电流	TEST FREQ. 测试频率
XRCD32-100K	10	0.23	0.760	100KHz
XRCD32-120K	12	0.27	0.685	100KHz
XRCD32-150K	15	0.31	0.635	100KHz
XRCD32-180K	18	0.41	0.525	100KHz
XRCD32-220K	22	0.47	0.500	100KHz
XRCD32-270K	27	0.66	0.405	100KHz
XRCD32-330K	33	0.76	0.380	100KHz
XRCD32-390K	39	0.85	0.355	100KHz
XRCD32-470K	47	0.97	0.330	100KHz
XRCD32-560K	56	1.25	0.290	100KHz
XRCD32-680K	68	1.45	0.275	100KHz
XRCD32-820K	82	1.85	0.235	100KHz
XRCD32-101K	100	2.20	0.220	100KHz
XRCD32-121K	120	2.90	0.185	100KHz
XRCD32-151K	150	3.40	0.170	100KHz
XRCD32-181K	180	3.90	0.165	100KHz
XRCD32-221K	220	6.50	0.155	100KHz
XRCD32-271K	270	7.30	0.135	100KHz
XRCD32-331K	330	9.70	0.125	100KHz
XRCD32-391K	390	10.20	0.115	100KHz

## 包装

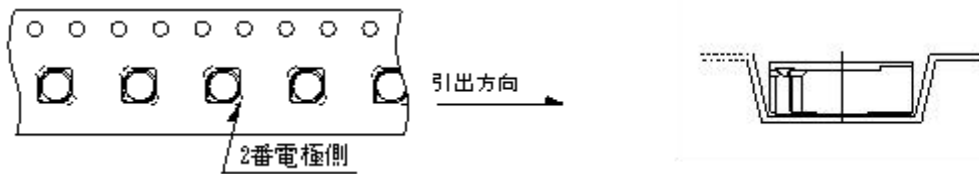

### 包装方式

LEADER部	SEAL TAPE 尺寸	10cm以上
	START CARRIER TAPE尺寸	20cm以上
	TRATLER部尺寸	10cm以上
	数量	1500pcs

纸卷

