


E18422



Connection cable

RJ45 to M12 Jumper 5m PUR

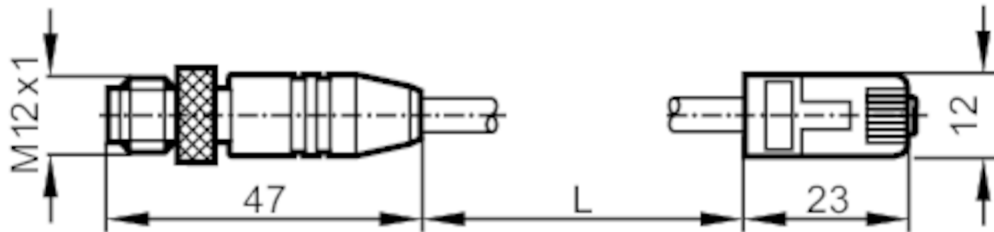

Application	
Design	Ethernet cable, D-coded
Application	Patch cable
Operating conditions	
Ambient temperature [°C]	-25...70
Protection	IP 67; IP 42; (M12 plug / RJ45 plug)
Mechanical data	
Weight [g]	323
Material	PUR / PC
Molded-body material	PUR / PC
Material nut	diecast zinc, nickel-plated
Remarks	
Pack quantity	1 pcs.
Electrical connection - plug M12	

Connector: 1 x M12, straight; coding: D; Moulded body: PUR; Locking: diecast zinc, nickel-plated; Tightening torque: 0.7...0.9 Nm



E18422




Connection cable

RJ45 to M12 Jumper 5m PUR

Electrical connection

Cable: 5 m, PUR, green, Ø 6.2 mm; 2 x 0.38 mm²

Connection

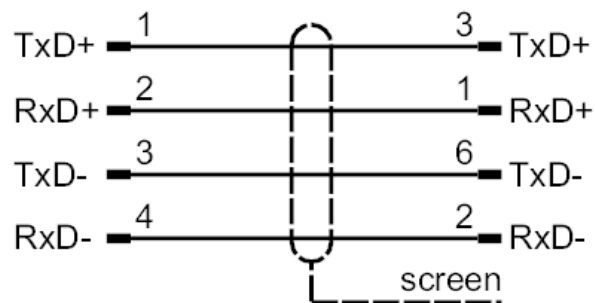

Electrical connection - plug RJ45

Connector: 1 x RJ45, straight; Moulded body: PC

