

2273002-2  ACTIVE

TE Internal #: 2273002-2

TE Internal Description: M8 x 1.0 straight plug Pigtail

M8 Connector: Pigtail Cable, Straight, Male

[View on TE.com >](#)

All M8 Connector: Pigtail Cable, Straight, Male (31)

Product Compliance

[For compliance documentation, visit the product page on TE.com >](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2023 (235) Candidate List Declared Against: JAN 2022 (223) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # T4051310004-004
M8 CABLE ST FEMALE 3M 4P PVC
CABLE

Customers Also Bought



TE Part #206151-1
23-37 RECEPT STD SEX



TE Part #211824-1
CPC PLUG ASSEMBLY 23-13



TE Part #NB-PTCO-161
Pt100, 2.0x2.3, Class A, PTFC101A1A0



TE Part #1622367-1
LR1 1% 1M0



TE Part #66255-6
MALE CONTACT ASSY. (STRIP)




TE Part #4-794630-4
14P MICRO MNL ASSY,VRT,HDR,LF



TE Part #1735284-2
SATA BACKPLANE RECEPTACLE,
VERTICAL, SMT



TE Part #5-1879338-6
CPF 0603 100K 1% 50PPM 1K RL

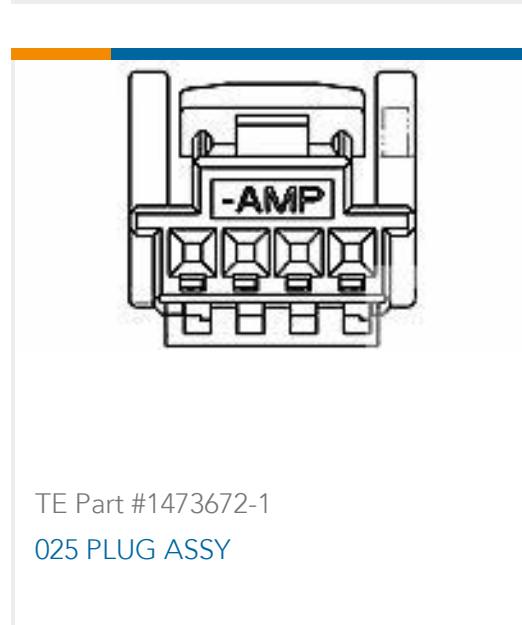

TE Part #1473672-1
025 PLUG ASSY



TE Part #1676193-9
RN 0805 150K 0.1% 10PPM

Documents

Product Drawings

[M8 x 1.0 straight plug Pigtail](#)

English

CAD Files

[3D PDF](#)

3D

Customer View Model

[ENG_CVM_CVM_2273002-2_A.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2273002-2_A.3d_jgs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2273002-2_A.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[M8 / M12 Connector System Catalog](#)

English

[M8 / M12 Connector System Catalog](#)

Japanese

Product Specifications

[Product Specification](#)

English