


3~16A
额定电流

技术参数:


- 1、额定电器性能: 3~16A 250VAC (UL;CUL);
- 2、动作时间标准: 环境温度25℃ 电流200% (6~32A) 时3到60秒内断开;
- 3、耐压: 1500VAC/0.5mA/1min无闪络、无击穿;
- 4、机械寿命: ≥10000次;
- 5、耐焊时间: ≤3秒焊接温度350±10℃。

电话: 0769-82310511-867
邮箱: hooya89@hooya.hk

品名	底座	上盖	端子类型	带灯类型
WH-001-**BR01N3-L22-E	黑色	暗红色	长脚	带红灯
WH-001-**BR01N2-L22-E	黑色	暗红色	中长脚	带红灯
WH-001-**BR01N1-L22-E	黑色	暗红色	短脚	带红灯
WH-001-**WC01B2-L62-E	白色	透明色	中长脚	带黄灯
WH-001-**WC01B3-L22-E	白色	透明色	长脚	带红灯
WH-001-**WC01B2-L22-E	白色	透明色	中长脚	带红灯
WH-001-**WC01B1-L22-E	白色	透明色	短脚	带红灯

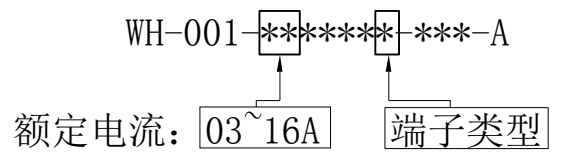


端子类型 (参考)

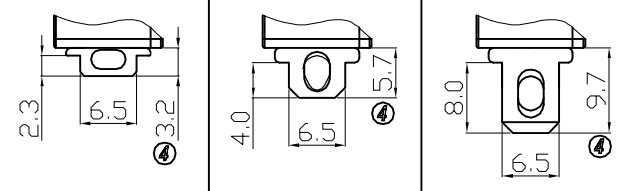

1 短脚 2 中长脚 3 长脚

开孔尺寸参考

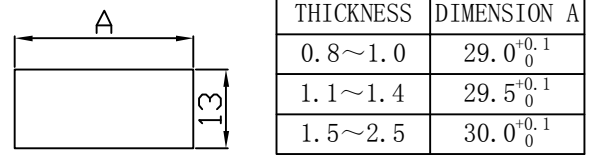

NO	DESCRIPTION	NO	DESCRIPTION	DIMENSIONAL TOLERANCES		APPROVED	CHECKED	DESIGN	DRAWN	ALL SIZE ARE IN		DRAWING NO.	REV.	
				RANGE	TOLERANCE					MM	NO			
5	→	10	→	X	±0.30				LMC					
4	→	9	→	X.X	±0.20				2020.11.15					
3	→	8	→	X.XX	±0.10									
2	→	7	→	ANGLES	±1'									
1	→	6	→	LECION ELECTRONIC & HARDWARE CO., LTD.				MATERIAL NO.		WH-001-*****-***-E	WIF121065	A0		
										SCALE				
										MAT'L		***		

