

3~16A
额定电流

技术参数:

产品执行标准: GB17701-2008、 IEC60934: 2000、 UL1077

1、额定电器性能: 3~16A 250VAC;

2、动作时间标准: 环境温度25℃电流200% (6~32A) 时3到120秒内断开;

3、耐压: 2500VAC/0.5mA/1min 无闪络、无击穿;

4、机械寿命: ≥10000次;

5、耐焊时间: ≤3秒焊接温度350±10℃。

电话: 0769-82310511-867


邮箱: hooya89@hooya.hk

品名	底座	上盖	端子类型	带灯类型
WH001-**-BR01N3-L22-A	黑色	暗红色	长脚	带红灯

WH001-*****-A

额定电流: 03~16A

端子类型 (参考)

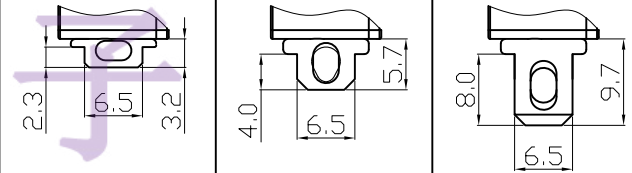


短脚

中长脚

长脚

开孔尺寸参考

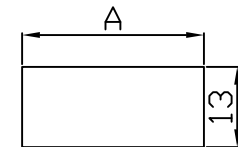

THICKNESS	DIMENSION A
0.8~1.0	29.0 ^{+0.1} ₀
1.1~1.4	29.5 ^{+0.1} ₀
1.5~2.5	30.0 ^{+0.1} ₀

5	→	10	→	DIMENSIONAL TOLERANCES		APPROVED	CHECKED	DESIGN	DRAWN	ALL SIZE ARE IN	MM		
4	→	9	→	RANGE	TOLERANCE					SCALE	NO		
3	→	8	→	X	±0.30				LMC	MAT'L	***		
2	→	7	→	X.X	±0.20				2019.03.16	MATERIAL NO.		DRAWING NO.	REV.
1	→	6	→	X.XX	±0.10	LECLION ELECTRONIC & HARDWARE CO., LTD.				WH001-10BR01N3-L22-A	WIF119005	A	
NO	DESCRIPTION	NO	DESCRIPTION	ANGLES	±1'								