


ITEM NO.	PART NUMBER	DESCRIPTION	QTY.	COMPONENT NOTES
1	54-00095	Connector, 3 pin M5 plug, 5xL13mm, gold plated, panel mount, solder cup, IP67	1	nut and o-ring included
2	Wire	Wire, hook-up, TS, 26 AWG, UL 11028, 600V, 105C, 1 mm, mPPE	3	color: red, green, white
3	Heat shrink	Heat shrink, UL, black	3	covers solder joints

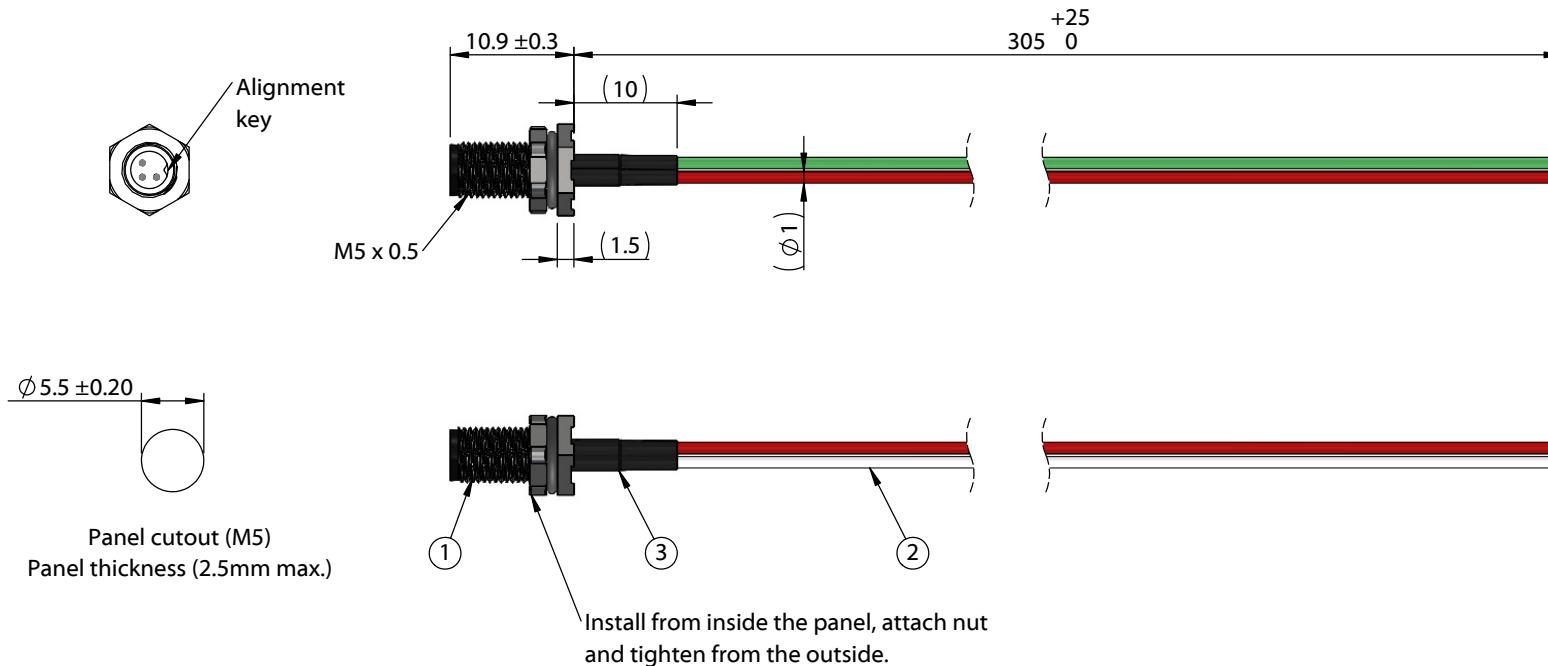

Notes:


Cable rated for 60 V, 1 A

Temperature: -40 ~ 85 °C

IP67 waterproof rating when mated with corresponding (IP67) connector and installed properly in panel

Cables individually packaged in PE bag

Functionally equivalent components may be substituted

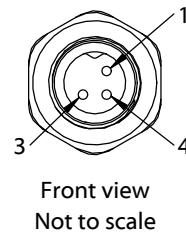

Wiring Diagram	
54-00095	wire color (P/N)
1	red (30-01772)
3	green (30-01777)
4	white (30-01774)

Revision:	Date:	Description:	Prepared:	Notes:	TENSILITY
A	11/10/2022	Initial release		RoHS compliant Function test: no open, no short circuit, no intermittent	tel 1.541.323.3228 800 877.670.7118 fax 1.541.323.4202 web tensility.com
			Verified:	Dimensions are in millimeters. Tolerances: X: ± 0.5 mm X.X: ± 0.3 mm X.XX: ± 0.05 mm	Description: Cable, 305 mm, M5 3C plug panel mount 54-00095 to blunt cut, 26 AWG, UL 11028 hook-up wire
					Size: A Part number: 10-05269
					Scale: 1.5:1 Sheet 1 of 1