

# CES-LTPG-GY-25 - Cable sleeve



0801698  
<https://www.phoenixcontact.com/us/products/0801698>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Cable sleeve, large, no. of conductors: 1, type: Round cable, slotted, external cable diameter: 1x 24 mm ... 25 mm, material: SEBS (halogen-free), color: gray, length: 53 mm, width: 39 mm, height: 17 mm

## Product description

Slotted cable sleeve Slotted sleeves for accommodating preassembled cables and lines with a diameter of 24 mm ... 25 mm, can be used in CES sealing frames.

## Commercial data

|                                      |                     |
|--------------------------------------|---------------------|
| Item number                          | 0801698             |
| Packing unit                         | 1 pc                |
| Minimum order quantity               | 10 pc               |
| Sales key                            | BF67                |
| Product key                          | BF7CCX              |
| Catalog page                         | Page 680 (C-2-2019) |
| GTIN                                 | 4046356675017       |
| Weight per piece (including packing) | 24.74 g             |
| Weight per piece (excluding packing) | 24.74 g             |
| Customs tariff number                | 40169997            |
| Country of origin                    | PL                  |

# CES-LTPG-GY-25 - Cable sleeve

0801698

<https://www.phoenixcontact.com/us/products/0801698>




## Technical data

### Product properties

|                   |              |
|-------------------|--------------|
| Product type      | Cable sleeve |
| No. of conductors | 1            |

### Dimensions
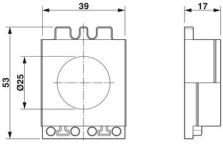
|                     |                                                                                    |
|---------------------|------------------------------------------------------------------------------------|
| Dimensional drawing |  |
| Width               | 39 mm                                                                              |
| Height              | 17 mm                                                                              |
| Length              | 53 mm                                                                              |

### Material specifications

|                                        |      |
|----------------------------------------|------|
| Material                               | SEBS |
| Flammability rating according to UL 94 | V0   |

### Cable/line

|                             |                    |
|-----------------------------|--------------------|
| External cable diameter ( ) | 1x 24 mm ... 25 mm |
|-----------------------------|--------------------|

### Characteristics

|                    |             |
|--------------------|-------------|
| Seal size          | large       |
| Design, Format     | Round cable |
| Design, Cable seal | slotted     |

### Environmental and real-life conditions

#### Ambient conditions

|                                 |                           |
|---------------------------------|---------------------------|
| Degree of protection            | IP54                      |
| Ambient temperature (operation) | -40 °C ... 80 °C (static) |


# CES-LTPG-GY-25 - Cable sleeve

0801698

<https://www.phoenixcontact.com/us/products/0801698>



## Drawings

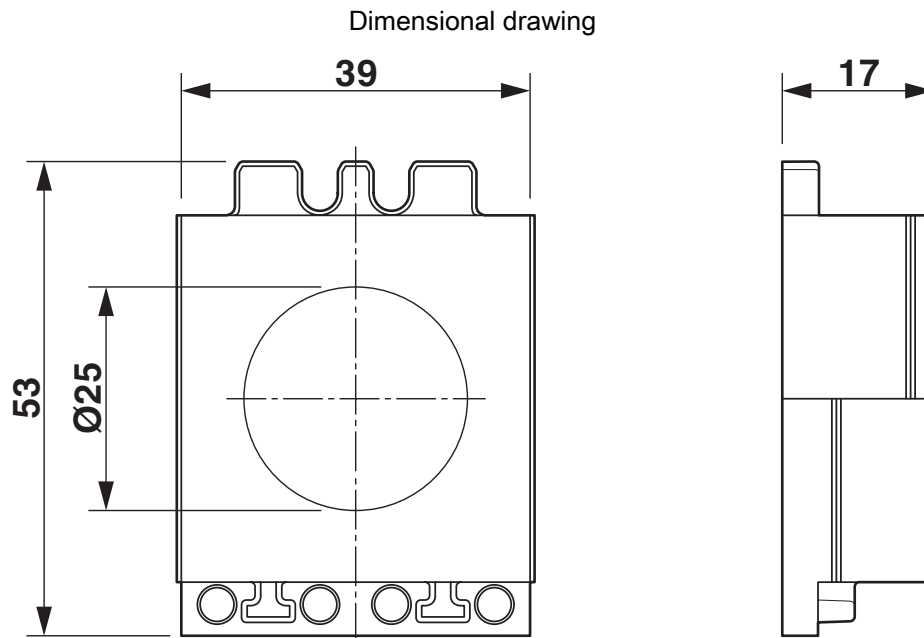

Dimensional drawing

# CES-LTPG-GY-25 - Cable sleeve



0801698

<https://www.phoenixcontact.com/us/products/0801698>

## Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/0801698>



**cUL Recognized**

Approval ID: NITW8.E255026



**UL Recognized**

Approval ID: NITW2.E255026

**DNV**

Approval ID: TAE00003VJ

**cULus Recognized**

# CES-LTPG-GY-25 - Cable sleeve

0801698

<https://www.phoenixcontact.com/us/products/0801698>



## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-11.0 | 27144425 |
| ECLASS-12.0 | 27144425 |
| ECLASS-13.0 | 27144425 |

### ETIM

|          |          |
|----------|----------|
| ETIM 8.0 | EC000451 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 39121400 |
|-------------|----------|

# CES-LTPG-GY-25 - Cable sleeve



0801698

<https://www.phoenixcontact.com/us/products/0801698>

## Environmental product compliance

|            |                                                         |
|------------|---------------------------------------------------------|
| China RoHS | Environmentally friendly use period: unlimited = EFUP-e |
|            | No hazardous substances above threshold values          |

# CES-LTPG-GY-25 - Cable sleeve

0801698

<https://www.phoenixcontact.com/us/products/0801698>



## Accessories

### CES-B10-HFFS-PLBK - Sealing frame

0801663

<https://www.phoenixcontact.com/us/products/0801663>



Sealing frame, With locking latch, design: B10, Number of cable seals (small): 6, material: PA (halogen-free), color: black, length: 99.2 mm, width: 58 mm, height: 20 mm

---

### CES-B16-HFFS-PLBK - Sealing frame

0801662

<https://www.phoenixcontact.com/us/products/0801662>



Sealing frame, With locking latch, design: B16, Number of cable seals (small): 8, material: PA (halogen-free), color: black, length: 120 mm, width: 58 mm, height: 20 mm

## CES-LTPG-GY-25 - Cable sleeve

0801698

<https://www.phoenixcontact.com/us/products/0801698>



## CES-B24-HFFS-PLBK - Sealing frame

0801661

<https://www.phoenixcontact.com/us/products/0801661>



Sealing frame, With locking latch, design: B24, Number of cable seals (small): 10, material: PA (halogen-free), color: black, length: 147 mm, width: 58 mm, height: 20 mm

---

## CES-B10-SFFS-PLBK - Sealing frame

0801660

<https://www.phoenixcontact.com/us/products/0801660>



Sealing frame, with screw locking, design: B10, Number of cable seals (small): 6, material: PA (halogen-free), color: black, length: 99.2 mm, width: 58 mm, height: 20 mm



# CES-LTPG-GY-25 - Cable sleeve

0801698

<https://www.phoenixcontact.com/us/products/0801698>



## CES-B16-SFFS-PLBK - Sealing frame

0801659

<https://www.phoenixcontact.com/us/products/0801659>



Sealing frame, with screw locking, design: B16, Number of cable seals (small): 8, material: PA (halogen-free), color: black, length: 120 mm, width: 58 mm, height: 20 mm

---

## CES-B24-SFFS-PLBK - Sealing frame

0801658

<https://www.phoenixcontact.com/us/products/0801658>



Sealing frame, with screw locking, design: B24, Number of cable seals (small): 10, material: PA (halogen-free), color: black, length: 147 mm, width: 58 mm, height: 20 mm

---

Phoenix Contact 2023 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)