


High Speed HDMI Cable with Ethernet and Locking Connector, UHD 4K, 24AWG (M/M), 10 ft. (3.05 m)

MODEL NUMBER: **P569-010-LOCK**

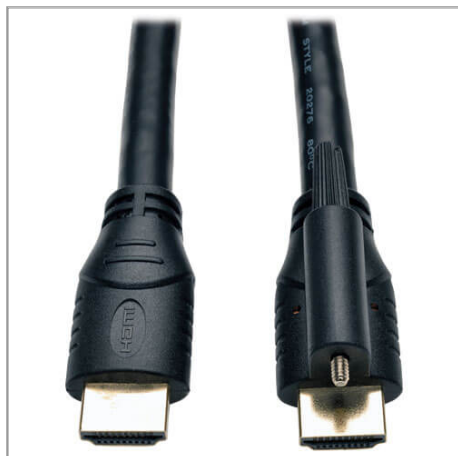

Features

- 10-ft. High Speed HDMI Cable with Ethernet (v1.4)
- Features a locking HDMI connector for use with BHDBT Series HDBaseT Extender products
- Locking connector ensures a secure connection, preventing signal loss due to cables getting bumped and disconnected
- Constructed using 24 AWG wiring to ensure optimal performance to the latest HDMI features
- Supports Ultra High Definition (UHD) video resolutions up to 4K
- Backward compatible to previous HDMI generations
- Fully molded cables, with Gold plated contacts assures long life

Specifications

OVERVIEW	
UPC Code	037332188540
Product Type	Passive Cable
Technology	HDMI
Cable Type	Passive
VIDEO	
Max Supported Video Resolution	3840 x 2160 (4K) @ 30Hz
Max Supported Color Depth	48-bit Deep Color
HDR Support	No

Highlights

- 10 ft. (3.05 m) High Speed HDMI Cable with Ethernet
- Features a locking HDMI connector for use with BHDBT Series HDBaseT Extender products
- Locking connector ensures a secure connection, preventing signal loss due to cables getting bumped and disconnected
- Constructed using 24 AWG wiring to ensure optimal performance to the latest HDMI features
- Supports Ultra High Definition (UHD) 4K video resolutions

System Requirements

- HDMI video source and HDMI enabled TV / Monitor

Package Includes

- 10-ft. High Speed HDMI Cable with Ethernet and Locking Connector, 24AWG

3D Video Supported	Yes
Chroma Sub Sampling	4:4:4
EDID Support	Yes
Signal Transmission	Bidirectional
AUDIO	
Audio Specification	ARC
USER INTERFACE, ALERTS & CONTROLS	
LED Indicators	0
PHYSICAL	
Color	Black
Material of Construction	PVC
Cable Jacket Color	Black
Connector Color	Black
Cable Jacket Material	PVC
Cable Jacket Rating	VW-1
Cable Outer Diameter (OD)	10.0 mm
Wire Gauge (AWG)	24
Cable Length (ft.)	10
Cable Length (m)	3.05
Cable Length (in.)	120
Ferrite Core	No
Minimum Bend Radius	50mm
Shipping Dimensions (hwd / in.)	10.00 x 8.00 x 0.50
Shipping Dimensions (hwd / cm)	25.40 x 20.32 x 1.27
Shipping Weight (lbs.)	0.82
Shipping Weight (kg)	0.37
ENVIRONMENTAL	
Operating Temperature Range	14° to 122°F (-10° to 50°C)
Storage Temperature Range	5° to 140°F (-15° to 60°C)
Operating Humidity Range	0% to 90% RH, Non-Condensing
Storage Humidity Range	0% to 90% RH, Non-Condensing
COMMUNICATIONS	

EDID Compatible	Yes
Consumer Electronics Control (CEC) Supported	Yes
CONNECTIONS	
Side A - Connector 1	HDMI (MALE)
Side B - Connector 1	HDMI (MALE)
Connector Plating	Gold
Contact Plating	Gold
Connector Style	Straight
Latching or Gripping Connector	No
FEATURES & SPECIFICATIONS	
EMI/RFI Line Noise Protection	No
MST Support	No
Antibacterial	No
IP68 Rated	No
IP20 Rated	No
Armored Cable	No
Ethernet Support	Yes
HDCP Specification	1.4; 2.2
STANDARDS & COMPLIANCE	
Product Compliance	RoHS; REACH
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty