

# SAC-4P+D-22AWG-OE-OE-680-100,0 - Cable reel



1112981

<https://www.phoenixcontact.com/us/products/1112981>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



By the meter, Cable reel, shielded, PVC, gray, 4-wire, color single wire: brown, white, blue, black, cable length: 100 m, Foil shielding plus drain wire

## Commercial data

Item number	1112981
Packing unit	1 pc
Sales key	BF16
Product key	BF1IIB
GTIN	4063151034849
Weight per piece (including packing)	22.22 g
Weight per piece (excluding packing)	22.22 g
Country of origin	US

# SAC-4P+D-22AWG-OE-OE-680-100,0 - Cable reel



1112981

<https://www.phoenixcontact.com/us/products/1112981>

## Technical data

### Product properties

Product type	Cable by the meter
Number of positions	4
Application	Connector

### Electrical properties


Nominal voltage $U_N$	300 V
-----------------------	-------

### Cable/line

Cable length	100 m
--------------	-------

PVC, gray, 105°C [680]

Dimensional drawing

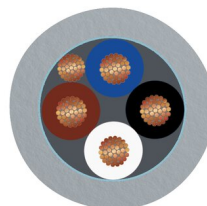

Cable weight	45.42 kg/km
UL AWM Style	2517 (105 °C / 300 V)
Number of positions	4
Shielded	yes
Cable type	PVC, gray, 105°C [680]
AWG signal line	22
Wire diameter incl. insulation	1.27 mm $\pm$ 0.03 mm
External cable diameter	5.08 mm $\pm$ 0.2 mm
Outer sheath, material	PVC
External sheath, color	gray
Conductor material	Tin-plated Cu litz wires
Material wire insulation	PVC (Signal line)
Single wire, color	brown, white, blue, black
Type of pair shielding	Plastic-coated aluminum foil, aluminum side inside
Overall twist	Conductors, fillers, and drain wire are twisted with left-hand lay
Max. conductor resistance	max. 51.1 $\Omega$ /km (20 °C)
Insulation resistance	$\geq$ (550 M Ohms/m @ 500V)
Nominal voltage, cable	300 V
Minimum bending radius, flexible installation	8 x D
Flame resistance	FT4
Other resistance	UV resistant
Special properties	UL standards PLTC and ITC

# SAC-4P+D-22AWG-OE-OE-680-100,0 - Cable reel



1112981

<https://www.phoenixcontact.com/us/products/1112981>

Ambient temperature (operation)	-30 °C ... 105 °C (cable, fixed installation)
---------------------------------	---

# SAC-4P+D-22AWG-OE-OE-680-100,0 - Cable reel



1112981

<https://www.phoenixcontact.com/us/products/1112981>

## Classifications

### ECLASS

ECLASS-11.0	27061801
ECLASS-12.0	27061801
ECLASS-13.0	27061801

# SAC-4P+D-22AWG-OE-OE-680-100,0 - Cable reel



1112981

<https://www.phoenixcontact.com/us/products/1112981>

## Accessories

### WIREFOX SAC - Stripping tool

1212623

<https://www.phoenixcontact.com/us/products/1212623>



Stripping pliers, for halogen-free sensor/actuator cables (SAC cables), with PUR and PVC insulation, from Ø of 4.4 to 7 mm, any stripping length

---

Phoenix Contact 2023 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)