


E18214

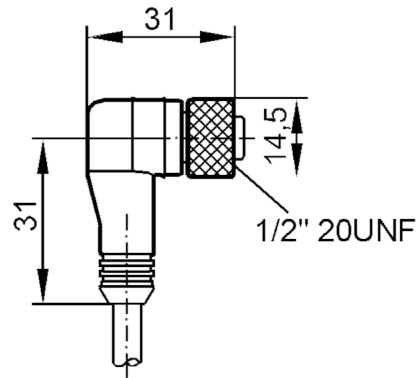

Female cordset

ADOAAO30MSS0002E03



Application

System gold-plated contacts

Electrical data

Operating voltage [V] < 300 AC/DC

Operating conditions

Ambient temperature [°C] -20...80

Protection IP 68

Mechanical data

Weight [g] 72.575

Dimensions [mm] 31 x 14.5 x 31

Material PVC

Molded-body material PVC

Material nut brass, nickel-plated

Remarks

Pack quantity 1 pcs.

E18214



Female cordset

ADOAAO30MSS0002E03

Electrical connection


Cable: 2 m, PVC, yellow; 3 x 0.34 mm² / AWG 22

Electrical connection - Socket

Connector: 1 x 1/2", angled; coding: C; Moulded body: PVC; Locking: brass, nickel-plated; Contacts: gold-plated



Connection

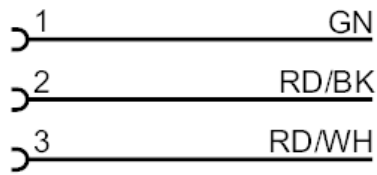

GN = green
RD/BK = red/black
RD/WH = red/white