

GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: UK Plug (Type G) BS1363A, Fused at 3A to IEC320-C5, GT Cable #426: 0.75mmsq / 3 Conductors, 6.8 +/- 0.3mm OD, H05VV-F, 70 Deg.C, 500V, BLU/BRN/GRN-YW, Approvals: IEC 60227, 2050mm, GlobTek Black	
	Model No. Power Cord	
	Part No./Ordering No. 6104262M0712(R)	Rev D1

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

In Addition to GlobTek Inc.'s renewed ISO9001:2008 - Quality Management System Certification, GlobTek Inc. is now certified to:

ISO13485:2003 - Medical Devices Quality Management System Certification
ISO14001:2004 - Environmental Management System Certification

ISO Certificates are available online at <https://www.globtek.com/iso-certificates/>
Prop 65 Statement: <https://en.globtek.com/prop-65-statement.pdf>

The acceptance of this specification and use of the product described in this document indicates the acceptance and binding of the customer to Globtek TERMS AND CONDITIONS (attached to the end of this document), which supersede all other agreements, terms, and conditions (<https://en.globtek.com/terms-and-conditions/>).

The purchaser of this product (Customer) agrees that it is their sole responsibility to determine suitability/fitness of the product described in this specification for their application and to take precautions for protection against any hazards attendant to the handling and use of the product.

Footnote:

GlobTek Inc. will not be liable for the safety and performance of these power supplies if unauthorized access and repair occurs. End user should consult applicable UL, CSA or EN standards for proper installation instruction.

Limitation of Use:

GlobTek products are intended for use with commercial, medical, and/or industrial equipment only. GlobTek product are not authorized for use as mission critical components in life support hazardous environment, nuclear or aircraft applications without prior written approval from the CEO of GlobTek Inc.
Contents of this document are subject to change without prior notice.

Customer Approval of Specification:

Please approve, sign and send back to GlobTek so we can complete order processing.
A delay in receipt of this form will delay delivery schedule.

Company Name: _____

Customer P/N: _____

Quote Number: _____

Date: _____

Authorized Representative Name: _____

Authorized Representative Signature: _____

GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: UK Plug (Type G) BS1363A, Fused at 3A to IEC320-C5, GT Cable #426: 0.75mmsq / 3 Conductors, 6.8 +/- 0.3mm OD, H05VV-F, 70 Deg.C, 500V, BLU/BRN/GRN-YW, Approvals: IEC 60227, 2050mm, GlobTek Black		
	Model No. Power Cord		
	Part No./Ordering No. 6104262M0712(R)		Rev D1

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

REVISION HISTORY


REV	DESCRIPTION	SUB	DATE	APPROVED
D1	Add cable diameter tolerance to the spec; add UKCA approval marking to the connector (effective for productions beginning with lot reference (L/R) 8005831 and later).	bsiep	05/24/2021	QA
D	Update to SF fromat; Add Malaysia, Saudi Arabia, and Gulf State approvals	bsiep	10/09/2020	QA

Cordset Information:
CordsetColor:GlobTek Black
Cord Length (mm):2050

NOTES:

GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: UK Plug (Type G) BS1363A, Fused at 3A to IEC320-C5, GT Cable #426: 0.75mmsq / 3 Conductors, 6.8 +/- 0.3mm OD, H05VV-F, 70 Deg.C, 500V, BLU/BRN/GRN-YW, Approvals: IEC 60227, 2050mm, GlobTek Black	
	Model No. Power Cord	
	Part No./Ordering No. 6104262M0712(R)	Rev D1


CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

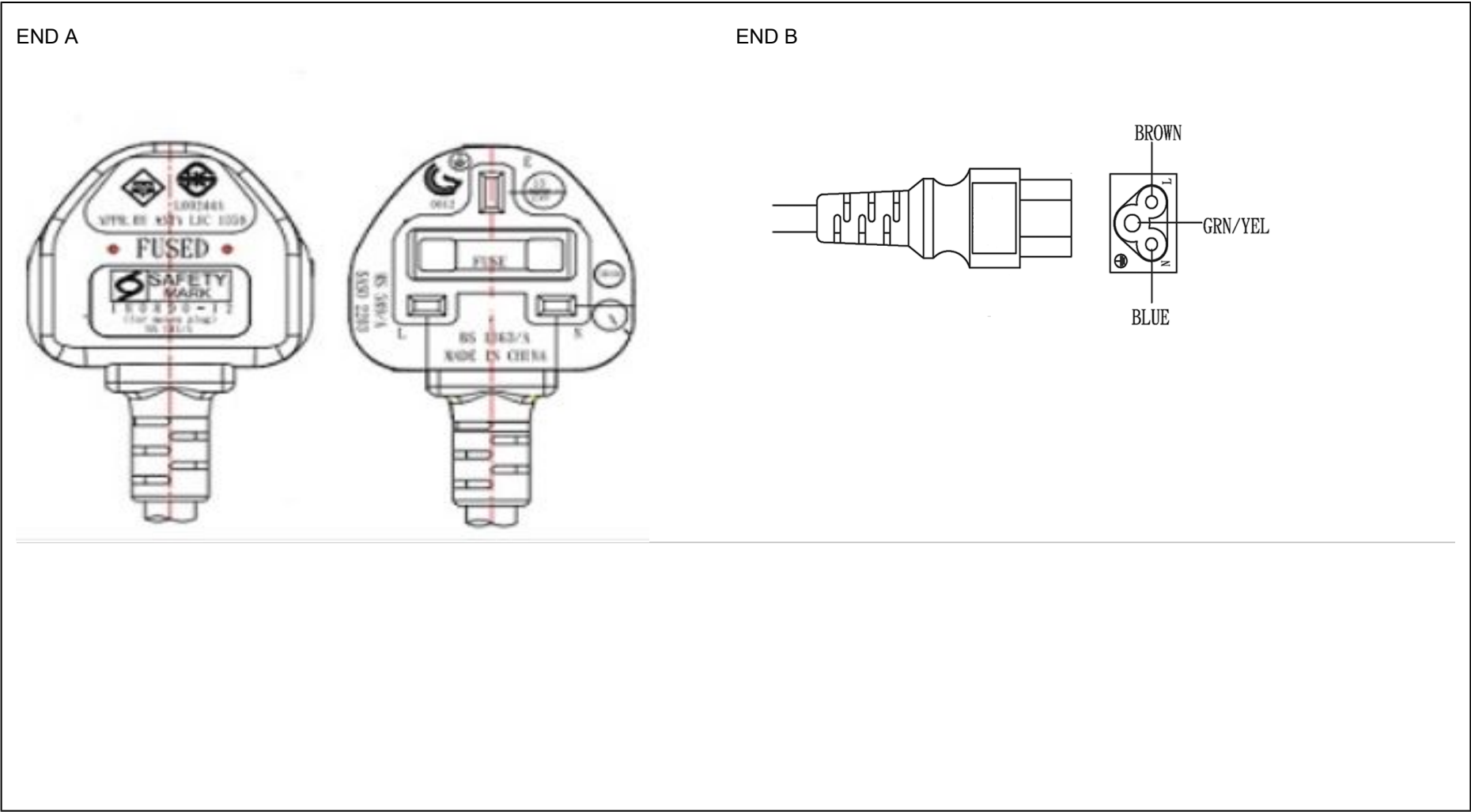

GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: UK Plug (Type G) BS1363A, Fused at 3A to IEC320-C5, GT Cable #426: 0.75mmsq / 3 Conductors, 6.8 +/- 0.3mm OD, H05VV-F, 70 Deg.C, 500V, BLU/BRN/GRN-YW, Approvals: IEC 60227, 2050mm, GlobTek Black	
	Model No. Power Cord	
	Part No./Ordering No. 6104262M0712(R)	Rev D1

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

CABLE IMAGE

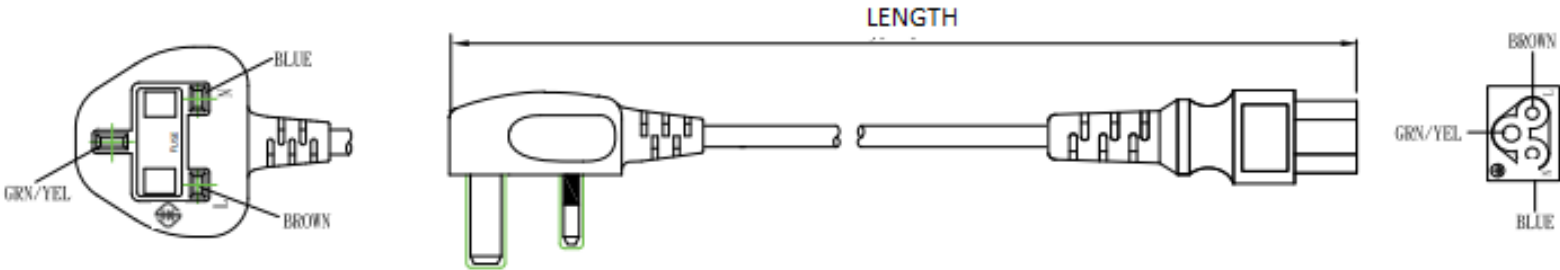








GloboTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: UK Plug (Type G) BS1363A, Fused at 3A to IEC320-C5, GT Cable #426: 0.75mmsq / 3 Conductors, 6.8 +/- 0.3mm OD, H05VV-F, 70 Deg.C, 500V, BLU/BRN/GRN-YW, Approvals: IEC 60227, 2050mm, GloboTek Black	
	Model No. Power Cord	
	Part No./Ordering No. 6104262M0712(R)	Rev D1

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

End A Code:PZ0800-3A Description:UK Plug (Type G) BS1363A, Fused at 3A Rating (V):250 Rating (A):10.0 Gender:Male Overmolded:Yes	Cable Code:426 Description:GT Cable #426: 0.75mmsq / 3 Conductors, 6.8 +/- 0.3mm OD, H05VV-F, 70 Deg.C, 500V, BLU/BRN/GRN-YW, Approvals: IEC 60227 Color:GloboTek Black Wire Gauge(AWG):0.75mmsq Cond:3 Type:H05VV-F Temperature:70° C Amps:10 Volts:500 OD:6.8 +/- 0.3 ConductorsColors:BLU/BRN/GRN-YW	End B Code:712EU Description:IEC320-C5 Rating (V):250 Rating (A):2.5 Gender:Female Overmolded:Yes
Overall cable rating:2.5A / 250V~		

GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: UK Plug (Type G) BS1363A, Fused at 3A to IEC320-C5, GT Cable #426: 0.75mmsq / 3 Conductors, 6.8 +/- 0.3mm OD, H05VV-F, 70 Deg.C, 500V, BLU/BRN/GRN-YW, Approvals: IEC 60227, 2050mm, GlobTek Black	
	Model No. Power Cord	
	Part No./Ordering No. 6104262M0712(R)	Rev D1

 CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

Plug Approvals		Cable Approvals	Connector Approvals	
<div>United Kingdom ASTA Diamond Approval Mark</div> <div>Singapore PSE safety mark</div> <div>Hong Kong HK safety mark</div> <div>Saudi Arabia SASO safety mark</div> <div>(file # only -- SASO 2203)</div> <div>Malaysia (File number)</div> <div>Gulf Conformity mark</div>		<div> KEMM-KEMM ΔCEBEC ΔCEBEC ① ② ③ ④ ⑤ ⑥ ⑦ ⑧ ⑨ ⑩ ⑪ ⑫ ⑬ ⑭ ⑮ ⑯ ⑰ ⑱ ㉑ ㉒ ㉓ ㉔ ㉕ ㉖ ㉗ ㉘ ㉙ ㉚ ㉛ ㉜ ㉝ ㉞ ㉟ ㊱ ㊲ ㊳ ㊴ ㊵ ㊶ ㊷ ㊸ ㊹ ㊺ ㊻ ㊼ ㊽ ㊾ ㊿ SAA-190646-EA ㉞ A004049 60227 IEC 53(RVV) 300/500V ㉞ S01027-4002</div> <div>EU Cable Approvals</div>	<div>10 DVE</div> <div>ENEC-VDE</div> <div></div> <div>UKCA Certification</div>	
AGENCY ONLINE DOCUMENTS		http://en.globtek.com/cordsets/		
RoHS/RoHS3 Declaration		https://www.globtek.com/pdf/rohs_cert/01t30000002p8dyAAA		
REACH Declaration		https://www.globtek.com/pdf/iso_certificates/REACH.pdf		
Conflict Minerals Declaration		https://www.globtek.com/pdf/conflict-minerals.pdf		
Prop 65 Statement		https://en.globtek.com/prop-65-statement.pdf		
CE.UKCA.Cord		https://globtek.secure.force.com/spec/ec_decl_product_model_family_incl_cord?id=01t30000002p8dy		
IPXY rating is based on 3rd party testing and customers should check suitability and test system level IPXY rating before ordering.				

PROPRIETARY INFORMATION


PROPRIETARY OF GLOBTEK, INC. ANY REPRODUCTION, DISCLOSURE OR USE OF THIS DRAWING, IN WHOLE OR IN PART, IS HEREBY PROHIBITED EXCEPT AS SPECIFIED IN WRITING BY GLOBTEK, INC. © GlobTek, Inc.
2012 - 2023

quest /09/21/2023 7:15:14 AM

GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: UK Plug (Type G) BS1363A, Fused at 3A to IEC320-C5, GT Cable #426: 0.75mmsq / 3 Conductors, 6.8 +/- 0.3mm OD, H05VV-F, 70 Deg.C, 500V, BLU/BRN/GRN-YW, Approvals: IEC 60227, 2050mm, GlobTek Black	
	Model No. Power Cord	
	Part No./Ordering No. 6104262M0712(R)	Rev D1

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

Hanking:200
Description:200 +/- 20mm
Image:

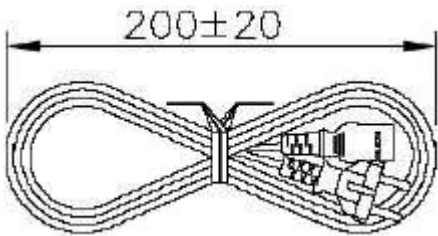

Notes/Modifications/Customizations (notes in this section supersede the values shown in the standard spec):