

# US-WMTB (29X8) - Cable marker




0828772

<https://www.phoenixcontact.com/us/products/0828772>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Cable marker, Card, white, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: Assembly with cable ties, cable diameter: > 13 mm, lettering field size: 29 x 8 mm, Number of individual labels: 24

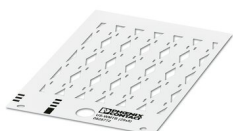

## Your advantages

- The markers, which are supplied as uniform cards, can be labeled quickly, easily, and cost-effectively using the THERMOMARK CARD
- The US-WMTB... UniSheet labeling range includes markers that can be secured using standard cable binders
- The perforated marking strips are easy to separate and can be easily fitted
- The cards provide space for including function texts

## Commercial data

Item number	0828772
Packing unit	1 pc
Minimum order quantity	10 pc
Sales key	BG09
Product key	BG2319
Catalog page	Page 214 (C-3-2019)
GTIN	4046356559898
Weight per piece (including packing)	13.08 g
Weight per piece (excluding packing)	12.926 g
Customs tariff number	39204910
Country of origin	DE

# US-WMTB (29X8) - Cable marker



0828772

<https://www.phoenixcontact.com/us/products/0828772>

## Technical data

### Product properties

Product type	Conductor marking
Type	Card form

### Marking

Number of individual labels	24
Number of individual labels per row	6

### Dimensions

Width	16 mm
Length	29 mm

### External dimensions

Outside diameter	> 13 mm ... 136 mm
------------------	--------------------

### Material specifications

Color	white
Material	PVC
Flammability rating according to UL 94	V0
Components	Silicone-free

### Cable/line

External cable diameter	> 13 mm
-------------------------	---------

### Environmental and real-life conditions

#### Test for substances that would hinder coating with paint or varnish

Result	Test passed
--------	-------------

#### UV resistance

Specification	ISO 4892-2:2013-03 (following)
Result	Test passed
Test duration	96 h

#### Wipe resistance of inscriptions

Specification	DIN EN 61010-1 (VDE 0411-1):2011-07
	DIN EN 62208 (VDE 0660-511):2012-06 (in parts)

#### Testing in a condensation changing climate in the presence of sulfur dioxide

Specification	DIN 50018:2013-05
Result	Test passed
Climate level	AHT 1.0 S
Cycles	2

#### Salt spray test

# US-WMTB (29X8) - Cable marker



0828772

<https://www.phoenixcontact.com/us/products/0828772>

Specification	DIN EN 60068-2-11:2000-02
Result	Test passed

## Ambient conditions

Ambient temperature (operation)	-30 °C ... 80 °C
Recommended storage conditions	23 °C/50 % relative humidity. Storage in a dry and dark place in the original packaging is recommended.
Recommended ambient temperature (storage/transport)	23 °C
Recommended humidity (storage/transport)	50 %
Shelf life	12 months

## Standards and regulations

Wipe resistance	DIN EN 61010-1 (VDE 0411-1)
-----------------	-----------------------------

## Mounting

Mounting type	Assembly with cable ties
---------------	--------------------------

# US-WMTB (29X8) - Cable marker



0828772

<https://www.phoenixcontact.com/us/products/0828772>

## Classifications

### ECLASS

ECLASS-11.0	27281102
ECLASS-12.0	27281102
ECLASS-13.0	27281102

### ETIM

ETIM 8.0	EC001530
----------	----------

### UNSPSC

UNSPSC 21.0	39131500
-------------	----------

# US-WMTB (29X8) - Cable marker

0828772

<https://www.phoenixcontact.com/us/products/0828772>



## Accessories

### BLUEMARK ID - Printer

1003334

<https://www.phoenixcontact.com/us/products/1003334>



Monochrome printer with UV LED technology and integrated "MARKING system app" identification software. 7" touch color display for printing plastic tags in UC, UCT, US, and UM format, as well as metal labels.

---

### BLUEMARK ID COLOR - Printer

1002329

<https://www.phoenixcontact.com/us/products/1002329>



CMYK multicolor printer with UV LED technology, with integrated "MARKING system app" identification software, 7" touch color display for printing plastic tags in UC, UCT, and UM format, as well as metal labels.

## US-WMTB (29X8) - Cable marker

0828772

<https://www.phoenixcontact.com/us/products/0828772>



## BLUEMARK CLED - Printer

5147999

<https://www.phoenixcontact.com/us/products/5147999>



Printers with LED-UV technology for printing plastic labels in UniCard format.

---

## THERMOMARK PRIME - Thermal transfer printer

5148888

<https://www.phoenixcontact.com/us/products/5148888>



Mobile thermal transfer printer for card materials, including power supply unit, Euro/US power cable, and USB cable. User manual printed in German and English. Magazine for UCT-TM... sheets and magazine for US-... cards. One packing unit each UCT-TM 6, US-EMLP (85,6x54), ink ribbon cartridge = 70 m

## US-WMTB (29X8) - Cable marker

0828772

<https://www.phoenixcontact.com/us/products/0828772>



## THERMOMARK CARD 2.0 - Thermal transfer printer

1085267

<https://www.phoenixcontact.com/us/products/1085267>



Thermal transfer printer for card materials, including Euro/US power cable and USB cable. User manual printed in German and English. Magazine for UCT-TM.. sheets and magazines for US-... cards. One packing unit each UCT-TM 6, US-EMLP (85,6x54), ink ribbon = 50 m

---

## THERMOMARK CARD - Thermal transfer printer

5146464

<https://www.phoenixcontact.com/us/products/5146464>



Thermal transfer printer for cards

## US-WMTB (29X8) - Cable marker

0828772

<https://www.phoenixcontact.com/us/products/0828772>



## THERMOMARK CARD-US-MAG1 - Magazine

5146451

<https://www.phoenixcontact.com/us/products/5146451>

Magazine for the THERMOMARK CARD printer, for accommodating US cards



---

## TMP-US-MAG1 - Magazine

0803341

<https://www.phoenixcontact.com/us/products/0803341>

Magazine, For THERMOMARK CARD and THERMOMARK PRIME, for accommodating US cards





## US-WMTB (29X8) - Cable marker

0828772

<https://www.phoenixcontact.com/us/products/0828772>



### THERMOMARK-RIBBON 110/50-TC - Ink ribbon

0801384

<https://www.phoenixcontact.com/us/products/0801384>



Ink ribbon, for THERMOMARK CARD for printing product groups UCT..., US..., and UM..., length: 50 m, roll length: 50 m, width: 110 mm, color: black

---

### THERMOMARK-RIBBON 110-TC - Ink ribbon

0801371

<https://www.phoenixcontact.com/us/products/0801371>



Ink ribbon, for THERMOMARK CARD for printing product groups UCT..., US..., and UM..., length: 300 m, roll length: 300 m, width: 110 mm, color: black

## US-WMTB (29X8) - Cable marker

0828772

<https://www.phoenixcontact.com/us/products/0828772>



### TMP-RIBBON 110 BK 100 - Ink ribbon cartridge

0803374

<https://www.phoenixcontact.com/us/products/0803374>

Ink ribbon cartridge, for THERMOMARK PRIME for printing product groups UCT. ..., US..., and UM..., roll length: 70 m, width: 110 mm, color: black



---

### TMP-RIBBON 110 BK 101 - Ink ribbon cartridge

0803714

<https://www.phoenixcontact.com/us/products/0803714>

Ink ribbon cartridge, for THERMOMARK PRIME for printing product groups US(2)-TM(F)..., US-TM(F)L..., US-WMTB..., US-EML..., US-EML(S)P..., US-EMLP-HA..., US-EM(S)P..., US-EML-RS..., roll length: 60 m, width: 110 mm, color: black



## US-WMTB (29X8) - Cable marker

0828772

<https://www.phoenixcontact.com/us/products/0828772>



### TMP-RIBBON 110 BU 100 - Ink ribbon cartridge

0803378

<https://www.phoenixcontact.com/us/products/0803378>



Ink ribbon cartridge, for THERMOMARK PRIME for printing product groups US(2)-TM(F)..., US-TM(F)L..., US-WMTB..., US-EML..., US-EML(S)P..., US-EMLP-HA..., US-EM(S)P..., US-EML-RS..., roll length: 60 m, width: 110 mm, color: blue

---

### TMP-RIBBON 110 GN 100 - Ink ribbon cartridge

0803380

<https://www.phoenixcontact.com/us/products/0803380>



Ink ribbon cartridge, for THERMOMARK PRIME for printing product groups US(2)-TM(F)..., US-TM(F)L..., US-WMTB..., US-EML..., US-EML(S)P..., US-EMLP-HA..., US-EM(S)P..., US-EML-RS..., roll length: 60 m, width: 110 mm, color: green

## US-WMTB (29X8) - Cable marker

0828772

<https://www.phoenixcontact.com/us/products/0828772>



### TMP-RIBBON 110 RD 100 - Ink ribbon cartridge

0803377

<https://www.phoenixcontact.com/us/products/0803377>



Ink ribbon cartridge, for THERMOMARK PRIME for printing product groups US(2)-TM(F)...., US-TM(F)L...., US-WMTB...., US-EML...., US-EML(S)P...., US-EMLP-HA...., US-EM(S)P...., US-EML-RS...., roll length: 60 m, width: 110 mm, color: red

---

### TMP-RIBBON 110 YE 100 - Ink ribbon cartridge

0803379

<https://www.phoenixcontact.com/us/products/0803379>



Ink ribbon cartridge, for THERMOMARK PRIME for printing product groups US(2)-TM(F)...., US-TM(F)L...., US-WMTB...., US-EML...., US-EML(S)P...., US-EMLP-HA...., US-EM(S)P...., US-EML-RS...., roll length: 60 m, width: 110 mm, color: yellow

## US-WMTB (29X8) - Cable marker

0828772

<https://www.phoenixcontact.com/us/products/0828772>



## BM ID-CARTR. BK - Ink cartridge

1044345

<https://www.phoenixcontact.com/us/products/1044345>



Replacement UV fluid, 23 ml, color: black

---

## BM ID-CARTR. CY - Ink cartridge

1044346

<https://www.phoenixcontact.com/us/products/1044346>



Replacement UV fluid, 23 ml, color: cyan

## US-WMTB (29X8) - Cable marker

0828772

<https://www.phoenixcontact.com/us/products/0828772>



## BM ID-CARTR. YE - Ink cartridge

1044348

<https://www.phoenixcontact.com/us/products/1044348>



Replacement UV fluid, 23 ml, color: yellow

---

## BM ID-ADAPTER PLATE-US - Magazine

1044355

<https://www.phoenixcontact.com/us/products/1044355>



Adapter plate for accommodating US sheets

---

Phoenix Contact 2023 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)