


PROPRIETARY INFORMATION:
 PROPRIETARY OF GLOBTEK, INC. ANY REPRODUCTION, DISCLOSURE OR
 USE OF THIS DRAWING, IN WHOLE OR IN PART, IS HEREBY
 PROHIBITED EXCEPT AS SPECIFIED IN WRITING BY GLOBTEK, INC.

REVISION			
REV	DESCRIPTION	DATE	APPROVED
A	INITIAL RELEASE	04/10/18	MK

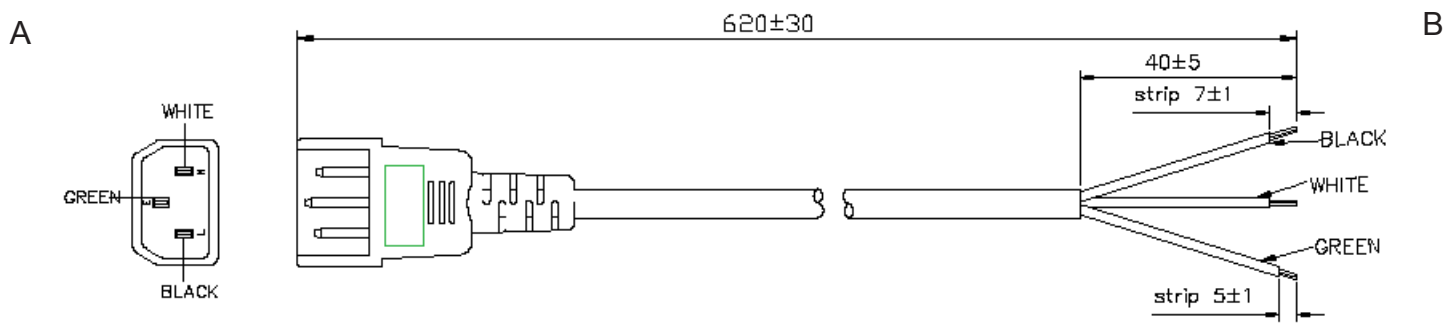

GENERAL SPECIFICATIONS:

RATING: 10A / 125V AC
 CABLE TYPE / SIZE: SJT, # 18 AWG, 3 CONDUCTOR
 TEMPERATURE RATING: 105° C
 CONDUCTOR COLORS: BLACK / WHITE / GREEN
 CABLE JACKET COLOR: BLACK
 OVERALL LENGTH (L): 620 ± 30 mm
 CABLE OUTER DIAMETER: 7.8 ± 0.1 mm
 END 'A' PLUG; IEC 320 / C14
 END 'B' SEE TERMINATION TABLE
 APPROVALS PLUG: UL, CSA OR cUL
 APPROVALS CABLE: UL, CSA OR cUL

PACKING:

BULK PACKED, BUNDLES OF 25.
 MAXIMUM SHIPPING CARTON WEIGHT IS 30 KG.

NOTES:

1. CORD AND PLUG MUST BE MARKED WITH APPROVAL SYMBOLS AND/ OR FILE NUMBERS.



CONDUCTOR TERMINATION TABLE:

Wire	Color	ROJ± 5 mm	RIJ±1mm	Terminal
NEUTRAL	WHT	40	7	STRIPPED
LINE	BLK	40	7	STRIPPED
GROUND	GRN	40	5	STRIPPED



DASH NO.	PART NO	REV.	DESCRIPTION	NOTES
TABULATION BLOCK				
REV.				
SHEET				
INIT.BY: DMR		DATE: 04/10/18	GlobTek, Inc. www.globtek.com 186 Veterans Dr. Northvale, NJ 07647 Tel. 201-784-1000 Fax 201.784.0111	
DRAWN: NF		DATE: 04/10/18	FS CN No.: G, CC SIZE: A	DWG TITLE: NORTH AMERICAN NON-DETACHABLE CORDSET MODEL: N / A REV. A
APRVD: DMR		DATE: 04/10/18	SCALE: NONE	PART NO: 7051062F00(R) SHEET 1/1

Foot Note:
 Globtek Inc. will not be liable for the safety and performance of these power product if unauthorized access and repair occurs. End user should consult the applicable UL, CSA or EN Standards for proper installation instruction.

Limitation of Use:
 Globtek product are not authorized for use as mission critical components in life support, hazardous environment, nuclear or aircraft applications without prior written approval from the CEO of Globtek Inc.

Contents of this document are subject to change without prior notice