

规格书

Specification

品 名
Model name

HYD-4216

PROPRIETARY
Huayu Electronic co.,Ltd.

CONFIDENTIAL
Huayu Electronic co.,Ltd.

Version #	Spec V1.1
制作日期 Date	2022/03/01
准备 Prepared	Yi Shen Acoustic specialist,R&D Dept.
承认 Approved	Qian Wanjin Executive Manager,R&D Dept.



兴化市华宇电子有限公司

地址：江苏省兴化市陈堡工业区人民路 1 号

电话：13625199874 传真：0523-83723118

邮箱：391245375@qq.com 网址：www.js-huayu.com

*Components Operating Div.
Huayu Electronic co.,Ltd.*

1.适用范围: 本规范适用于 HYD-4216 蜂鸣器。

This specifications apply the HYD-4216 buzzer.

2.基本规格/General specification

项目/Item		规格/Spec	条件/Condition
1	额定电压 Rated voltage	24VDC	
2	工作电压 Operation voltage	20~26VDC	
3	声压 Sound Pressure Level=SPL	Min 95dB	测试环境: 标准状态, 标准驱动电路, 额定电压 测试距离: 0.1m Standard State, Standard Drive Circuit. Rated voltage, Distance at 0.1m
4	平均消费电流 Average consumption current	Max 12mA	
5	振荡频率 Oscillation frequency	2700±500Hz	
6	工作温度范围 Range of operation temperature	-20~+70°C	
7	保存温度范围 Range of preservation temperature	-30~+80°C	
8	外部尺寸 Externals size	Φ41.8*16	参阅附图 Refer to the attached drawing
9	重量 Mass	11g	

☆标准状态: 常温 (15~35°C), 湿度 (25~85%相对湿度), 空气压力 (860~1060hpa)

在假设的情况判断, 测试是一基本状态下进行。

Standard State: Ordinary Temp(15~35°C), Humidity(25~85%RH), Air pressure(860~1060hPa)



In case of doubtful judgment, the test is re—performed under Basic State.

☆基本情况: 温度。(20±2°C), 湿度 (60~70%相对湿度), 空气压力 (860~1060hpa)



Basic State: Temp.(20±2°C), Humidity(60~70%RH), Air pressure(860~1060hPa)

<标准驱动电路>/<Standard Drive Circuit>

<标标测试治具>/<Standard Test Fixture>

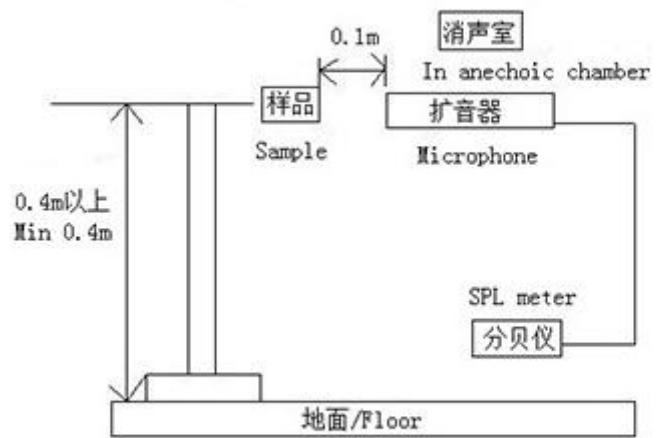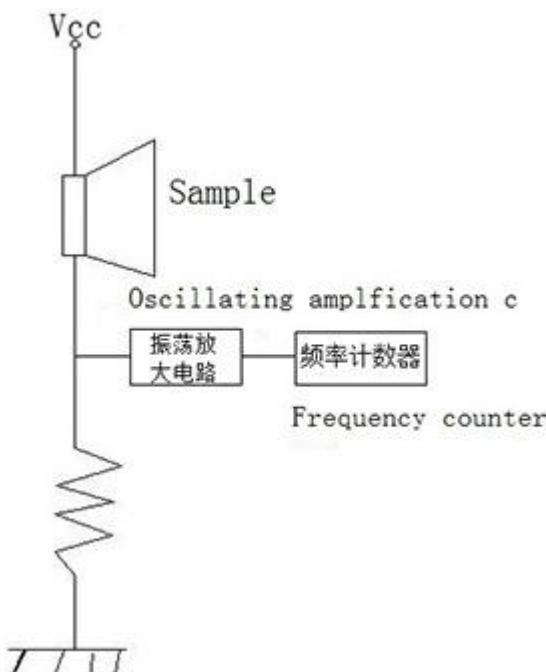


3. 可靠性规范/Reliability specification

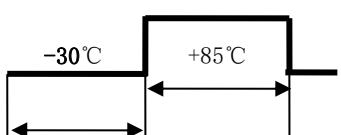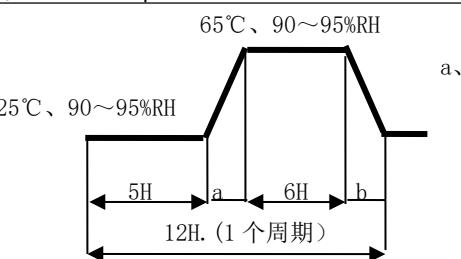项目/Item	试验条件/Test condition	判断标准/Criteria	引用规格/Reference Specification
高温保存试验 High temperature Preservation	+85°C 环境下放置 96 小时 Exposure to +85°C for 96 hrs.	经过测试，符合规格，没有任何不合格的外观和性能，除了是 80 分贝或以上 (2700±500 Hz) After the test the part shall meet specifications without any degradation in appearance And performance except SPL. SPL shall be 80 dB More. (at 2700±500 Hz)	GB/T 2423.2
低温保存试验 Low temperature preservation	-30°C 环境下放置 96 小时 Exposure to -30°C for 96 hrs.	After the test the part shall meet specifications without any degradation in appearance And performance except SPL. SPL shall be 80 dB More. (at 2700±500 Hz)	GB/T 2423.1
耐温试验 Thermal Shock	 -30°C → +85°C → -30°C 10 次周期 10 cycles	10 次周期 10 cycles	GB/T 2423.4
温湿度试验 Thermal, Humidity Shock	 65°C、90~95%RH 25°C、90~95%RH a, b=0.5H 12H. (1 个周期) 10 cycles	10 cycles	
常温寿命试验 Ordinary Temp. Life	常温 (25°C ±10°C) 电压 24VDC 连续测试 1000 小时 Driving the sounder at 24VDC for 1000hrs in the room temperature (25°C ±10°C)		
高温寿命试验 High Temp. Life	高温 (+80°C) 电压 24VDC 连续测试 500 小时 Driving the sounder at 24VDC for 500hrs in the low temperature (+80°C)		
低温寿命试验 Low Temp. Life	低温 (-20°C) 电压 24VDC 连续测试 500 小时 Driving the sounder at 24VDC for 500hrs in the low temperature (-20°C)		

4. 尺寸图/Dimension


(UNIT: mm)

Tolerance: ±0.5mm Except Specified

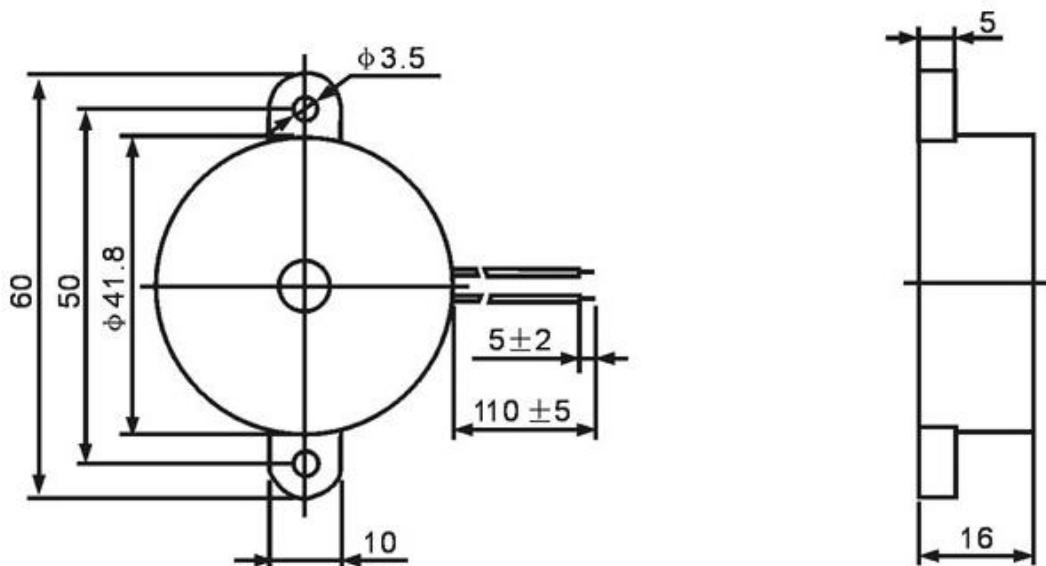

5.频率图/Frequency Response:

FREQUENCY RESPONSE

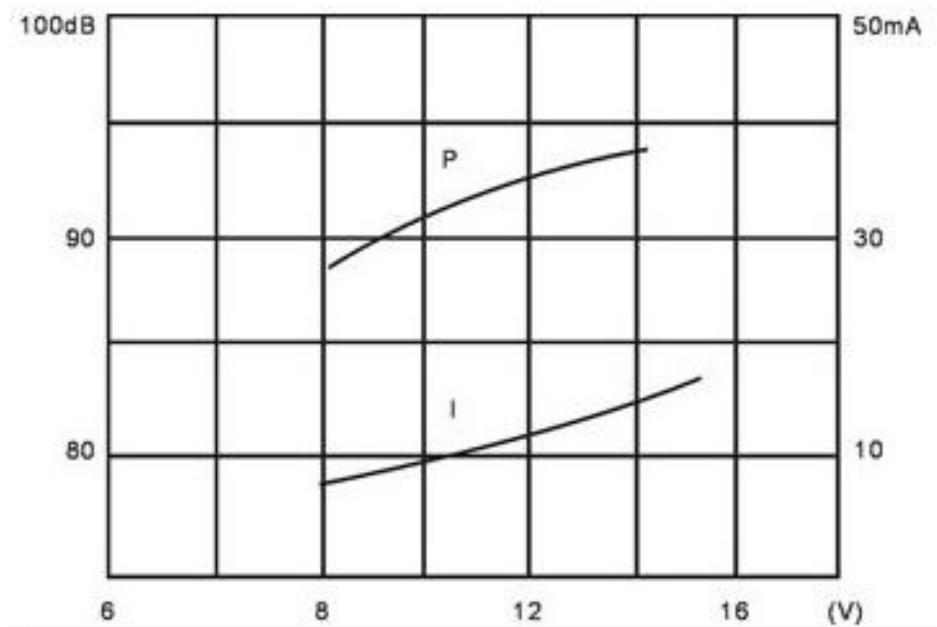

兴化市华宇电子有限公司

地址：江苏省兴化市陈堡工业区人民路1号

电话：13625199874 传真：0523-83723118

邮箱：1993937868@qq.com 网址：www.js-huayu.com

*Components Operating Div.
Huayu Electronic co.,Ltd*