

# SAC-5P-20,0-680/M12FS FDP - Sensor/actuator cable



1095816

<https://www.phoenixcontact.com/us/products/1095816>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Sensor/actuator cable, 5-position, shielded, free cable end, on Socket straight M12, coding: A, cable length: 20 m, Foil shielding plus drain wire

## Commercial data

|                                      |                                |
|--------------------------------------|--------------------------------|
| Item number                          | 1095816                        |
| Packing unit                         | 1 pc                           |
| Note                                 | Made to order (non-returnable) |
| Sales key                            | BF13                           |
| Product key                          | BF1IEC                         |
| GTIN                                 | 4055626927671                  |
| Weight per piece (including packing) | 22.22 g                        |
| Weight per piece (excluding packing) | 22.22 g                        |
| Country of origin                    | US                             |

## Technical data

### Product properties

|                      |                       |
|----------------------|-----------------------|
| Product type         | Sensor/actuator cable |
| Number of positions  | 5                     |
| Application          | Standard, U.S. cables |
| No. of cable outlets | 1                     |
| Shielded             | yes                   |
| Coding               | A                     |

### Insulation characteristics

|                      |    |
|----------------------|----|
| Overvoltage category | II |
| Degree of pollution  | 3  |

### Material specifications

|                                        |                                             |
|----------------------------------------|---------------------------------------------|
| Flammability rating according to UL 94 | HB                                          |
| Seal material                          | NBR                                         |
| Material of grip body                  | TPU, hardly inflammable, self-extinguishing |
| Contact material                       | CuSn                                        |
| Contact surface material               | Ni/Au                                       |
| Contact carrier material               | TPU GF                                      |
| Material for screw connection          | Zinc die-cast, nickel-plated                |

### Electrical properties

|                       |                            |
|-----------------------|----------------------------|
| Contact resistance    | $\leq 5 \text{ m}\Omega$   |
| Insulation resistance | $\geq 100 \text{ M}\Omega$ |
| Nominal voltage $U_N$ | 48 V AC                    |
|                       | 60 V DC                    |
| Nominal current $I_N$ | 4 A                        |
| Protective circuit    | unwired                    |

### Mechanical properties

#### Mechanical data

|                             |            |
|-----------------------------|------------|
| Insertion/withdrawal cycles | $\geq 100$ |
|-----------------------------|------------|

### Signaling

|                        |    |
|------------------------|----|
| Status display         | No |
| Status display present | No |

### Connection data

#### Conductor connection

|                   |                        |
|-------------------|------------------------|
| Tightening torque | 0.4 Nm (M12 connector) |
|-------------------|------------------------|

# SAC-5P-20,0-680/M12FS FDP - Sensor/actuator cable



1095816

<https://www.phoenixcontact.com/us/products/1095816>

## Connector

### Connection 1

|      |                |
|------|----------------|
| Type | free cable end |
|------|----------------|


### Connection 2

|                     |                     |
|---------------------|---------------------|
| Type                | Socket straight M12 |
| Number of positions | 5                   |
| Coding type         | A                   |
| Number of positions | 5                   |

## Cable/line

|              |      |
|--------------|------|
| Cable length | 20 m |
|--------------|------|

### PVC, gray, 105°C [680]
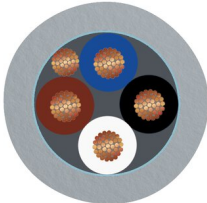
|                                               |                                                                                     |
|-----------------------------------------------|-------------------------------------------------------------------------------------|
| Dimensional drawing                           |  |
| Cable weight                                  | 45.42 kg/km                                                                         |
| UL AWM Style                                  | 2517 (105 °C / 300 V)                                                               |
| Number of positions                           | 4                                                                                   |
| Shielded                                      | yes                                                                                 |
| Cable type                                    | PVC, gray, 105°C [680]                                                              |
| AWG signal line                               | 22                                                                                  |
| Wire diameter incl. insulation                | 1.27 mm ±0.03 mm                                                                    |
| External cable diameter                       | 5.08 mm ±0.2 mm                                                                     |
| Outer sheath, material                        | PVC                                                                                 |
| External sheath, color                        | gray                                                                                |
| Conductor material                            | Tin-plated Cu litz wires                                                            |
| Material wire insulation                      | PVC (Signal line)                                                                   |
| Single wire, color                            | brown, white, blue, black                                                           |
| Type of pair shielding                        | Plastic-coated aluminum foil, aluminum side inside                                  |
| Overall twist                                 | Conductors, fillers, and drain wire are twisted with left-hand lay                  |
| Max. conductor resistance                     | max. 51.1 Ω/km (20 °C)                                                              |
| Insulation resistance                         | ≥ (550 M Ohms/m @ 500V)                                                             |
| Nominal voltage, cable                        | 300 V                                                                               |
| Minimum bending radius, flexible installation | 8 x D                                                                               |
| Flame resistance                              | FT4                                                                                 |
| Other resistance                              | UV resistant                                                                        |

# SAC-5P-20,0-680/M12FS FDP - Sensor/actuator cable



1095816

<https://www.phoenixcontact.com/us/products/1095816>

|                                 |                                               |
|---------------------------------|-----------------------------------------------|
| Special properties              | UL standards PLTC and ITC                     |
| Ambient temperature (operation) | -30 °C ... 105 °C (cable, fixed installation) |

## Environmental and real-life conditions

### Ambient conditions

|                                 |                                                |
|---------------------------------|------------------------------------------------|
| Degree of protection            | IP65                                           |
|                                 | IP67                                           |
|                                 | IP68                                           |
| Ambient temperature (operation) | -25 °C ... 90 °C (Plug / socket)               |
|                                 | -40 °C ... 80 °C (cable, fixed installation)   |
|                                 | -5 °C ... 80 °C (Cable, flexible installation) |

## Standards and regulations

|                          |                 |
|--------------------------|-----------------|
| Standard designation     | M12 connector   |
| Standards/specifications | IEC 61076-2-101 |

# SAC-5P-20,0-680/M12FS FDP - Sensor/actuator cable




1095816


<https://www.phoenixcontact.com/us/products/1095816>

## Drawings

Circuit diagram

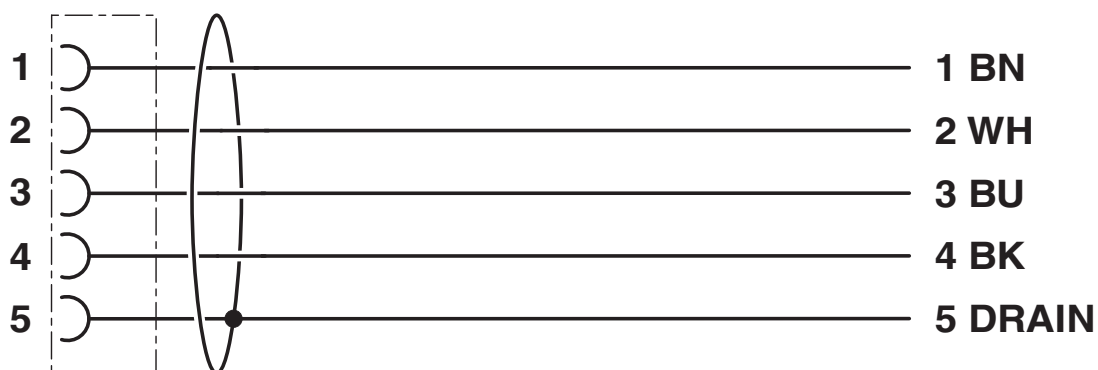


Dimensional drawing

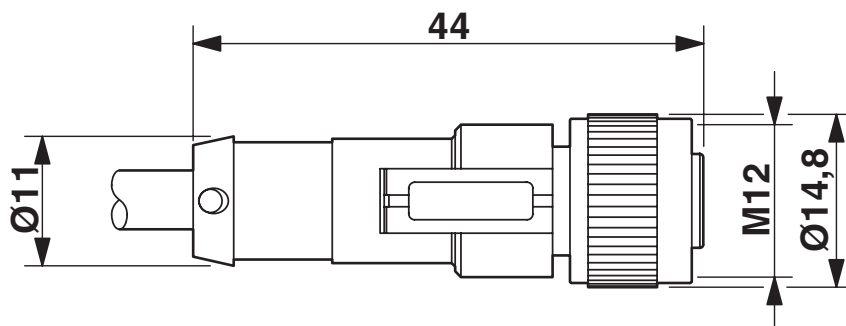

M12 x 1 socket, straight

Schematic diagram

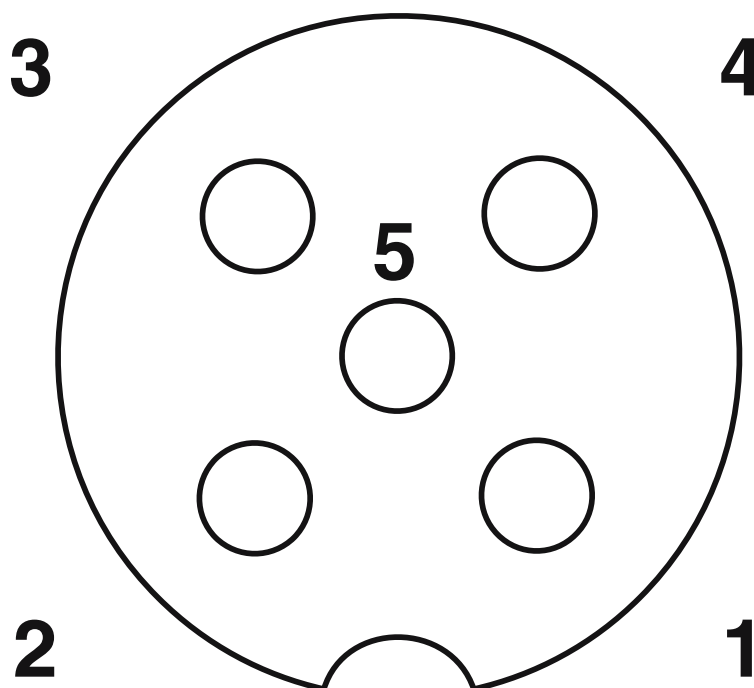

Pin assignment M12 socket, 5-pos., A-coded, female side

# SAC-5P-20,0-680/M12FS FDP - Sensor/actuator cable



1095816

<https://www.phoenixcontact.com/us/products/1095816>

## Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1095816>



### UL Listed

Approval ID: FILE E 221474

|  | Nominal voltage $U_N$ | Nominal current $I_N$ | Cross section AWG | Cross section $\text{mm}^2$ |
|--|-----------------------|-----------------------|-------------------|-----------------------------|
|  | 125 V                 | 4 A                   | -                 | -                           |



### cUL Listed

Approval ID: FILE E 221474

|  | Nominal voltage $U_N$ | Nominal current $I_N$ | Cross section AWG | Cross section $\text{mm}^2$ |
|--|-----------------------|-----------------------|-------------------|-----------------------------|
|  | 125 V                 | 4 A                   | -                 | -                           |

### cULus Listed

# SAC-5P-20,0-680/M12FS FDP - Sensor/actuator cable



1095816

<https://www.phoenixcontact.com/us/products/1095816>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-11.0 | 27060311 |
| ECLASS-12.0 | 27060311 |
| ECLASS-13.0 | 27060311 |

### ETIM

|          |          |
|----------|----------|
| ETIM 8.0 | EC001855 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 31251501 |
|-------------|----------|

# SAC-5P-20,0-680/M12FS FDP - Sensor/actuator cable



1095816

<https://www.phoenixcontact.com/us/products/1095816>

## Accessories

### PROT-M12 FS-PA-CHAIN - Sealing cap

1430873

<https://www.phoenixcontact.com/us/products/1430873>

M12 sealing cap made of plastic with fixing band, for sensor cables, for free M12 plugs



---

### SAC-M12-EXCLIP-M - Locking clip

1558988

<https://www.phoenixcontact.com/us/products/1558988>

Locking clip for the pin side of sensor/actuator cables with M12 connector and M12 connectors for assembly, for knurl diameter: 15 mm or for Allen key with a wrench size of 14 mm, prevents the disconnection of plug-in connections without tools



# SAC-5P-20,0-680/M12FS FDP - Sensor/actuator cable



1095816

<https://www.phoenixcontact.com/us/products/1095816>

## PROT-M12 MS-PA-CHAIN - Screw plug

1430899

<https://www.phoenixcontact.com/us/products/1430899>

M12 sealing cap with fixing band, for sensor cables, for free M12 sockets



---

## SAC-M12-EXCLIP-F - Locking clip

1558991

<https://www.phoenixcontact.com/us/products/1558991>

Locking clip for the socket side of sensor/actuator cables with M12 connector and M12 connectors for assembly, for knurl diameter: 15 mm or for Allen key with a wrench size of 14 mm, prevents the disconnection of plug-in connections without tools



# SAC-5P-20,0-680/M12FS FDP - Sensor/actuator cable



1095816

<https://www.phoenixcontact.com/us/products/1095816>

## TSD 04 SAC - Torque screwdriver

1208429

<https://www.phoenixcontact.com/us/products/1208429>



Torque screwdriver, with preset torque of 0.4 Nm and 4 mm hexagonal drive for M12 connectors

---

## TSD-M 1,2NM - Torque screwdriver

1212224

<https://www.phoenixcontact.com/us/products/1212224>



Torque screw driver, accuracy as per EN ISO 6789 standard, adjustable from 0.3 - 1.2 Nm

# SAC-5P-20,0-680/M12FS FDP - Sensor/actuator cable



1095816

<https://www.phoenixcontact.com/us/products/1095816>

## TSD-M SAC-BIT ADAPTER - Adapter insert

1212600

<https://www.phoenixcontact.com/us/products/1212600>



Adapter bit for TSD-M...torque tools, E6.3-1/4" drive with 4 mm hexagon to accommodate SAC bits

---

## SAC BIT M12-D15 - Tool

1208432

<https://www.phoenixcontact.com/us/products/1208432>



Nut for assembling sensor/actuator cables with M12 connector and M12 connectors for assembly, with a knurl diameter of 15 mm, for 4 mm hexagonal drive

---

Phoenix Contact 2023 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)