


E18206

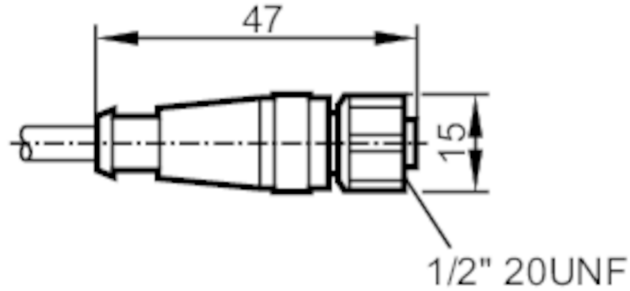

Female cordset

ADOGA030VAS0005E03



Application

System gold-plated contacts

Electrical data

Operating voltage [V] < 300 AC/DC

Operating conditions

Ambient temperature [°C] -10...100

Protection IP 68

Mechanical data

Weight [g] 199.58

Dimensions [mm] 15 x 15 x 47

Material PVC

Molded-body material PVC

Material nut stainless steel (1.4571/316Ti)

Remarks

Pack quantity 1 pcs.

E18206



Female cordset

 
ADOGA030VAS0005E03

Electrical connection


Cable: 5 m, PVC, yellow; 3 x 0.34 mm² / AWG 22

Electrical connection - Socket

Connector: 1 x 1/2", straight; coding: C; Moulded body: PVC; Locking: stainless steel (1.4571/316Ti); Contacts: gold-plated



Connection

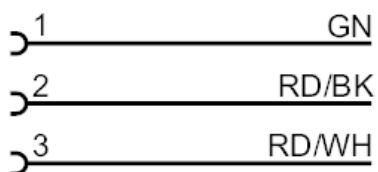

GN = Core colors :
RD/BK = green
RD/WH = red/black
red/white